
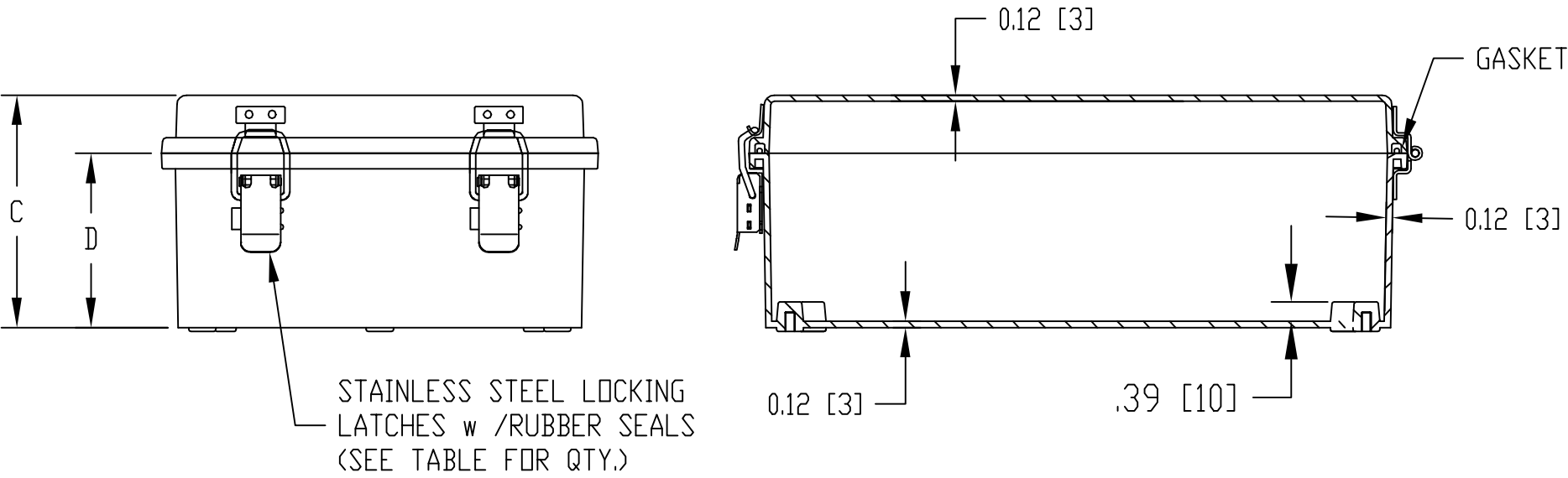


BUD	PART	PTH SERIES NEMA 4X PLASTIC BOX	PART	PTH-22706-L THRU	PTH-22780-L	REV.	12-1-17
	NAME	LANDSCAPE ORIENTATION (HINGED ON SHORT SIDE)	No.	PTH-22706-LC THRU	PTH-22780-LC	DATE	

DRAWING FOR REFERENCE
WE RESERVE THE RIGHT TO MAKE CHANGES TO OUR
STANDARD PRODUCTS. PLEASE CONSULT WITH BUD INDUSTRIES
PRIOR TO USING THIS DRAWING FOR DESIGN PURPOSE.

- NOTES:
- 1- MATERIAL: BODY - GRAY POLYCARBONATE RESIN
10% GLASS FIBER FILLED
COVER - GRAY POLYCARBONATE OR
CLEAR (-C SUFFIX) POLY-
CARBONATE
 - 2- UL508 / NEMA TYPE 4X WITH IP-67 TUV RATING
& UL-94 5VA
 - 3- CONTINUOUS POURED NEOPRENE GASKET IN COVER
 - 4- SUPPLIED WITH TWO OR FOUR M5 x 8mm LG.
TRUSS HEAD ZINC PLATED STEEL SCREWS
(ITEMS NOT SHOWN)
 - 5- DIMENSIONS ARE INCH [MM]
 - 6- OPTIONAL ACCESSORIES NOT INCLUDED:
INTERNAL MOUNTING PLATES 16 GA. STEEL OR ABS
EXTERNAL MOUNTING BRACKETS NBX-10922
(STAINLESS STEEL) OR PIX-4117 (GRAY POLY-
CARBONATE RESIN 10% GLASS FIBER FILLED)

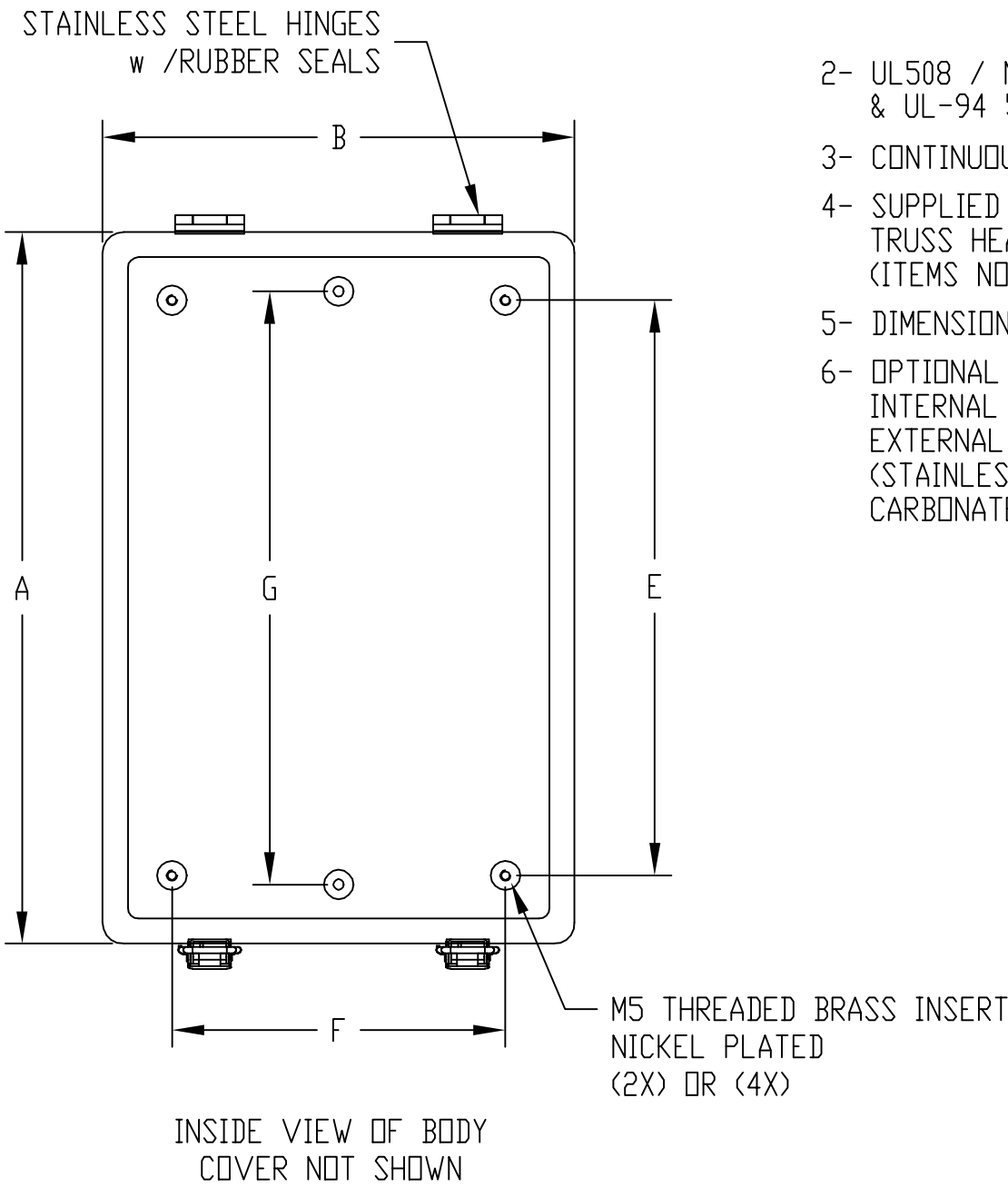

PART NO.		DIMENSIONS							LATCH QTY.
		A	B	C	D	E	F	G	
PTH-22706-L	PTH-22706-LC	9.84 [250]	5.91 [150]	5.12 [130]	3.15 [80]	---	---	8.27 [210]	2
PTH-22730-L	PTH-22730-LC	15.75 [400]	11.81 [300]	5.91 [150]	4.72 [120]	13.26 [337]	9.06 [230]	13.25 [336]	2
PTH-22746-L	PTH-22746-LC	14.96 [380]	7.48 [190]	5.04 [128]	3.86 [98]	4.72 [120]	12.20 [310]	---	2
PTH-22758-L	PTH-22758-LC	22.05 [560]	11.02 [280]	5.12 [130]	3.94 [100]	19.76 [502]	8.27 [210]	---	2
PTH-22760-L	PTH-22760-LC	16.93 [430]	13.00 [330]	7.09 [180]	5.91 [150]	14.17 [360]	10.22 [260]	14.75 [375]	2
PTH-22762-L	PTH-22762-LC	22.05 [560]	14.96 [380]	7.09 [180]	5.83 [148]	12.20 [310]	19.29 [490]	---	2
PTH-22780-L	PTH-22780-LC	9.84 [250]	3.15 [80]	3.35 [85]	1.97 [50]	7.87 [200]	1.59 [40]	8.65 [220]	1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bud Industries:

[PTH-22760-LC](#) [PTH-22762-L](#) [PTH-22762-LC](#) [PTH-22780-L](#) [PTH-22780-LC](#) [PTH-22730-LC](#) [PTH-22746-L](#) [PTH-22746-LC](#) [PTH-22758-L](#) [PTH-22758-LC](#) [PTH-22760-L](#) [PTH-22706-L](#) [PTH-22706-LC](#) [PTH-22730-L](#)