

Distribution Units have combinations of **four, five or six outlets** together with **neon indicator**, fuse and switch options. The **three sizes** are available in various combinations and, other than the compact version, all have shuttered outlets. The larger enclosed versions are also available with **EMI filtering**.




IEC Distribution Units



PXD301/050/01/1

- Five Shuttered Outlets
- 5 x 20mm Fuseholder
- Neon Indicator
- Filtered or Non-filtered
- EN60320 Inlet
- 10A, 250V AC

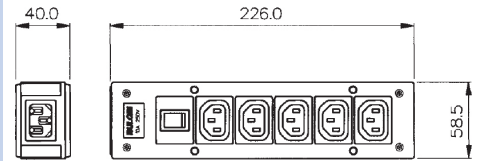


IEC Panel Mount Distribution Unit



PXD100/050/01/1

- Five Shuttered Outlets
- 5 x 20mm Fuseholder
- Neon Indicator
- Screw Fit to Panel
- 10A, 250V AC

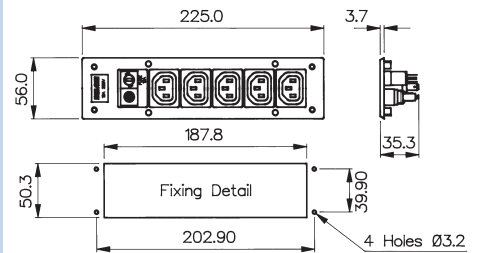


IEC Distribution Unit


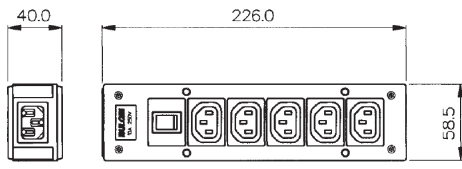

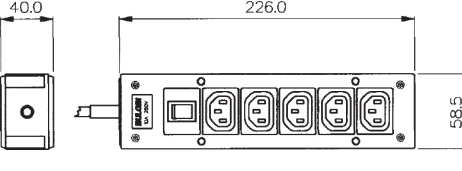


PXD303/050/01/1
 PXD306/050/01/1

- Five Shuttered Outlets
- 5 x 20mm Fuseholder
- Neon Indicator
- Filtered or Non-filtered
- 2 Metre Cable with BS1363 Plug
- 10A, 250V AC

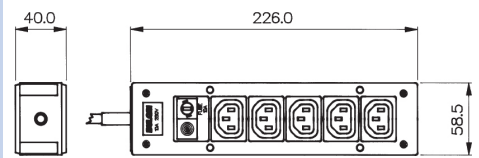

Part No.	Inlet	Outlet	EMI Filter	Neon Indicator	Fuse	Illuminated Switch
Panel Style:						
PXD100/050/01/1		5 Shuttered		1	1	
Box Style:						
PXD301/050/01/1	1	5 Shuttered		1	1	
PXD301/050/07/1	1	5 Shuttered				Red
PXD301/050/08/1	1	5 Shuttered	●			Green
PXD301/550/01/1	1	5 Shuttered	●	1	1	
PXD301/550/07/1	1	5 Shuttered	●			Red
PXD301/550/08/1	1	5 Shuttered	●			Green
PXD303/050/01/1	2m cable with BS1363 plug	5 Shuttered		1	1	
PXD303/050/07/1	2m cable with BS1363 plug	5 Shuttered				Red
PXD303/050/08/1	2m cable with BS1363 plug	5 Shuttered	●			Green
PXD303/550/01/1	2m cable with BS1363 plug	5 Shuttered	●	1	1	
PXD303/550/07/1	2m cable with BS1363 plug	5 Shuttered	●			Red
PXD303/550/08/1	2m cable with BS1363 plug	5 Shuttered	●			Green
PXD306/050/01/1	2m cable with CEE7 Sheet VII plug	5 Shuttered		1	1	

<p>IEC Distribution Unit</p>  <p>PXD301/050/07/1</p>	<ul style="list-style-type: none">○ Five Shuttered Outlets○ Illuminated Switch○ Filtered or Non-Filtered○ EN60320 Inlet○ 10A, 250V AC	
<p>IEC Distribution Unit</p>  <p>PXD303/050/08/1</p>	<ul style="list-style-type: none">○ Five Shuttered Outlets○ Illuminated Switch○ Filtered or Non-Filtered○ 2m Cable and BS1363 plug○ 10A, 250V AC	

Specifications

Mouldings:	Thermoplastic
Housing:	ABS
Connectors:	Nylon
Contacts:	Outlets: Brass, Tin Plated Inlets: Brass, Nickel Plated
Voltage Rating:	250V AC 50/60Hz
Current Rating:	10A
Proof Voltage:	2kV
Temp. Range:	-5°C to +60°C
Mating Connectors:	PX0686, PX0686/SE
RoHS	Compliant

Filter


Max. Earth Leakage:	
Current:	<0.35mA (at 250V, 50Hz)
Capacitor	2 x 2.2nF (Y), 1 x 15nF (X)
Inductance:	2 x 0.35mH
Fuse:	5 x 20mm, 10A (ceramic HRC type, IEC 127)

Compact Distribution Unit



PXD200

- Four Outlets
- EN60320 Inlet
- 10A, 250V AC
- cULus Approval

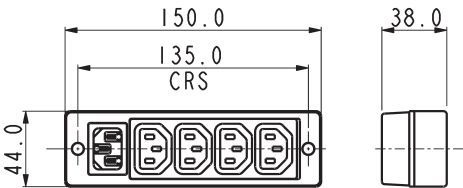


Compact Distribution Unit



PXD201

- Four Outlets
- 2m Cable with BS1363 connector, Schuko connector (CEE7) or NEMA 5/15 connector
- 10A, 250V AC

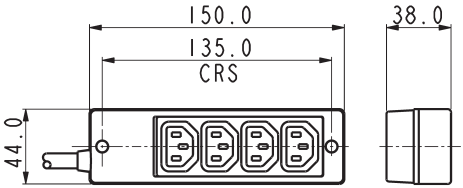

Specifications

Mouldings:	Thermoplastic
Housing:	ABS, UL94V-0
Connectors:	BS1363, CEE7, NEMA 5/15
Contacts:	Outlets: Brass, Tin Plated Inlets: Brass, Nickel Plated
Voltage Rating:	250V AC 50/60Hz
Current Rating:	10A
Proof Voltage:	2kV
Temp. Range:	-5°C to +60°C
Approvals	cULus Listed (PXD200)
RoHS	Compliant


Part No.	Inlet	Outlet
PXD200	1	4
PXD201	2m cable with BS 1363 plug	4
PXD201/1	2m cable with Schuko plug	4
PXD201/2	2m cable with NEMA 5/15	4

Compact Distribution Unit



PXD701/061/10/1

- Six Shuttered Outlets
- 5 x 20mm Fuseholder
- Filtered or Non Filtered
- Switch, Fuse, Neon Indicator
- With IEC Inlet
- 10A, 250V AC

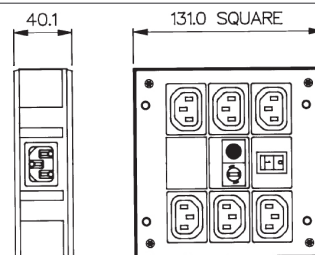


IEC Mount Distribution Unit



PXD500/061/10/1

- Six Shuttered Outlets
- 5 x 20mm Fuseholder
- Switch, Fuse, Neon Indicator
- Screw Fit to Panel
- 10A, 250V

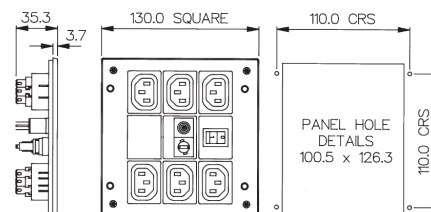


Compact Distribution Unit



PXD703/061/10/1
 PXD706/061/10/1

- Six Shuttered Outlets
- 5 x 20mm Fuseholder
- Filtered or Non Filtered
- Switch, Fuse, Neon Indicator
- 2 Metre Cable with BS1363 or CEE7 Plug
- 10A, 250V

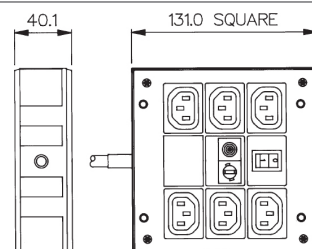

Specifications

Mouldings:	Thermoplastic
Housing:	ABS
Connectors:	Nylon
Contacts:	Outlets: Brass, Tin Plated Inlets: Brass, Nickel Plated
Voltage Rating:	250V AC 50/60Hz
Current Rating:	10A
Proof Voltage:	2kV
Temp. Range:	-5°C to +60°C
RoHS	Compliant

Part No.	Inlet	Outlet	EMI Filter	Switch	Fuse	Neon Indicator
Panel Style:						
PXD500/061/10/1		6 Shuttered		1	1	1
Box Style:						
PXD701/061/10/1	1	6 Shuttered		1	1	1
PXD701/561/10/1	1	6 Shuttered	●	1	1	1
PXD703/061/10/1	2m cable with BS 1363 plug	6 Shuttered		1	1	1
PXD703/561/10/1	2m cable with BS 1363 plug	6 Shuttered	●	1	1	1
PXD706/061/10/1	2m cable with CEE7 Sheet VII plug	6 Shuttered		1	1	1

Filter

Max. Earth Leakage Current:	<0.35mA (at 250V, 50Hz)
Capacitor	2 x 2.2nF (Y), 1 x 15nF (X)
Inductance:	2 x 0.35mH
Fuse:	5 x 20mm, 10A (ceramic HRC type, IEC 127)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bulgin:

[PXD100/050/01/1](#) [PXD701/561/10/1](#)