

8800 Thinline Rocker Switches 10A 250Vac



- ▶ Ultra thin rocker switch
- ▶ Ratings up to 15A, 250Vac
- ▶ Single and twin gang
- ▶ Bezel sizes:
Single 21 x 9.5
Twin 21 x 15.5



10(6)A 250Vac T100
6(2)A 250Vac T100 5E4 (50,000 Operations)
Inrush 50A to EN60065:1998



UL CSA 15A 250Vac (Twin unit is 10A 250Vac)
UL CSA 125Vac 1/2hp
UL 100°C, file E45221, CSA file LR10990

In house test


10A 28Vdc



RoHS compliant

3mm contact gap.
 Technical data on pages 4 & 5.

ORDER FORMAT

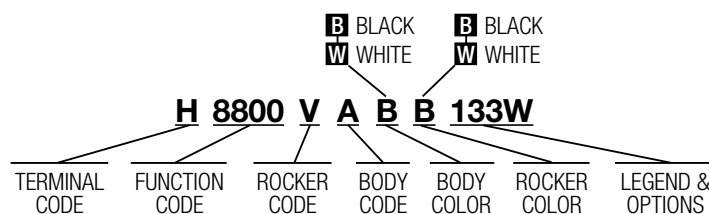

▶ TERMINAL	▶ FUNCTION	▶ ROCKER
H 4.8 x 0.8	 Switches are ON when pressed over terminal 1 8800 ON - OFF Single pole Switches are ON when pressed over terminals 1 or 3	V Curved
T 3.5 x 0.8 Solder	8800 8800 ON - OFF Twin (Single pole)	



H8800VA
T8800VA



H8800VA
T8800VA



H8800 8800VA
T8800 8800VA



H8800 8800VA
T8800 8800VA

BODY

A Single pole

Panel cut-out Bezel

*Optional profile for orientation

A Single pole - Twin

Panel cut-out Bezel

*Optional profile for orientation

Panel thickness	Dim X
0.75-1.24	19.1/19.2
1.25-1.99	19.3/19.4
2.00-3.00	19.7/19.8

Cut-outs must be punched in the direction of insertion

OPTIONS


Finish
Matt finish only

Color
Call factory for custom colors.
A full range is available for large orders


Legend printing
Select from the examples or call the factory for custom legends

Dimensions (mm)

8800VA (H terminals shown)

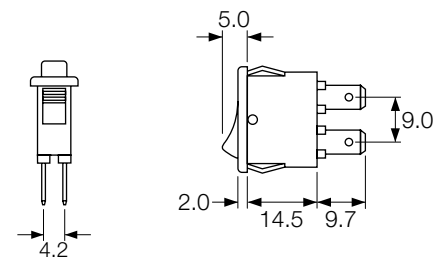

8800 8800VA (H terminals shown)

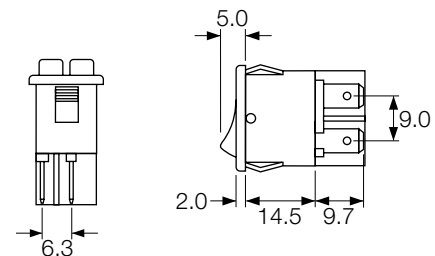

Examples of our range of legend printing

() is legend color B-Black, W-White, R-Red



132(W)



133(W)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[H8800VABB](#)