

7000 Push Button Switches 16A 250Vac



- ▶ Round and rectangular push button switches
- ▶ Ratings up to 16A, 250V ac
- ▶ Latching and momentary
- ▶ Illuminated & non-illuminated
- ▶ Matching indicators
- ▶ Low profile version
- ▶ Panel cut outs:
25.0 dia
27.2 x 22.3



16(4)A 250Vac T125
8(8)A 250Vac T85



UL CSA 16A Non Ind, 250Vac 1hp, 125Vac 1/2hp
UL 65°C, file no. E45221, CSA file no. LR10990



RoHS compliant

3mm contact gap.
Technical data on pages 4 & 5 (switches), 6 (indicators).

NON-LIT		LIT	
B BLACK	B BLACK	A AMBER	
R RED	R RED	C CLEAR	2 125V NEON
W WHITE	W WHITE	G GREEN	3 250V NEON
		R RED	7 12V INCANDESCENT

C 7053 A F W R 2 -----

TERMINAL CODE	FUNCTION CODE	ACTUATOR CODE	BODY CODE	BODY COLOR	ACTUATOR COLOR	LAMP VOLTAGE IF REQUIRED	LEGEND & OPTIONS
------------------	------------------	------------------	--------------	---------------	-------------------	-----------------------------	---------------------



ORDER FORMAT

TERMINAL	FUNCTION				ACTUATOR
C 6.3 x 0.8 9.1	7000 Single pole ON - OFF	7001 Single pole ON - OFF (momentary ON)	7003 Single pole ON - OFF with light	7004 Single pole ON - OFF (momentary ON) with light	A Round actuator shown in F body 21.0 9.7
H 4.8 x 0.8 9.1	7050 Double pole ON - OFF	7051 Double pole ON - OFF (momentary ON)	7053 Double pole ON - OFF with light	7054 Double pole ON - OFF (momentary ON) with light	B Round actuator - medium shown in F body 21.1 18.6
	7030 Indicator				C Round actuator - long shown in F body 21.1 29.5
					D Round actuator - sub panel mount 21.1 16.9
					S Rectangular actuator Shown in "A" body N/A for 7030 19.5 8.8



C7000AF ---




C7003AF ---



C7053CF ---



C7053BF ---

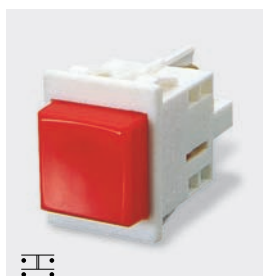

C7050SA ---



C7053AG ---



C7053DF ---



C7030AH ---

push
switches





BODY	OPTIONS
Panel cut-outs F H G Body types fit either cut-out A Cut-outs must be punched in the direction of insertion	Finish Matt finish is standard on bodies Gloss finish is standard on actuators Color Call factory for custom colors A full range is available for large orders Legend printing A wide range is available or call the factory for custom legends Lamp voltage Call factory for details of other available voltages Weatherproof housing (E) Additional housing which fits round body switches with an oversize housing with a clear silicone cover designed to IP65. Mounting hole dia: 38.0mm

DIMENSIONS (mm)

Panel thickness:

A 0.8 - 2.5mm

F, G, H 0.8 - 5.0mm

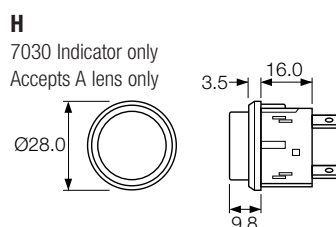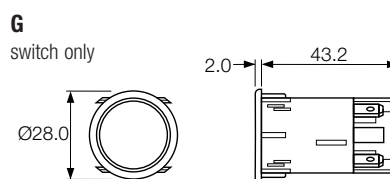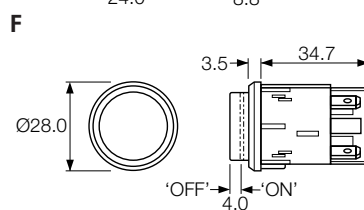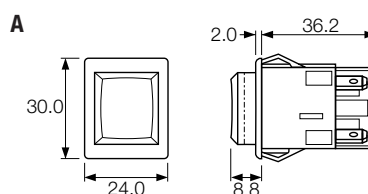

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[C7001AFBR](#) [C7001AGBW](#) [C7003AFBR3](#) [C7003AGBG2](#) [C7050AFBB](#) [C7051AFBR](#) [C7053AFBG2](#) [C7053AFBR2](#)
[C7003AFBR7](#) [C7050AFBR](#) [C7000AFBB](#) [C7001AGBB](#) [C7001AFBB](#) [C7030AHBA7](#) [C7003AFBG7](#) [C7003AFBR2](#)
[C7003AFBG2](#) [C7003AFBA2](#)