

916 - 920 Push Button Switches 0.5A 250Vac

In house test

0.5A 250Vac T85

RoHS

RoHS compliant

μ contact gap.

Technical data on pages 4 & 5.

- ▶ Self wiping contacts
- ▶ Slow make & break
- ▶ Momentary action
- ▶ Choice of switch circuits
- ▶ Choice of actuators



L **B** BLACK (for S or L actuator)
S **R** RED (for S or L actuator)
V Blank (for Stainless steel V actuator)

ORDER FORMAT

T 916 S B


TERMINAL CODE FUNCTION CODE ACTUATOR CODE ACTUATOR COLOR

push
switches

▶ TERMINAL	▶ FUNCTION	▶ ACTUATOR	▶ BODY	▶ OPTIONS
T 	916 Black base SP ON-OFF (momentary ON)	S Small Actuator 	Panel Cut-out (L & S Actuators) Panel thickness Both nuts - 2.5mm No backnut - 4.0mm	Finish Gloss finish only Color Call factory for custom colors A full range is available for large orders
	917 50V only Brown base SP ON-ON (momentary 1 side)	L Large Actuator 		
	918 White base SP ON-OFF (momentary OFF)	V Vandal Resistant IP66 Flat top Stainless steel 		
	919 Black base SP ON-ON (momentary 1 side)		Panel Cut-out (Stainless Steel V Actuator) Panel thickness - 8.0mm	
	920 White base DP ON-OFF (momentary ON)			


Dimensions (mm)

Nylon S and L actuators

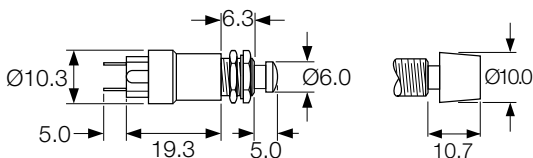

Neck thread - 40 TPI Whit. Actuator travel - 2.5 max

Stainless steel V actuator (IP66)

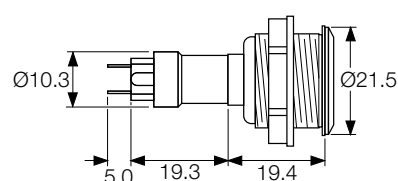

Neck thread - 26 TPI Whit. Actuator travel - 2.5 max

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[T916SB](#) [T916SR](#) [T920SB](#)