

380 Vandal Resistant Switches - Designed to IP66



16(4)A 250Vac T85



16A 125/250Vac 3/4hp T85 50E3

125V 1/2 HP, 250V 3/4 HP, 0.4A 125Vdc, 0.2A 250Vdc



RoHS compliant

Approvals apply to switch mechanism only.
μ contact gap.
Switching mechanisms are snap action (not sealed).

 
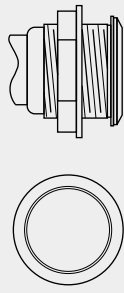
 
- ▶ Snap action switches
- ▶ Ratings up to 16A, 250Vac
- ▶ Stainless steel button and bezel
- ▶ Front panel sealed to IP66
- ▶ Single pole C/O switch



383 2510V

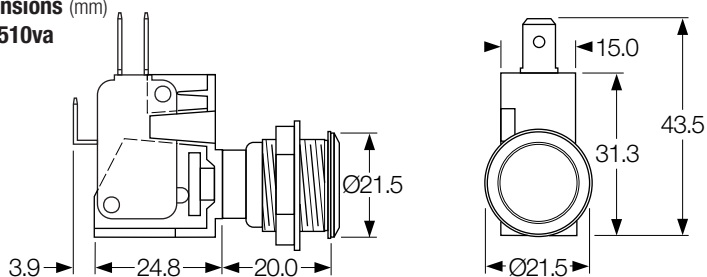
ORDER FORMAT

383 2510 V
TERMINAL FUNCTION ACTUATOR

▶ TERMINAL	▶ FUNCTION	▶ ACTUATOR	▶ BODY
383 	2510  ON - ON (momentary 1 side)	V Flat top (stainless steel) 	Stainless Steel Chamfer profile bezel  Panel cut-out Ø19.2 Panel thickness up to 8.0mm
385			
382			

Dimensions (mm)

3832510va



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[3832510V](#)