


PXM0608NSANBK4868 Datasheet

Product Name // Black Anodised Transversely Sealed Aluminium Inline Plug Connector - Cable Entry: 4.82-6.85mm

 [View Product Page](#)

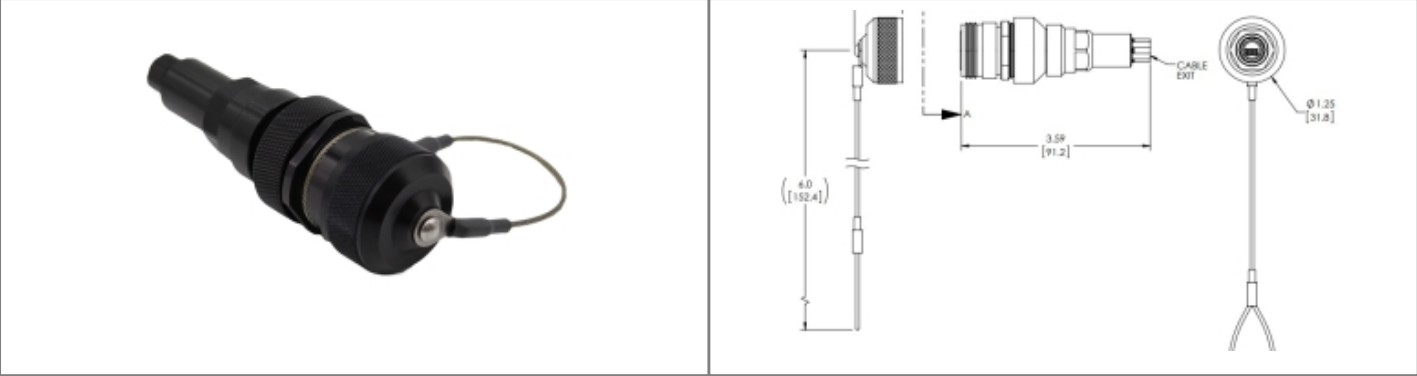

// **Product Description:**

- Black Anodised Transversely Sealed Aluminium Inline Plug Connector - Cable Entry: 4.82-6.85mm
- Comes with Cap and grounding shield
- IP68 rated even without a mate or dust Cap
- Crimp Terminals
- Durability >500 cycles
- Operating temperature -40°C to +100°C
- Supports 10, 100 and 1,000 Mbps data transmissions
- POE, POE+, and POE++
- Hardware: Stainless Steel, Seals: Silicone, Lanyard: Stainless Steel (Nylon coated)

// **General Information:**

Product Display Title:	Black Anodised Transversely Sealed Aluminium Inline Plug Connector - Cable Entry: 4.82-6.85mm
Product Family:	Circular Data Connectors
Product Series:	600 Series - Ethernet Buccaneer Connectors
Body Colour:	Black
Body Length:	91.2mm
Body Material:	Aluminium
Body Material Type:	Metal Body
Connection Method:	Standard RJ45 cable to be sourced
Contact Type:	Female
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	35mm
Durability:	>500 cycles
Ethernet Category:	Any
Function:	Inline Plug Connector
Ip Rating:	IP68
Material Finish:	Anodised
Max Cable Entry Size:	6.88mm
Min Cable Entry Size:	4.83mm
Min Operating Temperature:	-40°C
Operating Humidity:	43°C - 98%
Max Operating Frequency:	+100°C
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	500hr
Shock Resistance:	100G - 6ms

// **Product PDF Links**



// **Product 3D CAD Model Links**



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[PXM0608NSANBK4868](#)