


# PXM06285FANBKUS Datasheet

 [View Product Page](#)

**Product Name // Black Anodised Transversely Sealed Aluminium Flange Mount Connector - Unshielded - Cat5e Female**

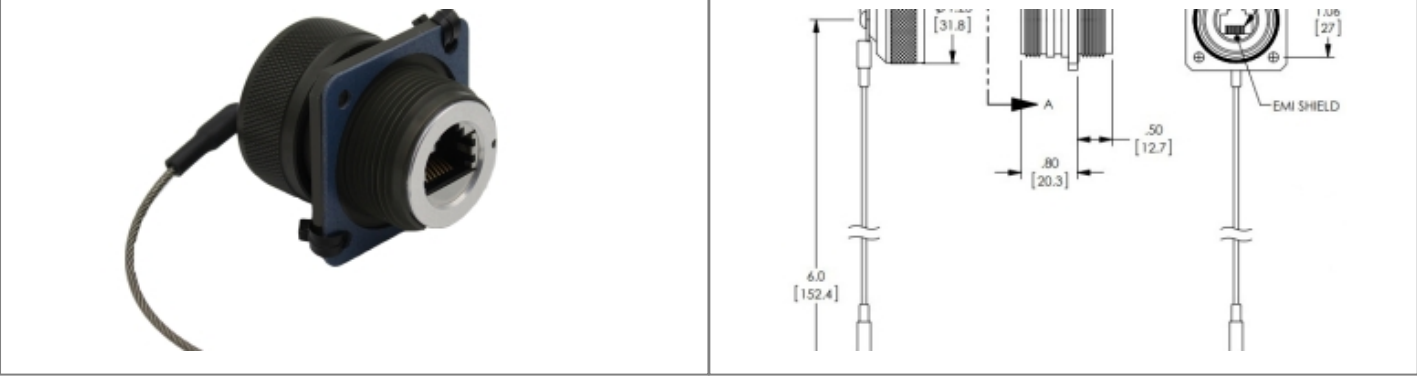

### // Product Description:

- Black Anodised Transversely Sealed Aluminium Flange Mount Connector - Unshielded - Cat5e Female
  - IP68 rated even without a mate or dust Cap
  - Crimp Terminals
  - Durability >500 cycles
- Operating temperature -40°C to +100°C
  - Supports 10, 100 and 1,000 Mbps data transmissions
  - POE, POE+, and POE++
  - Hardware: Stainless Steel, Seals: Silicone, Lanyard: Stainless Steel (Nylon coated)

### // General Information:

Product Display Title:	Black Anodised Transversely Sealed Aluminium Flange Mount Connector - Unshielded - Cat5e Female
Product Family:	Circular Data Connectors
Product Series:	600 Series - Ethernet Buccaneer Connectors
Body Colour:	Black
Body Length:	33mm
Body Material:	Aluminium
Body Material Type:	Metal Body
Connection Method:	Latching
Contact Type:	Female
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	35mm
Durability:	>500 cycles
Ethernet Category:	Cat 5e
Flange Mount Length:	36.6mm
Function:	Flange Mount Connector
Ip Rating:	IP68
Material Finish:	Anodised
Min Operating Temperature:	-40°C
Mount Hole Distance:	27mm
Operating Humidity:	43°C - 98%
Max Operating Frequency:	+100°C
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	500hr
Shock Resistance:	100G - 6ms

#### // Product PDF Links

 [Standard Series USB connectors...](#)

#### // Product 3D CAD Model Links

 [PXM06285FANBKUS3D CAD Model](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[PXM06285FANBKUS](#)