


PXM0609NSANBK6883 Datasheet

 [View Product Page](#)

Product Name // Black Anodised Aluminium Plug
Connector - Cable Entry: 6.88-8.38mm

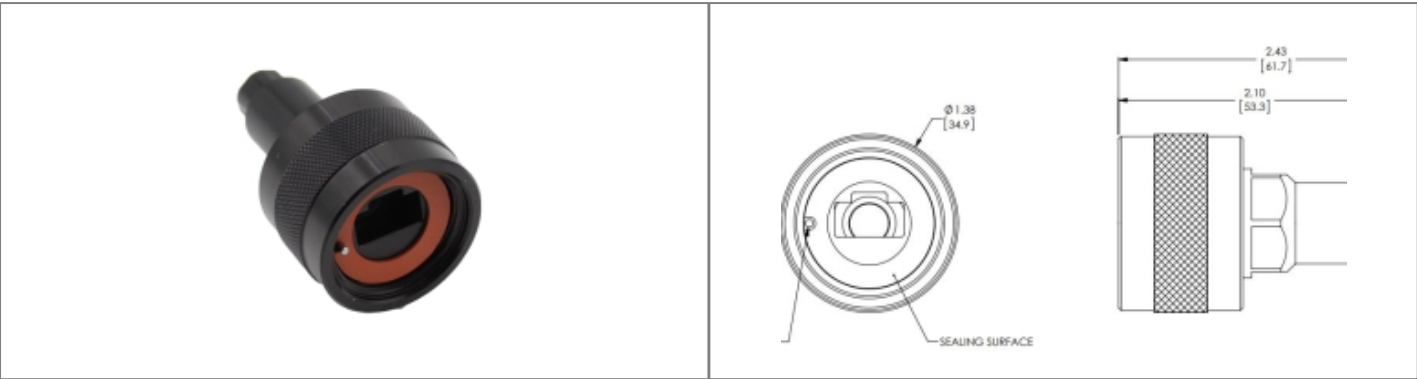

// **Product Description:**

- Black Anodised Aluminium Plug Connector - Cable Entry: 6.88-8.38mm
 - IP68 rated when mated
 - Crimp Terminals
 - Durability >500 cycles
- Operating temperature -40°C to +100°C
 - Supports 10, 100 and 1,000 Mbps data transmissions
 - POE, POE+, and POE++
 - Hardware: Stainless Steel, Seals: Silicone

// **General Information:**

Product Display Title:	Black Anodised Aluminium Plug Connector - Cable Entry: 6.88-8.38mm
Product Family:	Circular Data Connectors
Product Series:	600 Series - Ethernet Buccaneer Connectors
Body Colour:	Black
Body Length:	61.7mm
Body Material:	Aluminium
Body Material Type:	Metal Body
Connection Method:	Standard RJ45 cable to be sourced
Contact Type:	Male
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	35mm
Durability:	>500 cycles
Ethernet Category:	Any
Function:	Plug Connector
Ip Rating:	IP68
Material Finish:	Anodised
Max Cable Entry Size:	8.38mm
Min Cable Entry Size:	6.88mm
Min Operating Temperature:	-40°C
Operating Humidity:	43°C - 98%
Max Operating Frequency:	+100°C
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	500hr
Shock Resistance:	100G - 6ms

// **Product PDF Links**



// **Product 3D CAD Model Links**



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[PXM0609NSANBK6883](#)