


PXM06006MENBK4868 Datasheet

Product Name // Black Electroless Nickel Aluminium Plug Connector with Cap - Cable Entry: 4.82-6.85mm - Cat6a Male

 [View Product Page](#)

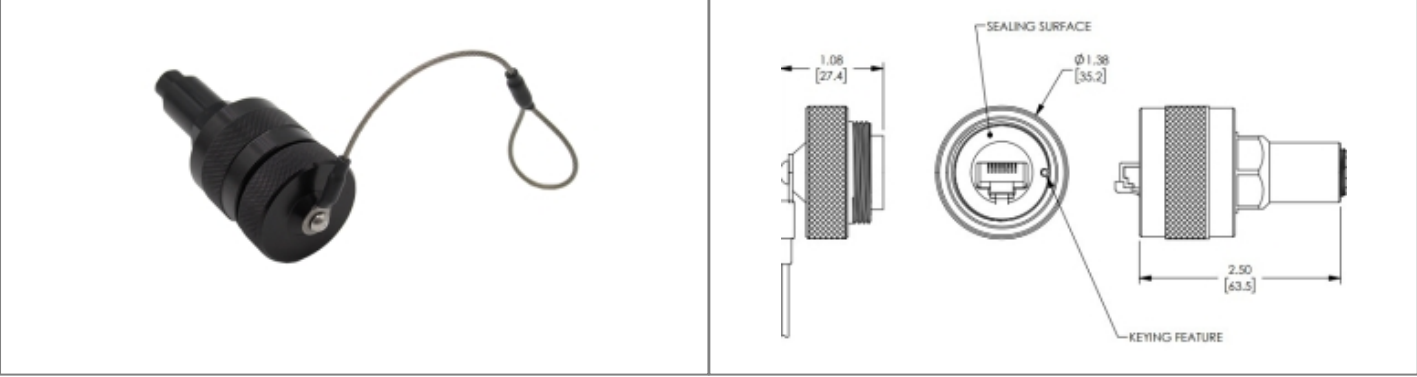

// Product Description:

- Black Electroless Nickel Aluminium Plug Connector with Cap - Cable Entry: 4.82-6.85mm - Cat6a Male
 - IP68 rated when mated
 - Crimp Terminals
 - Durability >500 cycles
- Operating temperature -40°C to +100°C
 - Supports 10, 100 and 1,000 Mbps data transmissions
 - POE, POE+, and POE++
 - Hardware: Stainless Steel, Seals: Silicone, Lanyard: Stainless Steel (Nylon coated & 6.0" length)

// General Information:

Product Display Title:	Black Electroless Nickel Aluminium Plug Connector with Cap - Cable Entry: 4.82-6.85mm - Cat6a Male
Product Family:	Circular Data Connectors
Product Series:	600 Series - Ethernet Buccaneer Connectors
Body Colour:	Black
Body Length:	61.7mm
Body Material:	Aluminium
Body Material Type:	Metal Body
Connection Method:	Crimp
Contact Type:	Male
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	35mm
Durability:	>500 cycles
Ethernet Category:	Cat 6a
Function:	Plug Connector
Ip Rating:	IP68
Material Finish:	Electroless Nickel
Max Cable Entry Size:	6.88mm
Min Cable Entry Size:	4.83mm
Min Operating Temperature:	-40°C
Operating Humidity:	43°C - 98%
Max Operating Frequency:	+100°C
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	500hr
Shock Resistance:	100G - 6ms

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[PXM06006MENBK4868](#)