


# PX0840/AA/3M00 Datasheet

 [View Product Page](#)

**Product Name // Overmoulded USB 2.0 Cable PX0840**  
**Series USB Standard A Plug to Sealed A Plug 3m Cable**

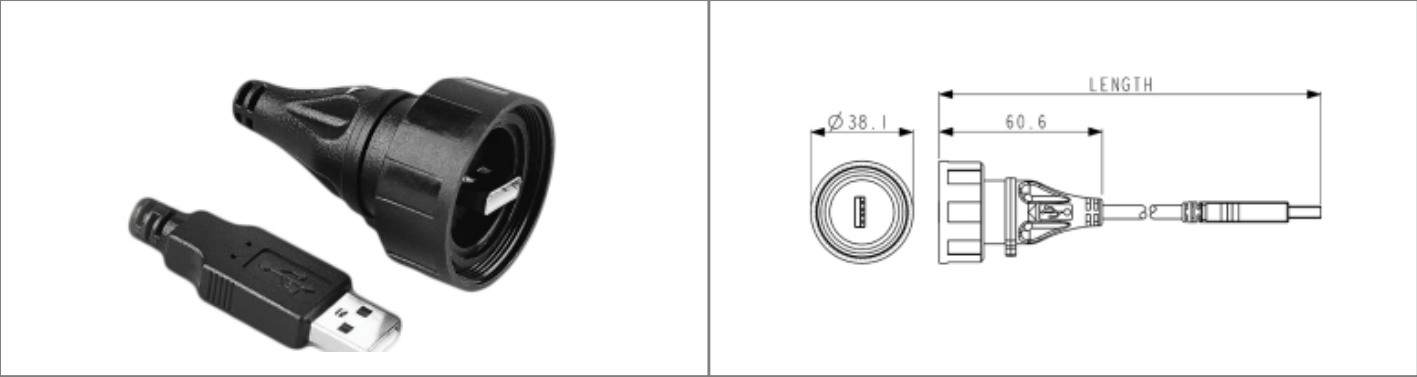

## // Product Description:

- Pre-Wired Overmoulded USB 2.0 Cable
- Water and dustproof to IP68 when mated with compatible connector
- Standard USB 2.0 Type A plug to Sealed Standard USB 2.0 Type A plug
- 3m Cable Length
- PX0835 Sealing Cap available separately to maintain IP rating of unmated connectors
- Mate with PX08 Standard USB 2.0 Series Panel Mount Connectors

## // General Information:

Product Display Title:	Pre-Wired Overmoulded USB 2.0 Cable
Product Family:	Circular Data Connectors
Product Series:	Standard Buccaneer - USB
Body Colour:	Black
Body Material:	PVC
Cable Length:	3m
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	1A
Data Cable Type:	USB 2.0 Standard A Plug to Sealed A Plug
Diameter Over Coupling Ring Mm:	38.1mm
Flamability Rating:	UL94V-0
Function:	Flex to Standard Connector Double Ended Cable
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	0°C
Number Of Contacts:	4 Contacts
Rohs Compliant:	Yes
Voltage Max:	5V

### // Product PDF Links



### // Product 3D CAD Model Links



Have a question or project enquiry  
you'd like to talk to us about?



[Click Here To Contact Us](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bulgin:](#)

[PX0840/AA/3M00](#)