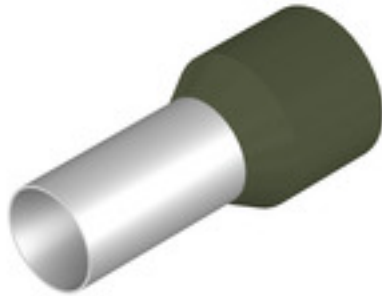


H50,0/36 OLIV**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Standard, 26 mm, 20 mm, Olive green
Order No.	0444200000
Type	H50,0/36 OLIV
GTIN (EAN)	4008 1901 10284
Qty.	50 pc(s).
Packaging	loose

Creation date January 15, 2022 7:02:51 AM CET

Catalogue status 17.12.2021 / We reserve the right to make technical changes.

H50,0/36 OLIV**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	2.8 g
------------	-------

Technical data

Description of article	Wire end ferrule with plastic collar, olive green	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	15 mm	Colour code	Weidmüller
Conductor cross-section	50 mm ²	Contact surface diameter (D1)	10.3 mm
Contact surface length (L2)	20 mm	L1 in mm	36 mm
Metal sleeve thickness (S1)	0.3 mm	Plastic collar thickness (S2)	0.5 mm
Stripping length	26 mm	Wire connection cross section AWG, max.	AWG 1

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Catalogues	Catalogues in PDF-format
Brochures	

H50,0/36 OLIV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[0444200000](#)