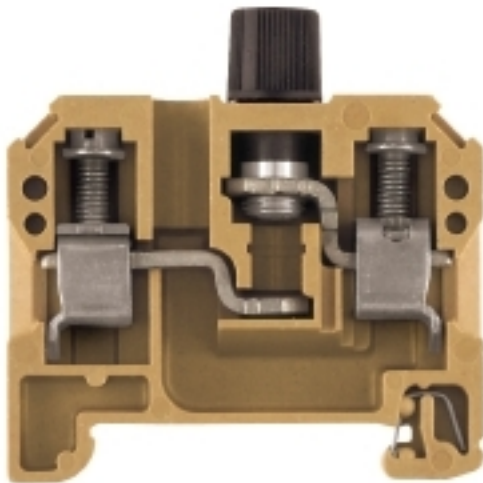


SAKS 1/35/G25 DB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image**

Similar to illustration

Klippon® Connect with clamping yoke Technology

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

General ordering data

Version	SAK Series, Fuse terminal, Rated cross-section: 10 mm ² , Screw connection, dark beige, Direct mounting
Order No.	0501500000
Type	SAKS 1/35/G25 DB
GTIN (EAN)	4008190200367
Qty.	20 pc(s).

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	53 mm	Depth (inches)	2.087 inch
Height	54 mm	Height (inches)	2.126 inch
Width	13 mm	Width (inches)	0.512 inch
Net weight	38.8 g		

Temperatures

Storage temperature	-25 °C...55 °C	Continuous operating temp., min.	-60 °C
Continuous operating temp., max.	130 °C		

Material data

Material	KrG	Colour	dark beige
UL 94 flammability rating	V-0, 5VA		

System specifications

Version	Screw connection, Fuse cartridge, One end without connector	End cover plate required	Yes
Number of potentials	1	Number of levels	1
Number of clamping points per level	2	Number of potentials per tier	1
Levels cross-connected internally	No	PE connection	No
Rail	TS 35	N-function	No
PE function	No	PEN function	No

Additional technical data

Explosion-tested version	No	Installation advice	Direct mounting
Number of similar terminals	1	Open sides	right
Type of mounting	Snap-on		

CSA rating data

Certificate No. (CSA)	12400-198	Current size C (CSA)	10 A
Voltage size C (CSA)	600 V	Wire cross section max. (CSA)	10 AWG
Wire cross section min. (CSA)	26 AWG		

Conductors for clamping (additional connection)

Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max.	10 mm ²
---	--------------------

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Conductors for clamping (rated connection)

Blade size	1.0 x 5.5 mm	Clamping range, max.	16 mm ²
Clamping range, min.	0.13 mm ²	Clamping screw	M 4
Connection cross-section, stranded, max.	10 mm ²	Connection cross-section, stranded, min.	1.5 mm ²
Connection direction	on side	Gauge to IEC 60947-1	B6
Number of connections	2	Stripping length	12 mm
Tightening torque, max.	2.4 Nm	Tightening torque, min.	1.2 Nm
Torque level with DMS electric screwdriver	4	Type of connection	Screw connection
Wire connection cross section AWG, max.	AWG 10	Wire connection cross section AWG, min.	AWG 26
Wire connection cross section, finely stranded, max.	10 mm ²	Wire connection cross section, finely stranded, min.	0.5 mm ²
Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max.	10 mm ²	Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min.	0.5 mm ²
Wire connection cross-section, solid core, max.	16 mm ²	Wire connection cross-section, solid core, min.	0.5 mm ²

Display element

Operating voltage for display, max.	500 V	Type of voltage for indicator	AC/DC
-------------------------------------	-------	-------------------------------	-------

Fuse terminals

Cartridge fuse	G-Si. 5 x 25	Display	Neon lamp
Fuse holder (cartridge holder)	for screw fixing	Operating voltage, max.	500 V
Type of voltage for indicator	AC/DC		

General

Installation advice	Direct mounting	Rail	TS 35
Wire connection cross section AWG, max.	AWG 10	Wire connection cross section AWG, min.	AWG 26

Rating data

Rated cross-section	10 mm ²	Rated voltage	500 V
Rated current	10 A	Current at maximum wires	10 A
Volume resistance according to IEC 60947-7-x	0.56 mΩ	Rated impulse withstand voltage	6 kV
Power loss in accordance with IEC 60947-7-x	1.82 W	Pollution severity	3

UL rating data

Certificate No. (UR)	E60693	Conductor size Factory wiring max. (UR)	8 AWG
Conductor size Factory wiring min. (UR)	26 AWG	Conductor size Field wiring max. (UR)	10 AWG
Conductor size Field wiring min. (UR)	22 AWG	Current size C (UR)	6.3 A
Voltage size C (UR)	600 V		

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Classifications

ETIM 6.0	EC000899	ETIM 7.0	EC000899
ETIM 8.0	EC000899	ECLASS 9.0	27-14-11-16
ECLASS 9.1	27-14-11-16	ECLASS 10.0	27-14-11-16
ECLASS 11.0	27-14-11-16		

Approvals

Approvals



ROHS Conform

UL File Number Search E60693

Downloads

Approval/Certificate/Document of Conformity	EAC certificate Lloyds Register Certificate MARITREG Certificate
User Documentation	StorageConditionsTerminalBlocks
Catalogues	Catalogues in PDF-format

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

SAK-Series



A partition plate is used for the optical separation of circuits or used for electrical isolation from neighbouring cross-connectors. In contrast to the end plate, the contour can be larger than the adjacent terminal blocks. However, it should not be smaller, as otherwise the required clearance and creepage distances within the application can no longer be maintained.

General ordering data

Type	TW SAK16 KRG	Version
Order No.	0281120000	SAK Series, Partition plate, 3 mm, dark beige, yellow, Used between
GTIN (EAN)	4008190072360	terminals, Direct mounting
Qty.	20 pc(s).	
Type	TW 4 SAK4-10	Version
Order No.	0130160000	SAK Series, Partition plate, 1.5 mm, beige
GTIN (EAN)	4008190096335	
Qty.	20 pc(s).	
Type	TSCH 3 SAKD2.5 N	Version
Order No.	0366860000	SAK Series, Small partition, beige, 5 mm
GTIN (EAN)	4008190010928	
Qty.	100 pc(s).	
Type	TSCH 4 AKZ4	Version
Order No.	0363360000	SAK Series, Small partition, beige, 6 mm
GTIN (EAN)	4008190136680	
Qty.	100 pc(s).	
Type	TW DK4 HP/DBR/2	Version
Order No.	3833500000	SAK Series, Partition plate, 2 mm, dark brown, Direct mounting
GTIN (EAN)	4008190009052	
Qty.	20 pc(s).	
Type	TSCH 1	Version
Order No.	0319160000	SAK Series, Small partition, beige, 2 mm
GTIN (EAN)	4008190097219	
Qty.	100 pc(s).	
Type	TW AST1/PA HP/DBR/0.5	Version
Order No.	0474700000	SAK Series, Partition plate, 0.5 mm, dark brown
GTIN (EAN)	4008190078508	
Qty.	20 pc(s).	
Type	TSCH 6 DKI S4	Version
Order No.	0190260000	SAK Series, Small partition, beige, 5 mm
GTIN (EAN)	4008190051075	
Qty.	100 pc(s).	
Type	TW SAK4-10 HP/DBR/0.5	Version
Order No.	0197100000	SAK Series, Partition plate, 0.5 mm, brown, dark beige, Direct
GTIN (EAN)	4008190146627	mounting
Qty.	20 pc(s).	
Type	TSCH 2	Version
Order No.	0353660000	SAK Series, Small partition, beige, 0.6 mm
GTIN (EAN)	4008190128432	
Qty.	100 pc(s).	

Creation date January 15, 2022 3:55:32 PM CET

Catalogue status 17.12.2021 / We reserve the right to make technical changes.

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	TW SAK4-10 KRG	Version
Order No.	0130120000	SAK Series, Partition plate, 2.25 mm, dark beige, yellow, Direct
GTIN (EAN)	4008190139117	mounting
Qty.	20 pc(s).	
Type	TW 4 SAK4-10 BL	Version
Order No.	0130180000	SAK Series, Partition plate, 1.5 mm, blue
GTIN (EAN)	4008190114138	
Qty.	20 pc(s).	
Type	TW SAK4-10 KRG/BL	Version
Order No.	0130170000	SAK Series, Partition plate, 2.25 mm, blue, Direct mounting
GTIN (EAN)	4008190063757	
Qty.	20 pc(s).	
Type	TW SAKS2 HP/DBR/2	Version
Order No.	0607000000	SAK Series, Partition plate, 2 mm, dark brown, Used between
GTIN (EAN)	4008190002732	terminals
Qty.	20 pc(s).	

Connection sleeves



General ordering data

Type	VH 13.6/7/4.2 SAKA10	Version
Order No.	0299700000	SAK Series, Connecting sleeve, for cross-connection link, Number of
GTIN (EAN)	4008190018313	poles:
Qty.	50 pc(s).	
Type	VH 19/5/3.5 SAK4-16	Version
Order No.	0285100000	SAK Series, Connecting sleeve, for cross-connection link, Number of
GTIN (EAN)	4008190189297	poles: 1
Qty.	50 pc(s).	
Type	VH 12/4.9/3.3 SAK6N	Version
Order No.	0249000000	SAK Series, Connecting sleeve, for cross-connection link, Number of
GTIN (EAN)	4008190129507	poles:
Qty.	100 pc(s).	
Type	VH 17.5/5/3.5 SAK6N-16	Version
Order No.	0285200000	SAK Series, Connecting sleeve, for cross-connection link, Number of
GTIN (EAN)	4008190054717	poles:
Qty.	50 pc(s).	
Type	VH 23/6/4.2 SAKA10	Version
Order No.	0348700000	SAK Series, Connecting sleeve, for cross-connection link, Number of
GTIN (EAN)	4008190185923	poles: 1
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Steel



Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

General ordering data

Type	TS 32X15/LL 2M/ST/ZN	Version
Order No.	0514400000	Rail, TS 32, with slot, Steel, galvanic zinc plated and passivated
GTIN (EAN)	4008190086152	
Qty.	2 m	

QL / SAKH 10



Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data

Type	QL 3 SAKH10	Version
Order No.	0131500000	SAK Series, Cross-connector, for cross-connection link, Number of poles: 3
GTIN (EAN)	4008190056490	
Qty.	50 pc(s).	
Type	QL 2 SAKH10	Version
Order No.	0131400000	SAK Series, Cross-connector, for cross-connection link, Number of poles: 2
GTIN (EAN)	4008190114237	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

W-Series



A partition plate is used for the optical separation of circuits or used for electrical isolation from neighbouring cross-connectors. In contrast to the end plate, the contour can be larger than the adjacent terminal blocks. However, it should not be smaller, as otherwise the required clearance and creepage distances within the application can no longer be maintained.

General ordering data

Type	WTW EN	Version
Order No.	1058800000	W-Series, Partition plate
GTIN (EAN)	4008190140175	
Qty.	20 pc(s).	

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/6.5 MC NE WS	Version
Order No.	1609840000	Dekafix, Terminal marker, 5 x 6.5 mm, Pitch in mm (P): 6.50
GTIN (EAN)	4008190203429	Weidmueller, white
Qty.	900 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Gauge rings



Gauge rings are used to protect against the using of incorrectly selected fuse sizes. They are simply inserted into the respective fuse base and prevent the using of bigger fuses.

General ordering data

Type	P 14/6 D01 GN SAKS4	Version
Order No.	0328600000	Accessories, Gauge ring (automatic circuit breaker), 6 A
GTIN (EAN)	4008190004248	
Qty.	50 pc(s).	
Type	P 14/10 D01 RT SAKS4	Version
Order No.	0328700000	Accessories, Gauge ring (automatic circuit breaker), 10 A
GTIN (EAN)	4008190010294	
Qty.	50 pc(s).	
Type	P 14/4 D01 BR SAKS4	Version
Order No.	0138100000	Accessories, Gauge ring (automatic circuit breaker), 4 A
GTIN (EAN)	4008190077365	
Qty.	50 pc(s).	
Type	P 14/2 D01 RS SAKS4	Version
Order No.	0138000000	Accessories, Gauge ring (automatic circuit breaker), 2 A
GTIN (EAN)	4008190114664	
Qty.	50 pc(s).	

Insulation caps



With our accessories for the bus bar taps, you can quickly and easily insulate the tap terminals and visualize the potential through the color coding.

General ordering data

Type	IK 4 BL ZB4	Version
Order No.	0475480000	Accessories, Special terminal, Rated cross-section: PA, blue, Busbar
GTIN (EAN)	4008190145668	
Qty.	50 pc(s).	
Type	IK 16/ZB16 BL	Version
Order No.	0502980000	Accessories, Special terminal, Rated cross-section: PA, blue, Busbar
GTIN (EAN)	4008190159696	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	IK 4 GG ZB4	Version
Order No.	0475460000	Accessories, Special terminal, Rated cross-section: PA, Green/yellow,
GTIN (EAN)	4008190065348	Busbar
Qty.	50 pc(s).	
Type	IK 16/ZB16 GG	Version
Order No.	0502960000	Accessories, Special terminal, Rated cross-section: PA, Green/yellow
GTIN (EAN)	4008190113438	
Qty.	50 pc(s).	
Type	IK 35/ZB35 BL	Version
Order No.	0502780000	Accessories, Special terminal, Rated cross-section: PA, blue, Busbar
GTIN (EAN)	4008190141455	
Qty.	50 pc(s).	
Type	IK 6 GG ZBE6K	Version
Order No.	0526060000	Accessories, Special terminal, Rated cross-section: PA, Green/yellow,
GTIN (EAN)	4008190128647	Busbar
Qty.	50 pc(s).	

DEK 5/8



WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

General ordering data

Type	DEK 5/8 MM WS	Version
Order No.	2007130000	Dekafix, Terminal marker, 5 x 8 mm, Weidmueller, white
GTIN (EAN)	4050118392012	
Qty.	500 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cover profiles



Cover profiles provide protection against external impact on functional areas of the terminal blocks or in combination with our support brackets for the entire terminal strip. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

General ordering data

Type	ADP 2/HP2 1M	Version
Order No.	0485300000	SAK Series, Cover profile, Transparent, 1000 mm
GTIN (EAN)	4008190051716	
Qty.	1 m	

DEK 5/6



WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

General ordering data

Type	DEK 5/6 MM WS	Version
Order No.	2007120000	Dekafix, Terminal marker, 5 x 6 mm, Weidmueller, white
GTIN (EAN)	4050118392104	
Qty.	600 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Q / SAK



Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data

Type	Q 10 SAK10	Version
Order No.	0457400000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190016166	poles: 10
Qty.	20 pc(s).	
Type	Q 4 SAK10	Version
Order No.	0457300000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190129750	poles: 4
Qty.	50 pc(s).	
Type	Q 2 SAK10	Version
Order No.	0457100000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190103545	poles: 2
Qty.	50 pc(s).	
Type	Q 3 SAK10	Version
Order No.	0457200000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190135379	poles: 3
Qty.	50 pc(s).	

SAK-Series



Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

Type	EW 35	Version
Order No.	0383560000	Accessories, End bracket
GTIN (EAN)	4008190181314	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Test plugs

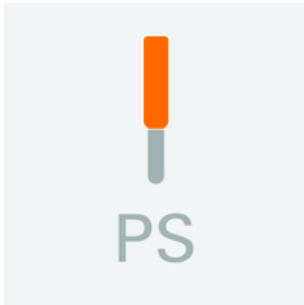


Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

Type	PS 4 F.STB 4	Version
Order No.	0299600000	Accessories, Test plug
GTIN (EAN)	4008190074043	
Qty.	20 pc(s).	
Type	PS 2.0 OR	Version
Order No.	0293800000	Accessories, Test plug
GTIN (EAN)	4008190042356	
Qty.	20 pc(s).	
Type	ZS 2.3/4	Version
Order No.	0249600000	Accessories, Adapter plug
GTIN (EAN)	4008190022785	
Qty.	20 pc(s).	
Type	FZS 2/4 RT/80 SAKT4	Version
Order No.	1276300000	Accessories, Adapter plug
GTIN (EAN)	4008190026080	
Qty.	20 pc(s).	
Type	PS 2.3 RT	Version
Order No.	0180400000	Accessories, Test plug
GTIN (EAN)	4008190060121	
Qty.	20 pc(s).	

E 14

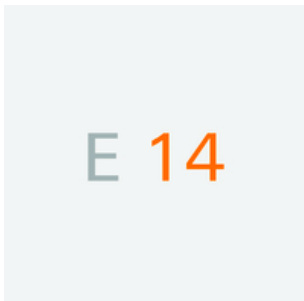

Weidmueller offers NEOZED fuses in E 14 design in sizes from 2 A to 16 A.

General ordering data

Type	E 14/2A RS	Version
Order No.	0137400000	Active components, Cartridge fuse
GTIN (EAN)	4008190069094	
Qty.	10 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	E 14/16A GR	Version
Order No.	0328500000	Active components, Cartridge fuse
GTIN (EAN)	4008190152161	
Qty.	10 pc(s).	
Type	E 14/10A RT	Version
Order No.	0328400000	Active components, Cartridge fuse
GTIN (EAN)	4008190000288	
Qty.	10 pc(s).	
Type	E 14/4A BR	Version
Order No.	0137500000	Active components, Cartridge fuse
GTIN (EAN)	4008190142629	
Qty.	10 pc(s).	
Type	E 14/6A GN	Version
Order No.	0328300000	Active components, Cartridge fuse
GTIN (EAN)	4008190002190	
Qty.	10 pc(s).	

Insulated



Bus bar taps with insulation offer finger safety on the one hand. On the other hand, the colored insulation also indicates the respective potential, such as the neutral conductor or PE.

General ordering data

Type	ZB 16K SW	Version
Order No.	0502810000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, black, Feed-through (bushing)
GTIN (EAN)	4008190332563	
Qty.	50 pc(s).	
Type	ZBE 6K SW	Version
Order No.	0525910000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, black, Busbar, Direct mounting
GTIN (EAN)	4008190977054	
Qty.	50 pc(s).	
Type	ZB 4K GG HENSEL	Version
Order No.	1824560000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Green/yellow, Feed-through (bushing)
GTIN (EAN)	4032248330973	
Qty.	50 pc(s).	
Type	ZB 4G GN/GE	Version
Order No.	0322160000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Green/yellow, Feed-through (bushing)
GTIN (EAN)	4008190014278	
Qty.	50 pc(s).	
Type	ZB 4/6K BL	Version
Order No.	0565480000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, blue, Feed-through (bushing)
GTIN (EAN)	4008190086831	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	ZBE 6K BL	Version
Order No.	0525980000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190060886	yoke, PA, blue, Busbar, Direct mounting
Qty.	50 pc(s).	
Type	ZB 4K SW	Version
Order No.	0475310000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190008406	yoke, PA, Feed-through (bushing)
Qty.	50 pc(s).	
Type	ZB 16K GE/GN	Version
Order No.	0502860000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190188795	yoke, PA, Green/yellow, Feed-through (bushing)
Qty.	50 pc(s).	
Type	ZB 35K BL M6X16	Version
Order No.	0502680000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190004385	yoke, PA, blue, Feed-through (bushing)
Qty.	20 pc(s).	
Type	ZB 4G SW	Version
Order No.	0322110000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190189310	yoke, PA, black, Feed-through (bushing)
Qty.	50 pc(s).	
Type	ZBE 6K GE/GN	Version
Order No.	0525960000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190145026	yoke, PA, Green/yellow, Busbar, Direct mounting
Qty.	50 pc(s).	
Type	ZB 4K BL	Version
Order No.	0475380000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190010942	yoke, PA, blue, Feed-through (bushing)
Qty.	50 pc(s).	
Type	ZB 35K GE/GN M6X16	Version
Order No.	0502660000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190052294	yoke, PA, Green/yellow, Feed-through (bushing)
Qty.	20 pc(s).	
Type	ZB 16K BL	Version
Order No.	0502880000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190014186	yoke, PA, blue, Feed-through (bushing)
Qty.	50 pc(s).	
Type	ZB 4/6K GE/GN	Version
Order No.	0565460000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190032609	yoke, PA, Green/yellow, Feed-through (bushing)
Qty.	50 pc(s).	
Type	ZB 35K SW M6X16	Version
Order No.	0502610000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190332587	yoke, PA, black, Feed-through (bushing)
Qty.	20 pc(s).	
Type	ZB 4K GE/GN	Version
Order No.	0475360000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190188047	yoke, PA, Green/yellow, Feed-through (bushing)
Qty.	50 pc(s).	
Type	ZB 4G BL	Version
Order No.	0322180000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping
GTIN (EAN)	4008190050504	yoke, PA, blue, Feed-through (bushing)
Qty.	50 pc(s).	

SAKS 1/35/G25 DB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****QL mounting screws**

Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data

Type	SS M3 D 128-A 3	Version
Order No.	0164400000	Accessories, Lock washer
GTIN (EAN)	4008190035914	
Qty.	50 pc(s).	

SAK-Series

SAK
Series

Warning covers with a flash symbol provide more safety for man and machine. They are used where external voltage must be indicated within the application.

General ordering data

Type	AD 4 SAK10	Version
Order No.	0178600000	SAK Series, cover plate, yellow, 25 mm
GTIN (EAN)	4008190068288	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

SAK-Series



End plates are fitted to the open side of the last modular terminal before the end bracket. The use of an end plate ensures the function of the modular terminal and the specified rated voltage. It guarantees protection against contact with live parts and makes the final terminal finger-proof.

General ordering data

Type	AP SAK4-10	Version
Order No.	0117960000	SAK Series, End plate, 1.5 mm, beige, Direct mounting
GTIN (EAN)	4008190081485	
Qty.	20 pc(s).	
Type	AP SAKB/C/T KRG	Version
Order No.	0146720000	SAK Series, End plate, 3 mm, dark beige, yellow, Direct mounting
GTIN (EAN)	4008190027995	
Qty.	20 pc(s).	
Type	AP SAK4-10 KRG/BL	Version
Order No.	0117970000	SAK Series, End plate, 1.5 mm, blue, Direct mounting
GTIN (EAN)	4008190049607	
Qty.	20 pc(s).	
Type	AP SAK4-10 BL	Version
Order No.	0117980000	SAK Series, End plate, 1.5 mm, blue, Direct mounting
GTIN (EAN)	4008190171087	
Qty.	20 pc(s).	
Type	AP SAK4-10 DB	Version
Order No.	0105100000	SAK Series, End plate, 1.5 mm, dark beige, Direct mounting
GTIN (EAN)	4008190394875	
Qty.	20 pc(s).	
Type	AP SAK4-10 KRG	Version
Order No.	0117920000	SAK Series, End plate, 1.5 mm, dark beige, yellow, Direct mounting
GTIN (EAN)	4008190135904	
Qty.	20 pc(s).	
Type	AP SAK35/TW SAK16	Version
Order No.	0303660000	SAK Series, End plate, 1.5 mm, beige
GTIN (EAN)	4008190110765	
Qty.	10 pc(s).	
Type	AP SAKA KRG	Version
Order No.	0134220000	SAK Series, End plate, 3 mm, dark beige, yellow, Direct mounting
GTIN (EAN)	4008190167943	
Qty.	20 pc(s).	
Type	AP SAKS1+3 KRG/DB	Version
Order No.	0191300000	SAK Series, End plate, 3 mm, dark beige, Direct mounting
GTIN (EAN)	4008190099763	
Qty.	20 pc(s).	
Type	AP SAK4-10 I	Version
Order No.	0117910000	SAK Series, End plate, 1.5 mm, Light Grey, Direct mounting
GTIN (EAN)	4008190183707	
Qty.	20 pc(s).	

Creation date January 15, 2022 3:55:32 PM CET

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	AP SAK4-10 RT	Version
Order No.	0117900000	SAK Series, End plate, 1.5 mm, red, Direct mounting
GTIN (EAN)	4008190125059	
Qty.	20 pc(s).	
Type	AP SAKS1+3 KRG	Version
Order No.	0191320000	SAK Series, End plate, 3 mm, dark beige, yellow, Direct mounting
GTIN (EAN)	4008190031688	
Qty.	20 pc(s).	
Type	AP KSKM	Version
Order No.	9509630000	SAK Series, End plate, 1.5 mm, beige, Direct mounting
GTIN (EAN)	4008190456771	
Qty.	20 pc(s).	
Type	AP SAK35/TW SAK16 BL	Version
Order No.	0303680000	SAK Series, End plate, 1.5 mm, blue
GTIN (EAN)	4008190025199	
Qty.	10 pc(s).	
Type	AP RSF1 KRG	Version
Order No.	0270420000	SAK Series, End plate, 3 mm, medium yellow, Direct mounting
GTIN (EAN)	4008190099107	
Qty.	10 pc(s).	

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/6.5 MC SDR	Version
Order No.	1609850000	Dekafix, Terminal marker, 5 x 6.5 mm, Pitch in mm (P): 6.50
GTIN (EAN)	4008190456610	Weidmueller, To customer specification
Qty.	180 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Copper

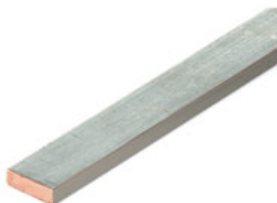

Of all the metals used, copper has the best electrical conductivity, which results in the highest short-circuit resistance. This makes the copper busbar the most widely used variant.

General ordering data

Type	SSCH 10X3X1000 CU/SN	Version
Order No.	0348900000	Accessories, Busbar, Copper
GTIN (EAN)	4008190024802	
Qty.	1 m	
Type	SSCH 15X6X1000 CU/SN	Version
Order No.	0357400000	Accessories, Busbar, Copper
GTIN (EAN)	4008190169572	
Qty.	1 m	
Type	SSCH 6X6X1000 CU/SN	Version
Order No.	0571300000	Accessories, Busbar, Copper
GTIN (EAN)	4008190015039	
Qty.	1 m	

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/6 MC SDR	Version
Order No.	1609830000	Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00
GTIN (EAN)	4008190456603	Weidmueller, To customer specification
Qty.	200 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

QL / SAKS

Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.



General ordering data

Type	QL 2 SAKS2	Version
Order No.	0207800000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190144364	poles: 2
Qty.	20 pc(s).	
Type	QL 10 SAKS4	Version
Order No.	0339000000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190025335	poles: 10
Qty.	20 pc(s).	
Type	QL 2 SAKS1	Version
Order No.	0191400000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190123130	poles: 2
Qty.	50 pc(s).	
Type	QL 2 SAKS4	Version
Order No.	0328000000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190071165	poles: 2
Qty.	20 pc(s).	
Type	QL 4 SAKS2	Version
Order No.	0208000000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190069100	poles: 4
Qty.	20 pc(s).	
Type	QL 10 SAKS2	Version
Order No.	0338900000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190105723	poles: 10
Qty.	20 pc(s).	
Type	QL 3 SAKS1	Version
Order No.	0191500000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190036881	poles: 3
Qty.	50 pc(s).	
Type	QL 4 SAKS1	Version
Order No.	0191600000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190105518	poles: 4
Qty.	20 pc(s).	
Type	QL 10 SAKS1	Version
Order No.	0338800000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190127039	poles: 10
Qty.	20 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	QL 3 SAKS4	Version
Order No.	0328100000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190097639	poles: 3
Qty.	20 pc(s).	

Mounting rail support



Mounting rail supports can be used to mount din rails at any location in the cabinet. The resulting raised or angled din rail offers the installer both easier component mounting and wiring.

General ordering data

Type	SH 2	Version
Order No.	0494920000	Accessories, Rail support, KrG
GTIN (EAN)	4008190007584	
Qty.	10 pc(s).	

Screws



Depending on the terminal block or also accessories, we offer different types of screws as additional items or also spare parts.

General ordering data

Type	BFSC M3X25	Version
Order No.	0292500000	Accessories, Mounting screw, for cross-connection link
GTIN (EAN)	4008190177027	
Qty.	100 pc(s).	
Type	KISC M3X6 SAKS1	Version
Order No.	0346200000	Clamping yoke, Mounting screw, Steel
GTIN (EAN)	4008190175658	
Qty.	100 pc(s).	
Type	BFSC M4X30	Version
Order No.	0267100000	Accessories, Mounting screw, for cross-connection link
GTIN (EAN)	4008190187897	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com

Accessories

Type	BFSC M4X9T	Version
Order No.	0103300000	Accessories, Mounting screw, for cross-connection link
GTIN (EAN)	4008190023348	
Qty.	100 pc(s).	

E 16

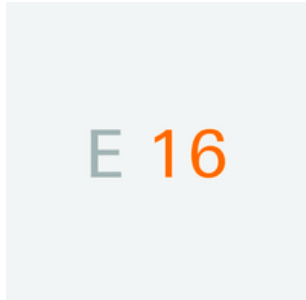


Weidmueller offers NEOZED fuses in E 16 design in sizes from 10 A to 25 A.

General ordering data

Type	E 16/16A GR TNDZ	Version
Order No.	0208600000	Active components, Cartridge fuse
GTIN (EAN)	4008190015121	
Qty.	25 pc(s).	
Type	E 16/10A RT TNDZ	Version
Order No.	0208500000	Active components, Cartridge fuse
GTIN (EAN)	4008190067120	
Qty.	25 pc(s).	
Type	E 16/25A GE TNDZ	Version
Order No.	0208800000	Active components, Cartridge fuse
GTIN (EAN)	4008190037314	
Qty.	25 pc(s).	
Type	E 16/20A BL TNDZ	Version
Order No.	0208700000	Active components, Cartridge fuse
GTIN (EAN)	4008190044886	
Qty.	25 pc(s).	

5x25

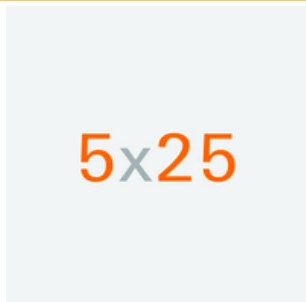

For protection against overcurrent, we offer cartridge fuse with dimensions 5x25 mm in sizes from 250 mA to 6.3 A.

General ordering data

Type	G 25/1.00A/M RT	Version
Order No.	0265800000	Active components, Fuse
GTIN (EAN)	4008190141660	
Qty.	10 pc(s).	

Creation date January 15, 2022 3:55:32 PM CET

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	G 25/4.00A/F BR	Version
Order No.	0192800000	Active components, Fuse
GTIN (EAN)	4008190115319	
Qty.	10 pc(s).	
Type	G 25/0.25A/M GE	Version
Order No.	0546900000	Active components, Fuse
GTIN (EAN)	4008190097370	
Qty.	10 pc(s).	
Type	G 25/6.30A/F GN	Version
Order No.	0192900000	Active components, Fuse
GTIN (EAN)	4008190135461	
Qty.	10 pc(s).	
Type	G 25/0.80A/M GR	Version
Order No.	0646400000	Active components, Fuse
GTIN (EAN)	4008190060794	
Qty.	10 pc(s).	
Type	G 25/10.0A/M RT	Version
Order No.	0193100000	Active components, Fuse
GTIN (EAN)	4008190023799	
Qty.	10 pc(s).	
Type	G 25/2.00A/F BL	Version
Order No.	0192700000	Active components, Fuse
GTIN (EAN)	4008190176402	
Qty.	10 pc(s).	
Type	G 25/0.50A/M WS	Version
Order No.	0510300000	Active components, Fuse
GTIN (EAN)	4008190018368	
Qty.	10 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/5 MC NE WS	Version
Order No.	1609801044	Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00
GTIN (EAN)	4008190397111	Weidmueller, white
Qty.	1,000 pc(s).	

Testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

Type	STB 18/RSF1	Version
Order No.	0286500000	SAK Series, Socket
GTIN (EAN)	4008190515591	
Qty.	20 pc(s).	

Type	STB 13.5/D6/4/M4 SAKA10	Version
Order No.	0135200000	SAK Series, Socket
GTIN (EAN)	4008190172862	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Fixing screws



Current and voltage transformer wiring

Our test disconnect terminal blocks featuring spring and screw connection technology allow you to create all the important converter circuits for measuring current, voltage and power in a safe and sophisticated way.

General ordering data

Type	KISC M3X20 SAK10 CU5	Version
Order No.	0377100000	SAK Series, Mounting screw, Steel
GTIN (EAN)	4008190060350	
Qty.	100 pc(s).	

Uninsulated



Uninsulated bus bar tap-off terminals offer a space-saving option for connecting conductors on a bus bar.

General ordering data

Type	ZB 4/6	Version
Order No.	0556700000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, Feed-through (bushing)
GTIN (EAN)	4008190188412	
Qty.	50 pc(s).	
Type	ZB 35/M6X16	Version
Order No.	0266500000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, Feed-through (bushing)
GTIN (EAN)	4008190102814	
Qty.	20 pc(s).	
Type	ZBE 6	Version
Order No.	0459500000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, Busbar, Direct mounting
GTIN (EAN)	4008190032692	
Qty.	50 pc(s).	
Type	ZB 4	Version
Order No.	0316500000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, Feed-through (bushing)
GTIN (EAN)	4008190061999	
Qty.	50 pc(s).	
Type	ZB 16 ZKSC	Version
Order No.	0316600000	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, Feed-through (bushing)
GTIN (EAN)	4008190145989	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/6 MC NE WS	Version
Order No.	1609820000	Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00
GTIN (EAN)	4008190203436	Weidmueller, white
Qty.	1,000 pc(s).	

QL / RSF1+2



Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data

Type	QL 3 RSF1+2	Version
Order No.	0267500000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190116835	poles: 3
Qty.	50 pc(s).	
Type	QL 10 RSF1+2	Version
Order No.	0341700000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190003173	poles: 10
Qty.	20 pc(s).	
Type	QL 4 RSF1+2	Version
Order No.	0267600000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190174859	poles: 4
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com

Accessories

Type	QL 2 RSF1+2	Version
Order No.	0267400000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190139988	poles: 2
Qty.	50 pc(s).	

Copper

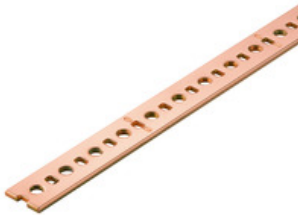

Of all the metals used, copper has the best electrical conductivity, which results in the highest short-circuit resistance. This makes the copper busbar the most widely used variant.

General ordering data

Type	NSCH 1M	Version
Order No.	0280200000	Accessories, Busbar, Copper
GTIN (EAN)	4008190012953	
Qty.	10 m	

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/8 MC NE WS	Version
Order No.	1856740000	Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00
GTIN (EAN)	4032248400850	Weidmueller, white
Qty.	800 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Steel



Steel bus bars, together with stainless steel, have the highest strength among metallic busbars and are used in applications where short-circuit resistance plays only a secondary role.

General ordering data

Type	ESCH 1 M	Version
Order No.	0280300000	Accessories, Busbar, Steel
GTIN (EAN)	4008190143053	
Qty.	1 m	

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/5 MC SDR	Version
Order No.	1609810000	Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00
GTIN (EAN)	4008190456597	Weidmueller, To customer specification
Qty.	200 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Plus



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.


- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/8 PLUS MC NE WS	Version
Order No.	1046350000	Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00
GTIN (EAN)	4032248782055	Weidmueller, white
Qty.	800 pc(s).	

TS 32

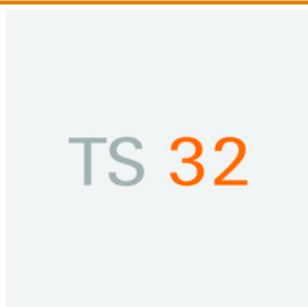

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

Type	WEW 32/1	Version
Order No.	1067600000	W-Series, End bracket
GTIN (EAN)	4008190099657	
Qty.	50 pc(s).	

Type	EWK 2	Version
Order No.	0199360000	Accessories, End bracket
GTIN (EAN)	4008190023546	
Qty.	50 pc(s).	

Type	EWK 1	Version
Order No.	0206160000	Accessories, End bracket
GTIN (EAN)	4008190080020	
Qty.	50 pc(s).	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	EWK 1 ALT	Version
Order No.	0495160000	Accessories, End bracket
GTIN (EAN)	4008190160777	
Qty.	50 pc(s).	

QL / SAKA



Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data


Type	QL 4 SAKA10	Version
Order No.	0135700000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190118822	poles: 4
Qty.	50 pc(s).	
Type	QL 2 SAKA10	Version
Order No.	0135500000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190099404	poles: 2
Qty.	50 pc(s).	
Type	QL 10 SAKA10	Version
Order No.	0338500000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190063313	poles: 10
Qty.	20 pc(s).	
Type	QL 3 SAKA10	Version
Order No.	0135600000	SAK Series, Cross-connector, for cross-connection link, Number of
GTIN (EAN)	4008190032081	poles: 3
Qty.	50 pc(s).	

SAKS 1/35/G25 DB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

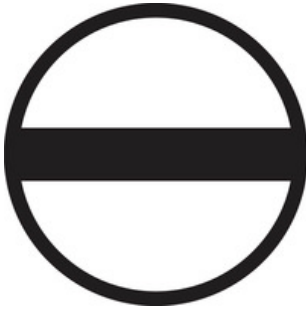www.weidmueller.com**Accessories****Slotted screwdriver**

Slotted screwdriver with rounded blade SD DIN 5265, ISO 2380/2, output to DIN 5264, ISO 2380/1. ChromTop tip, SoftFinish grip

General ordering data

Type	SDS 1.0X5.5X150	Version
Order No.	9008350000	Screwdriver, Screwdriver
GTIN (EAN)	4032248056316	
Qty.	1 pc(s).	

Brass

Brass bus bars, as a copper alloy, has positive properties in terms of electrical conductivity and at the same time has a higher strength than copper against mechanical stress.

General ordering data

Type	ST 10.00x3.00x1000 CuZn ...	Version
Order No.	0259800000	Accessories, Busbar, Brass
GTIN (EAN)	4008190049300	
Qty.	1 m	

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

5x20

5x20

For protection against overcurrent, we offer cartridge fuse with dimensions 5x20 mm in sizes from 100 mA to 6.3 A.

General ordering data

Type	G 20/2.50A/F	Version
Order No.	0431000000	Active components, Fuse
GTIN (EAN)	4008190085513	
Qty.	10 pc(s).	
Type	G 20/4.00A/F	Version
Order No.	0431200000	Active components, Fuse
GTIN (EAN)	4008190022983	
Qty.	10 pc(s).	
Type	G 20/5.00A/F	Version
Order No.	0431300000	Active components, Fuse
GTIN (EAN)	4008190185381	
Qty.	10 pc(s).	
Type	G 20/0.25A/F	Version
Order No.	0430500000	Active components, Fuse
GTIN (EAN)	4008190153991	
Qty.	10 pc(s).	
Type	G 20/0.20A/F	Version
Order No.	0430400000	Active components, Fuse
GTIN (EAN)	4008190152383	
Qty.	10 pc(s).	
Type	G 20/1.00A/F	Version
Order No.	0430700000	Active components, Fuse
GTIN (EAN)	4008190093877	
Qty.	10 pc(s).	
Type	G 20/1.60A/F	Version
Order No.	0430800000	Active components, Fuse
GTIN (EAN)	4008190031503	
Qty.	10 pc(s).	
Type	G 20/6.30A/F	Version
Order No.	0431400000	Active components, Fuse
GTIN (EAN)	4008190086053	
Qty.	10 pc(s).	
Type	G 20/3.15A/F	Version
Order No.	0431100000	Active components, Fuse
GTIN (EAN)	4008190012977	
Qty.	10 pc(s).	
Type	G 20/0.10A/F	Version
Order No.	0430300000	Active components, Fuse
GTIN (EAN)	4008190077174	
Qty.	10 pc(s).	

Creation date January 15, 2022 3:55:32 PM CET

SAKS 1/35/G25 DB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	G 20/0.63A/F	Version
Order No.	0439000000	Active components, Fuse
GTIN (EAN)	4008190131210	
Qty.	10 pc(s).	
Type	G 20/0.50A/F	Version
Order No.	0430600000	Active components, Fuse
GTIN (EAN)	4008190046835	
Qty.	10 pc(s).	
Type	G 20/2.00A/F	Version
Order No.	0430900000	Active components, Fuse
GTIN (EAN)	4008190123567	
Qty.	10 pc(s).	

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	DEK 5/8 PLUS MC SDR	Version
Order No.	1046370000	Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00
GTIN (EAN)	4032248782079	Weidmueller, To customer specification
Qty.	160 pc(s).	
Type	DEK 5/8 MC SDR	Version
Order No.	1856750000	Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00
GTIN (EAN)	4032248400867	Weidmueller, To customer specification
Qty.	160 pc(s).	

SAKS 1/35/G25 DB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****SchT group marker carrier**

The SchT 5 S group tag carriers are clipped directly onto the TS 32 mounting rail (G-rail) or the TS 35 mounting rail (top-hat rail). It is therefore possible to label the terminal strip irrespective of the terminal and the type of terminal. SchT 5 and SchT 5 S are fitted with ESO 5, STR 5 protective strips.

The SchT 7 is a hinged group tag carrier for inlay tags which enables easy access to the clamping screw.

The SchT 7 is fitted with ESO 7, STR 7 protective strips or DEK 5.

Inlay tags and protective strips can be found under "Accessories".

General ordering data

Type	SCHT 7	Version
Order No.	0517960000	SCHT, Terminal marker, 39.3 x 8 mm, Pitch in mm (P): 7.00
GTIN (EAN)	4008190001742	Weidmueller, white
Qty.	20 pc(s).	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[0501500000](#)