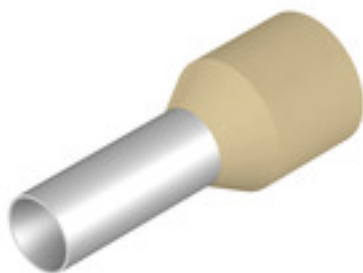


H10,0/22 EB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 15 mm, 12 mm, Ivory
Order No.	0534200000
Type	H10,0/22 EB
GTIN (EAN)	4008190033460
Qty.	100 pc(s).
Packaging	loose

H10,0/22 EB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	0.5 g
------------	-------

Technical data

Description of article	Wire end ferrule with plastic collar, ivory	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	7.6 mm	Colour code	Weidmüller
Conductor cross-section	10 mm ²	Contact surface diameter (D1)	4.5 mm
Contact surface length (L2)	12 mm	L1 in mm	22 mm
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 025 A
Plastic collar thickness (S2)	0.4 mm	Stripping length	15 mm
Wire connection cross section AWG, max.	AWG 8		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E354986
Certificate no. (cULus)	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Catalogues	Catalogues in PDF-format
Brochures	

H10,0/22 EB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Drawings****Drawing**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[0534200000](#)