

SKMU PG48-K GR**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Similar to illustration

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	SKMU PA (plastic locknut), Locknut, PG 48, 8 mm, Polyamid 6 (PA6 - GF30)
Order No.	1719090000
Type	SKMU PG48-K GR
GTIN (EAN)	4008190352318
Qty.	25 ST

SKMU PG48-K GR

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS

Conform

Dimensions and weights

Height	8 mm	Height (inches)	0.315 inch
Net weight	14.2 g		

Temperatures

Operating temperature	-40 °C...100 °C
-----------------------	-----------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%


General information

Silicone	No	O.D.	80.85 mm
UL 94 flammability rating	HB	Operating temperature range, max.	100 °C
Operating temperature range, min.	-40 °C	Pitch of thread	1.59 mm
Halogen	No	AF size 1	70 mm
Thickness	8.00 mm	Cable glands	PG 48
Material	Polyamid 6 (PA6 - GF30)	External thread	PG 48
Internal thread	PG 48	Length of thread	8 mm

Classifications

ETIM 6.0	EC000940	ETIM 7.0	EC000940
ETIM 8.0	EC000940	ETIM 9.0	EC000940
ETIM 10.0	EC000940	ECLASS 9.0	27-14-44-24
ECLASS 9.1	27-14-44-24	ECLASS 10.0	27-14-44-24
ECLASS 11.0	27-14-44-24	ECLASS 12.0	27-14-08-07
ECLASS 13.0	27-14-08-07	ECLASS 14.0	27-14-08-07
ECLASS 15.0	27-14-08-07		

Drawings

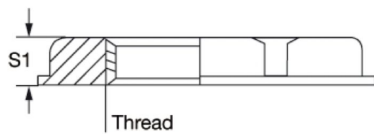

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1719090000](#)