

IE-FC-DFM-KNOB-4X**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Version	FrontCom, Double frame, Metal cover, Control knob locking, NEMA 4X
Order No.	2669640000
Type	IE-FC-DFM-KNOB-4X
GTIN (EAN)	4050118800531
Qty.	1 pc(s).

IE-FC-DFM-KNOB-4X

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	27.5 mm	Height (inches)	1.083 inch
Width	132 mm	Width (inches)	5.197 inch
Wall thickness, min.	1 mm	Wall thickness, max.	5 mm
Net weight	824.97 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Material cover	Zinc diecast, powder-coated	Material frame	Zinc diecast, powder-coated
Product type	Double frame, Metal cover, Control knob locking, NEMA 4X	Protection class (UL)	Type 4x
Protection degree	IP65, in closed state		

General standards

Certificate No. (CSA)	2000039-80039714	Certificate No. (DNVGL)	TAA000022B
Certificate No. (cURus)	E223801		

Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ECLASS 9.0	27-18-27-02
ECLASS 9.1	27-18-27-90	ECLASS 10.0	27-18-27-02
ECLASS 11.0	27-18-27-02	ECLASS 12.0	27-18-28-92

Approvals

Approvals



UL File Number Search	UL Website
Certificate No. (cURus)	E223801

Downloads

Engineering Data	CAD data – STEP
User Documentation	Designation key / Type key
Catalogues	Catalogues in PDF-format


IE-FC-DFM-KNOB-4X

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com


Drawings

Dimensioned drawing

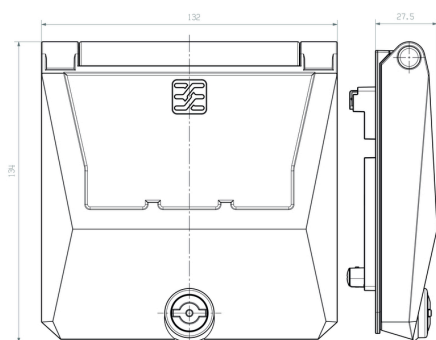


Unit: mm

Installation cut-out

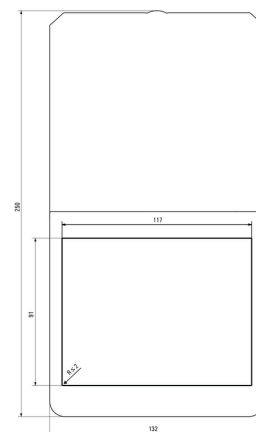


Unit: mm

Dimensioned drawing

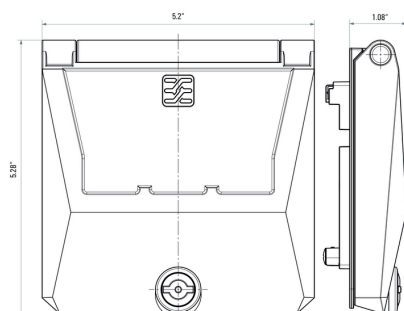

Unit: in

Installation cut-out

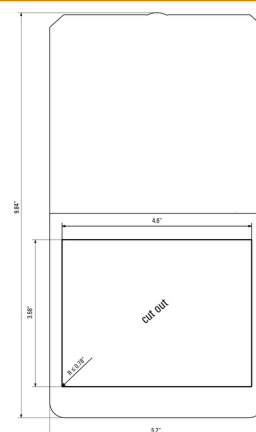

Unit: in

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[2669640000](#)