

LKSC M2,9x13VZ**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030


32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

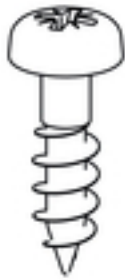**Flexible - More flexible - Profilform**

Modular housings in profile form - the flexible modular system comprising coloured and transparent plastic profiles and carrier modules

The combination of standard pitches mounted side by side in any arrangement and metre goods cut accurate to the millimetre creates the perfect balance between flexibility and economic efficiency:

- Pitch profiles with standard widths ranging from 5mm to 45mm allow the mounting of all standard PCB formats.
- Variable heights ensure maximum component density, even with larger electronics components.
- The different installation variations mean that mounting the enclosure directly is as easy as clipping components onto the terminal rail
- Solid hoods protect the module reliably from external influences

The recipe for success: variable profile + modular form components = flexible enclosure concept that offers a large surface area for the PCBs.

The modular concept is designed for modules with high space requirements and suitable for small component quantities and different widths.

General ordering data

Version	Accessories, Mounting screw
Order No.	4011200000
Type	LKSC M2,9x13VZ
GTIN (EAN)	4032248415014
Qty.	100 pc(s).

LKSC M2,9x13VZ**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technical data**Dimensions and weights**

Height	13 mm	Height (inches)	0.512 inch
Net weight	0.647 g		

Temperatures

Storage temperature	-25 °C...55 °C
---------------------	----------------

General data

Colour	grey	Colour chart (similar)	RAL 7035
Encapsulation option	No	Protection degree	IP20

Material data

Comparative Tracking Index (CTI)	≥ 600
----------------------------------	-------

Classifications

ETIM 6.0	EC002848	ETIM 7.0	EC002848
ETIM 8.0	EC002848	ECLASS 9.0	27-14-11-92
ECLASS 9.1	27-14-11-92	ECLASS 10.0	27-14-11-92
ECLASS 11.0	27-14-11-92	ECLASS 12.0	27-14-11-92

Important note

Product information	<p>3 heights are available for the cover profile and the end plates: TS mounting: TS 32 = 45mm, TS 35x7,5 = 40.5mm Direct mounting: 24mm Dimensions of the PCB: Thickness: 1.6 (±0.2) mm, width: 42 (+0.5) mm Dimension of the RS section = length of the printed circuit board – 4.5mm Dimension of ADP section = PCB length – 1mm Example: PCB length 160mm, RS section = 155,5mm, ADP section = 159mm</p>
---------------------	--

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	WSCAD
Catalogues	Catalogues in PDF-format
Brochures	

LKSC M2,9x13VZ

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold


Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Drawings

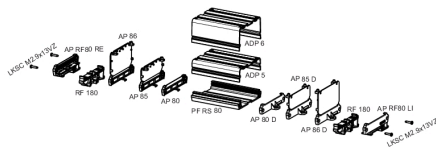

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[4011200000](#)