

IE-XRJ45/IDC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

IE plug-in connectors, IP20, for copper and fibre optic cables

General ordering data

Version	Flange insert, Cat.6_A / Class E_A (ISO/IEC 11801 2010), IP20
Order No.	8808330000
Type	IE-XRJ45/IDC
GTIN (EAN)	4032248505913
Qty.	1 pc(s).

IE-XRJ45/IDC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	23.4 mm	Height (inches)	0.921 inch
Width	14.7 mm	Width (inches)	0.579 inch
Length	43.8 mm	Length (inches)	1.724 inch
Wall thickness, min.	1.45 mm	Wall thickness, max.	1.55 mm
Net weight	29 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Connection 1	RJ45	Connection 2	IDC
Wiring	TIA-568A, TIA-568B, PROFINET	Housing main material	Zinc diecast
Insulation cross-section, max.	1.8	Category	Cat.6_A / Class E_A (ISO/IEC 11801 2010)
Contact surface	Gold over nickel	Connection diameter, solid	0.41...0.64
Conductor connection cross-section, solid (AWG)	AWG 26...AWG 22	Conductor connection cross-section, solid	0.13...0.32 mm ²
Connection diameter, flexible	0.48...0.76 mm	Conductor connection cross-section, flexible (AWG)	AWG 26...AWG 22
Wire connection cross section, finely stranded, min.	0.141 mm ²	Conductor connection cross-section, flexible	0.14...0.35 mm ²
Shielding	360° shield contact	Protection degree	IP20
Insertion force	20 N	Plugging cycles	750

Electrical properties

Contact resistance	≤ 20 mΩ	Dielectric strength, contact / contact	≥ 1000 V DC
PoE / PoE+	conforming to IEEE 802.3at		

General standards

Certificate No. (DNVGL)	TAE00003EW	Connector standard	IEC 60603-7-51
-------------------------	------------	--------------------	----------------

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ECLASS 9.0	27-44-03-90
ECLASS 9.1	27-44-03-90	ECLASS 10.0	27-44-03-90
ECLASS 11.0	27-44-03-90	ECLASS 12.0	27-44-03-90

Approvals

Approvals



ROHS	Conform
------	---------

IE-XRJ45/IDC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-XRJ45/IDC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Dimensioned drawing

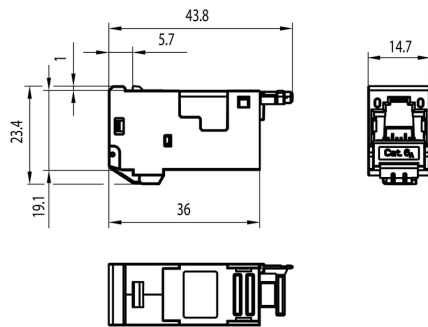

Installation cut-out

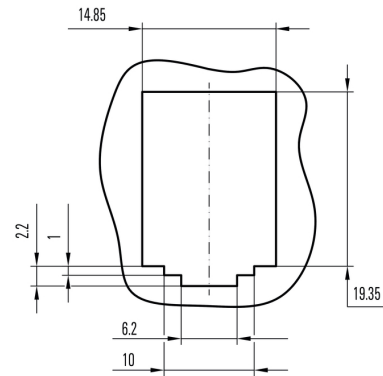

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[8808330000](#)