



TERMSERIES-compact

Universal relay with maximum vibration resistance

Using the all-rounder in a small space

To achieve maximum machine and system availability, many relays must also function reliably in environments with strong vibrations. In addition, compact modules for flat control cabinets are required. TERMSERIES-compact fulfills both demands.

The new, ultra-compact modules round out the TERMSERIES family. Their relays are enclosed, which makes them particularly vibration-proof. Due to the slim and, above all, flat design, they can be installed anywhere. Since they have the same contours as the tried-and-tested TERMSERIES, all the accessories of the series can be used for cross-connections. In this way, comprehensive complete solutions can be realized with the 100% function-tested relay modules.

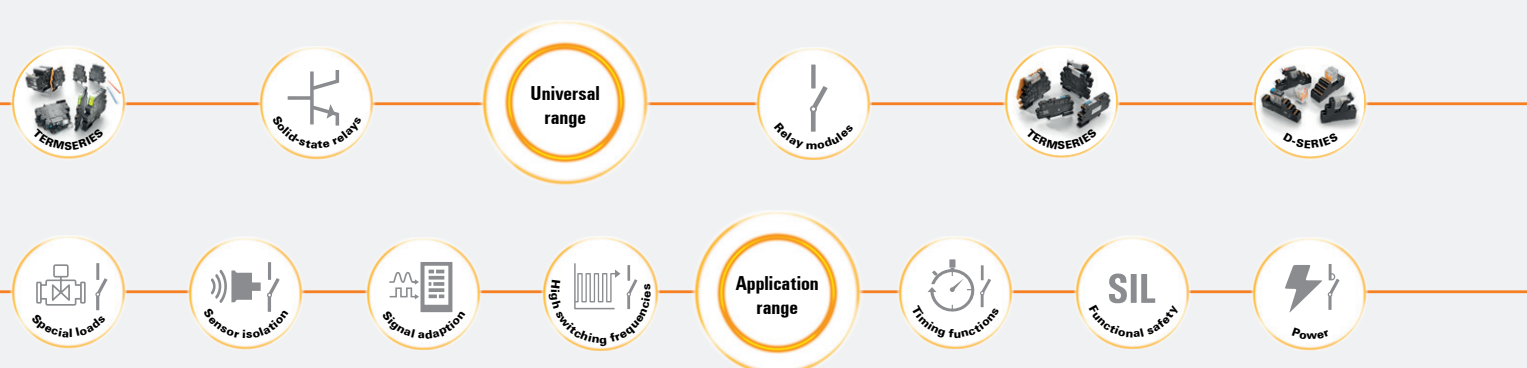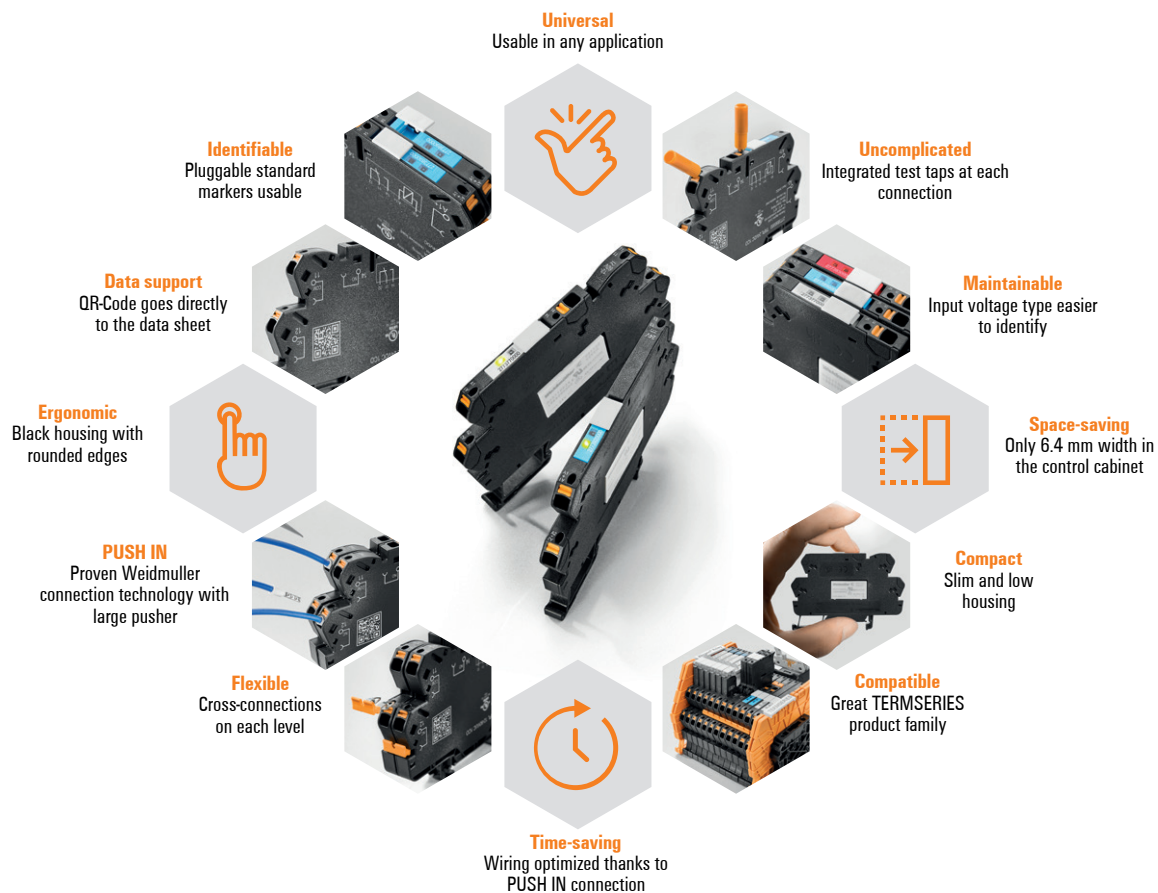

Perfect completion of the TERMSERIES

With its closed design and depth of only 63 mm, TERMSERIES-compact completes the proven TERMSERIES. Accessories that can be used in common, contour uniformity, mirror-symmetrical design and continuous cross-connection channels enable highly flexible solutions.

Universal applicability

The TERMSERIES-compact can be used in a wide range of applications thanks to different versions and a variety of input voltages. Multi-voltage input of the TERMSERIES with 24-230 V UC and 12-60 V UC are available for the first time in an extremely compact design.

High efficiency and user-friendliness

PUSH IN connection technology and colored pushers make wiring 75% faster and considerably safer. Colored accents for input voltages, easy-to-read part numbers, and integrated test taps facilitate maintenance.

Comprehensive digital support

Digital provision of all data for WMC, Eplan, CAD and tender texts according to E-Class and ETIM standards. Convenient data support is convenient via QR code on the side of the housing – with link to the data sheet.

Technical data

Type	Control side	Contact type / Version	Load side	Clamping range min./max.	Qty pk.	Order No.
TERMSERIES-compact – Complete module in 6.4 mm width, with PUSH IN technology						
TRPL 24VDC 1NO F	24 V DC	1 NO contact with fuse	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773930000
TRPL 5VDC 1NO	5 V DC	1 NO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2774040000
TRPL 24VUC 1CO	5 V DC	1 CO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2774030000
TRPL 24VUC 1NO	24 V UC	1 NO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773980000
TRPL 24VUC 1CO	24 V UC	1 CO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773970000
TRPL 24VDC 1NO	24 V DC	1 NO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773920000
TRPL 24VDC 1CO	24 V DC	1 CO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773890000
TRPL 24 - 230VUC 1NO	24 - 230 V UC	1 NO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773870000
TRPL 24 - 230VUC 1CO	24 - 230 V UC	1 CO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773860000
TRPL 230VAC 1NO	230 V AC	1 NO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773840000
TRPL 230VAC 1CO	230 V AC	1 CO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773830000
TRPL 120VAC 1NO	120 V AC	1 NO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773810000
TRPL 120VAC 1CO	120 V AC	1 CO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773800000
TRPL 12 - 60VUC 1NO	12 - 60 V UC	1 NO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773780000
TRPL 12 - 60VUC 1CO	12 - 60 V UC	1 CO contact	250 V AC / 6 A	0.14 - 2.5 mm ² (26-14 AWG)	10	2773770000
TXL S		Supply terminal		0.14 - 2.5 mm ² (26-14 AWG)	1	2774100000
TXL FT		Feed trough terminal		0.14 - 2.5 mm ² (26-14 AWG)	1	2774080000
TXL PP		Partition plate			10	2774090000



Visit our website for more information
www.weidmuller.com

Order free product samples

Secure your product sample in our online catalog using the search term TERMSERIES-compact PROMO or order no. 2899090000 and select "Order sample product".

Weidmüller, Inc
821 Southlake Blvd.
Richmond, Virginia 23236
Telephone: (800) 849-9343
Facsimile: (804) 379-2593
Email: info@weidmuller.com
Website: www.weidmuller.com



Visit our online catalog for
more information

Weidmüller 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Weidmuller:

[2774080000](#) [2773840000](#) [2773890000](#) [2773920000](#) [2774030000](#) [2773930000](#) [2773980000](#) [2773800000](#)
[2773770000](#) [2773870000](#) [2773860000](#) [2774100000](#) [2773830000](#) [2774090000](#) [2773970000](#) [2774040000](#)
[2773780000](#) [2773810000](#)