

H0,5/18D W**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Standard, 14 mm, 12 mm, white
Order No.	1076990000
Type	H0,5/18D W
GTIN (EAN)	4032248834624
Qty.	500 pc(s).
Packaging	loose

H0,5/18D W

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	0.086 g
------------	---------

Technical data

Description of article	Wire end ferrule with plastic collar, white	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	2.6 mm	Colour code	DIN
Conductor cross-section	0.5 mm ²	Contact surface diameter (D1)	1 mm
Contact surface length (L2)	12 mm	L1 in mm	18 mm
Metal sleeve thickness (S1)	0.15 mm	Military designation	T 20A 003 A
Plastic collar thickness (S2)	0.25 mm	Stripping length	14 mm
Wire connection cross section AWG, max.	AWG 20		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E354986
Certificate no. (cULus)	E499744

Downloads

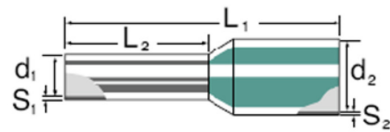
Engineering Data	EPLAN, WSCAD
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

H0,5/18D W**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Drawings****Drawing**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1076990000](#)