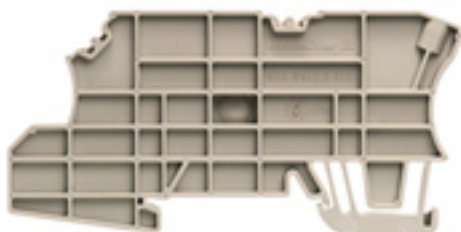


WBB WMF2.5 BLZ**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image****General ordering data**

Version	W-Series, Fixing bracket, dark beige, 5.08 mm
Order No.	1142980000
Type	WBB WMF2.5 BLZ
GTIN (EAN)	4032248925896
Qty.	10 pc(s).

WBB WMF2.5 BLZ

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	44.5 mm	Depth (inches)	1.752 inch
Height	88.5 mm	Height (inches)	3.484 inch
Width	5.08 mm	Width (inches)	0.2 inch
Net weight	10.2 g		

Temperatures

Storage temperature	-25 °C...55 °C	Continuous operating temp., min.	-50 °C
Continuous operating temp., max.	120 °C		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1	SCIP	936a8f21-8ce1-4838-a60e-9ad69268c052
------------	----------------	------	--------------------------------------

Material data

Material	Wemid	Colour	dark beige
UL 94 flammability rating	V-0		

System specifications

Version	Mounting block	Rail	TS 35
---------	----------------	------	-------

Additional technical data

Snap-on	No
---------	----

General

Rail	TS 35
------	-------

Classifications

ETIM 6.0	EC000886	ETIM 7.0	EC000886
ETIM 8.0	EC000886	ECLASS 9.0	27-14-11-92
ECLASS 9.1	27-14-11-33	ECLASS 10.0	27-14-11-92
ECLASS 11.0	27-14-11-92	ECLASS 12.0	27-14-11-92

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
User Documentation	StorageConditionsTerminalBlocks
Catalogues	Catalogues in PDF-format
Brochures	CAT 1 TERM 16/17 EN

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1142980000](#)