

VP M32 EXE MS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	VPMS Ex (ex blanking plug, brass), Blanking plug, M 32, 12 mm, Brass, nickel-plated
Order No.	1210920000
Type	VP M32 EXE MS
GTIN (EAN)	4032248992409
Qty.	10 pc(s).

VP M32 EXE MS

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Length	16 mm	Length (inches)	0.63 inch
Net weight	86.1 g		

Temperatures

Operating temperature	-40 °C... 100 °C
-----------------------	------------------

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1; 96-45-7 Imidazolidine-2-thione
------------	---

Certificate numbers cable gland

Certificate no. cable gland (ATEX)	INERIS 09 ATEX 0059X	Identification	II 2 GD, Ex d IIC, Ex e II, Ex tD
------------------------------------	----------------------	----------------	-----------------------------------

General information

AF size 1	39 mm	External thread	M 32
Length of thread	12 mm	Material	Brass, nickel-plated
O-Ring	NBR	Operating temperature range, max.	100 °C
Operating temperature range, min.	-40 °C	Pitch of thread	1.5 mm
Protection degree	IP54, IP64, IP68	Torque for cap nut, max.	10.8 Nm
Torque for cap nut, min.	7.2 Nm	Torque for connecting adapter, max.	36 Nm
Torque for connecting adapter, min.	18 Nm		

Classifications

ETIM 6.0	EC000451	ETIM 7.0	EC000451
ETIM 8.0	EC000451	ECLASS 9.0	27-14-44-25
ECLASS 9.1	27-14-44-35	ECLASS 10.0	27-14-44-25
ECLASS 11.0	27-14-44-25		

Approvals

Approvals



ROHS

Conform

Downloads


Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format

VP M32 EXE MS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

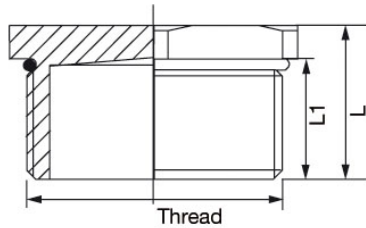

VP M32 EXE MS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Polyethylene flat gasket - GWDR PO**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M32-PO	Version
Order No.	1777960000	GWDR PO (flat gasket - polyethylene), Sealing ring, M 32, Polyethylene
GTIN (EAN)	4032248158225	
Qty.	50 pc(s).	

Brass lock nuts, nickel-plated

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	SKMU M32 MS	Version
Order No.	1737020000	SKMU MS (brass locknut), Locknut, M 32, 4 mm, Brass, nickel-plated
GTIN (EAN)	4008190956493	
Qty.	100 pc(s).	

VP M32 EXE MS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Neoprene flat gasket - GWDR NP**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M32-NP	Version
Order No.	1736260000	GWDR NP (flat gasket - neoprene), Sealing ring, M 32, Neoprene
GTIN (EAN)	4008190956059	
Qty.	50 pc(s).	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1210920000](#)