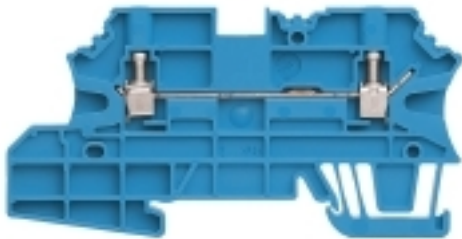


**WMF 2.5 DI BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

Weidmüller's new WMF (Weidmüller Multi-Functional) line of terminal blocks provide a multi-functional solution for routing and distributing signals. This space-saving terminal combines all the necessary functionality into a single solution. It features an integrated shield connection and can be used with feed-through, fuse and disconnect functionality. The three cross-connection channels and wide variety of labelling options offer additional flexibility.

**General ordering data**

|            |                                                                                                 |
|------------|-------------------------------------------------------------------------------------------------|
| Version    | W-Series, Test-disconnect terminal, Rated cross-section: 2.5 mm <sup>2</sup> , Screw connection |
| Order No.  | <a href="#">1270070000</a>                                                                      |
| Type       | WMF 2.5 DI BL                                                                                   |
| GTIN (EAN) | 4050118097245                                                                                   |
| Qty.       | 50 pc(s).                                                                                       |

## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|                          |            |                |            |
|--------------------------|------------|----------------|------------|
| Depth                    | 44.5 mm    | Depth (inches) | 1.752 inch |
| Depth including DIN rail | 45 mm      | Height         | 88 mm      |
| Height (inches)          | 3.465 inch | Width          | 5.08 mm    |
| Width (inches)           | 0.2 inch   | Net weight     | 10.7 g     |

## Temperatures

|                                  |                |                                  |        |
|----------------------------------|----------------|----------------------------------|--------|
| Storage temperature              | -25 °C...55 °C | Continuous operating temp., min. | -50 °C |
| Continuous operating temp., max. | 120 °C         |                                  |        |

## Material data

|                           |       |        |      |
|---------------------------|-------|--------|------|
| Material                  | Wemid | Colour | blue |
| UL 94 flammability rating | V-0   |        |      |

## Rating data IECEx/ATEX

|                                |                     |                                 |                     |
|--------------------------------|---------------------|---------------------------------|---------------------|
| Certificate No. (ATEX)         | DEMKO14ATEX1389U    | Certificate No. (IECEX)         | IECEXUL14.0097U     |
| Max. voltage (ATEX)            | 500 V               | Current (ATEX)                  | 20 A                |
| Wire cross section max. (ATEX) | 2.5 mm <sup>2</sup> | Max. voltage (IECEX)            | 500 V               |
| Current (IECEX)                | 20 A                | Wire cross section max. (IECEX) | 2.5 mm <sup>2</sup> |
| Marking EN 60079-7             | Ex ec II C Gc       | Ex 2014/34/EU label             | II 3 G D            |

## System specifications

|                  |                                                                                            |                                     |     |
|------------------|--------------------------------------------------------------------------------------------|-------------------------------------|-----|
| Version          | Screw connection,<br>Spacer, for plug-in cross-<br>connector, One end<br>without connector | End cover plate required            | Yes |
| Number of levels | 1                                                                                          | Number of clamping points per level | 2   |
| Rail             | TS 35                                                                                      |                                     |     |

## Additional technical data

|            |       |                  |         |
|------------|-------|------------------|---------|
| Open sides | right | Type of mounting | Snap-on |
|------------|-------|------------------|---------|

## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Conductors for clamping (rated connection)

|                                                                                         |                     |                                                                                         |                     |
|-----------------------------------------------------------------------------------------|---------------------|-----------------------------------------------------------------------------------------|---------------------|
| Blade size                                                                              | 0.6 x 3.5 mm        | Clamping range, max.                                                                    | 4 mm <sup>2</sup>   |
| Clamping range, min.                                                                    | 0.5 mm <sup>2</sup> | Clamping screw                                                                          | M 3                 |
| Connection cross-section, stranded, max.                                                | 4 mm <sup>2</sup>   | Connection cross-section, stranded, min.                                                | 1.5 mm <sup>2</sup> |
| Connection direction                                                                    | on side             | Gauge to IEC 60947-1                                                                    | A3                  |
| Number of connections                                                                   | 2                   | Stripping length                                                                        | 10 mm               |
| Tightening torque, max.                                                                 | 0.6 Nm              | Tightening torque, min.                                                                 | 0.5 Nm              |
| Type of connection                                                                      | Screw connection    | Wire connection cross section AWG, max.                                                 | AWG 12              |
| Wire connection cross section AWG, min.                                                 | AWG 26              | Wire connection cross section, finely stranded, max.                                    | 4 mm <sup>2</sup>   |
| Wire connection cross section, finely stranded, min.                                    | 0.5 mm <sup>2</sup> | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. | 2.5 mm <sup>2</sup> |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min. | 0.5 mm <sup>2</sup> | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 2.5 mm <sup>2</sup> |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.5 mm <sup>2</sup> | Wire connection cross-section, solid core, max.                                         | 4 mm <sup>2</sup>   |
| Wire connection cross-section, solid core, min.                                         | 0.5 mm <sup>2</sup> |                                                                                         |                     |

## Disconnect terminals

|                  |          |                      |    |
|------------------|----------|----------------------|----|
| Cross-disconnect | without  | Integral test socket | No |
| Slitting         | Pivoting |                      |    |

## General

|                                         |        |                                         |        |
|-----------------------------------------|--------|-----------------------------------------|--------|
| Rail                                    | TS 35  | Wire connection cross section AWG, max. | AWG 12 |
| Wire connection cross section AWG, min. | AWG 26 |                                         |        |

## Rating data

|                                              |                     |                                 |       |
|----------------------------------------------|---------------------|---------------------------------|-------|
| Rated cross-section                          | 2.5 mm <sup>2</sup> | Rated voltage                   | 500 V |
| Rated current                                | 20 A                | Current at maximum wires        | 20 A  |
| Volume resistance according to IEC 60947-7-x | 1.33 mΩ             | Rated impulse withstand voltage | 8 kV  |
| Power loss in accordance with IEC 60947-7-x  | 0.77 W              | Pollution severity              | 3     |
| Surge voltage category                       | III                 |                                 |       |

## UL rating data

|                                            |        |                                            |        |
|--------------------------------------------|--------|--------------------------------------------|--------|
| Certificate No. (cURus)                    | E60693 | Conductor size Factory wiring max. (cURus) | 12 AWG |
| Conductor size Factory wiring min. (cURus) | 26 AWG | Conductor size Field wiring max. (cURus)   | 12 AWG |
| Conductor size Field wiring min. (cURus)   | 26 AWG | Current size B (cURus)                     | 19 A   |
| Current size C (cURus)                     | 19 A   | Current size D (cURus)                     | 5 A    |
| Voltage size B (cURus)                     | 600 V  | Voltage size C (cURus)                     | 600 V  |
| Voltage size D (cURus)                     | 600 V  | Wire cross section max. (cURus)            | 12 AWG |
| Wire cross section min. (cURus)            | 26 AWG |                                            |        |

## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC000902    | ETIM 7.0    | EC000902    |
| ETIM 8.0    | EC000902    | ECLASS 9.0  | 27-14-11-26 |
| ECLASS 9.1  | 27-14-11-26 | ECLASS 10.0 | 27-14-11-26 |
| ECLASS 11.0 | 27-14-11-26 |             |             |

## Approvals

Approvals



|                       |         |
|-----------------------|---------|
| ROHS                  | Conform |
| UL File Number Search | E60693  |

## Downloads

|                                             |                                                                                                                                                                                                                                                                        |
|---------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Approval/Certificate/Document of Conformity | <a href="#">Attestation of Conformity</a><br><a href="#">EAC certificate</a><br><a href="#">EAC EX Certificate</a><br><a href="#">CCC Ex Certificate</a><br><a href="#">CE Declaration of Conformity</a><br><a href="#">CE Declaration of Conformity all terminals</a> |
| Engineering Data                            | <a href="#">CAD data – STEP</a>                                                                                                                                                                                                                                        |
| Engineering Data                            | <a href="#">EPLAN, WSCAD, Zuken E3.S</a>                                                                                                                                                                                                                               |
| User Documentation                          | <a href="#">Beipackzettel_WMf.pdf</a><br><a href="#">NTI WMF 2.5 DI.pdf</a><br><a href="#">Usage of terminals in EXi atmospheres</a><br><a href="#">StorageConditionsTerminalBlocks</a>                                                                                |
| Catalogues                                  | <a href="#">Catalogues in PDF-format</a>                                                                                                                                                                                                                               |
| Brochures                                   |                                                                                                                                                                                                                                                                        |

### WMF 2.5 DI BL

**Weidmüller Interface GmbH & Co. KG**

 
Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings



## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## End plates



## DCS marshalling

Our innovative PRV terminal blocks for DCS marshalling featuring a PUSH IN connection and our multifunctional DCS marshalling terminals featuring a screw connection (WMF) not only save space in the panel; they also guarantee more effective signal transmission in process control systems.

## General ordering data

|            |                            |                     |
|------------|----------------------------|---------------------|
| Type       | AP WMF2.5                  | Version             |
| Order No.  | <a href="#">1142990000</a> | W-Series, End plate |
| GTIN (EAN) | 4032248925889              |                     |
| Qty.       | 50 pc(s).                  |                     |

## Fuse holder



## DCS marshalling

Our innovative PRV terminal blocks for DCS marshalling featuring a PUSH IN connection and our multifunctional DCS marshalling terminals featuring a screw connection (WMF) not only save space in the panel; they also guarantee more effective signal transmission in process control systems.

## General ordering data

|            |                            |                                                                |
|------------|----------------------------|----------------------------------------------------------------|
| Type       | FUCR 100-250V SW           | Version                                                        |
| Order No.  | <a href="#">1167680000</a> | Accessories, Fuse holder, Rated cross-section: Direct mounting |
| GTIN (EAN) | 4032248113897              |                                                                |
| Qty.       | 10 pc(s).                  |                                                                |
| Type       | FUCR SW                    | Version                                                        |
| Order No.  | <a href="#">1167630000</a> | Accessories, Fuse holder, Rated cross-section: Direct mounting |
| GTIN (EAN) | 4032248113903              |                                                                |
| Qty.       | 10 pc(s).                  |                                                                |
| Type       | FUCR 10-36V SW             | Version                                                        |
| Order No.  | <a href="#">1167640000</a> | Accessories, Fuse holder, Rated cross-section: Direct mounting |
| GTIN (EAN) | 4032248113972              |                                                                |
| Qty.       | 10 pc(s).                  |                                                                |

## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

2.5 mm<sup>2</sup>


2.5  
mm<sup>2</sup>

The plug-in cross-connections feature easy handling and quick installation. This saves a great deal of time during installation in comparison with screwed solutions.

## General ordering data

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/2 BL              |
| Order No.  | <a href="#">1527740000</a> |
| GTIN (EAN) | 4050118448658              |
| Qty.       | 60 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/5 BL              |
| Order No.  | <a href="#">1527790000</a> |
| GTIN (EAN) | 4050118448627              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/6                 |
| Order No.  | <a href="#">1527630000</a> |
| GTIN (EAN) | 4050118448429              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/20 RD             |
| Order No.  | <a href="#">2108920000</a> |
| GTIN (EAN) | 4050118485899              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/3 RD              |
| Order No.  | <a href="#">2108690000</a> |
| GTIN (EAN) | 4050118448535              |
| Qty.       | 60 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/10                |
| Order No.  | <a href="#">1527690000</a> |
| GTIN (EAN) | 4050118447989              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/8                 |
| Order No.  | <a href="#">1527670000</a> |
| GTIN (EAN) | 4050118448405              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/9 RD              |
| Order No.  | <a href="#">2108900000</a> |
| GTIN (EAN) | 4050118448474              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/4 RD              |
| Order No.  | <a href="#">2108700000</a> |
| GTIN (EAN) | 4050118448528              |
| Qty.       | 60 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/7                 |
| Order No.  | <a href="#">1527640000</a> |
| GTIN (EAN) | 4050118448412              |
| Qty.       | 20 pc(s).                  |

## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type ZQV 2.5N/9  
 Order No. [1527680000](#)  
 GTIN (EAN) 4050118447996  
 Qty. 20 pc(s).

Type ZQV 2.5N/3  
 Order No. [1527570000](#)  
 GTIN (EAN) 4050118448450  
 Qty. 60 pc(s).

Type ZQV 2.5N/6 BL  
 Order No. [1527820000](#)  
 GTIN (EAN) 4050118448610  
 Qty. 20 pc(s).

Type ZQV 2.5N/8 BL  
 Order No. [1527840000](#)  
 GTIN (EAN) 4050118448597  
 Qty. 20 pc(s).

Type ZQV 2.5N/4  
 Order No. [1527590000](#)  
 GTIN (EAN) 4050118448443  
 Qty. 60 pc(s).

Type ZQV 2.5N/8 RD  
 Order No. [2108870000](#)  
 GTIN (EAN) 4050118448481  
 Qty. 20 pc(s).

Type ZQV 2.5N/4 BL  
 Order No. [1527780000](#)  
 GTIN (EAN) 4050118448634  
 Qty. 60 pc(s).

Type ZQV 2.5N/50 BL  
 Order No. [1527920000](#)  
 GTIN (EAN) 4050118448559  
 Qty. 5 pc(s).

Type ZQV 2.5N/10 RD  
 Order No. [2108910000](#)  
 GTIN (EAN) 4050118486018  
 Qty. 20 pc(s).

Type ZQV 2.5N/2  
 Order No. [1527540000](#)  
 GTIN (EAN) 4050118448467  
 Qty. 60 pc(s).

Type ZQV 2.5N/5  
 Order No. [1527620000](#)  
 GTIN (EAN) 4050118448436  
 Qty. 20 pc(s).

Type ZQV 2.5N/50 RD  
 Order No. [2109000000](#)  
 GTIN (EAN) 4050118486001  
 Qty. 5 pc(s).

Type ZQV 2.5N/9 BL  
 Order No. [1527870000](#)  
 GTIN (EAN) 4050118448580  
 Qty. 20 pc(s).



## WMF 2.5 DI BL

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/10 BL             |
| Order No.  | <a href="#">1527880000</a> |
| GTIN (EAN) | 4050118448573              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/50                |
| Order No.  | <a href="#">1527730000</a> |
| GTIN (EAN) | 4050118411362              |
| Qty.       | 5 pc(s).                   |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/6 RD              |
| Order No.  | <a href="#">2108720000</a> |
| GTIN (EAN) | 4050118448504              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/3 BL              |
| Order No.  | <a href="#">1527770000</a> |
| GTIN (EAN) | 4050118448641              |
| Qty.       | 60 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/7 BL              |
| Order No.  | <a href="#">1527830000</a> |
| GTIN (EAN) | 4050118448603              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/7 RD              |
| Order No.  | <a href="#">2108810000</a> |
| GTIN (EAN) | 4050118448498              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/20 BL             |
| Order No.  | <a href="#">1527890000</a> |
| GTIN (EAN) | 4050118448566              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/20                |
| Order No.  | <a href="#">1527720000</a> |
| GTIN (EAN) | 4050118447972              |
| Qty.       | 20 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/2 RD              |
| Order No.  | <a href="#">2108470000</a> |
| GTIN (EAN) | 4050118448542              |
| Qty.       | 60 pc(s).                  |

|            |                            |
|------------|----------------------------|
| Type       | ZQV 2.5N/5 RD              |
| Order No.  | <a href="#">2108710000</a> |
| GTIN (EAN) | 4050118448511              |
| Qty.       | 20 pc(s).                  |

## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

## W-Series




W  
Series

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

|            |                            |                       |
|------------|----------------------------|-----------------------|
| Type       | WEW 35/2                   | Version               |
| Order No.  | <a href="#">1061200000</a> | W-Series, End bracket |
| GTIN (EAN) | 4008190030230              |                       |
| Qty.       | 50 pc(s).                  |                       |

## Slotted screwdriver

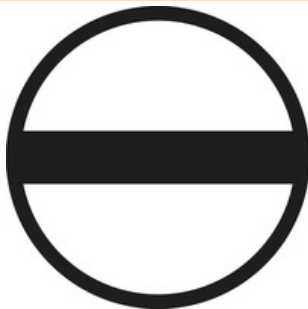

Slotted screwdriver with rounded blade SD DIN 5265, ISO 2380/2, output to DIN 5264, ISO 2380/1. ChromTop tip, SoftFinish grip

## General ordering data

|            |                            |                          |
|------------|----------------------------|--------------------------|
| Type       | SDS 0.6X3.5X100            | Version                  |
| Order No.  | <a href="#">9008330000</a> | Screwdriver, Screwdriver |
| GTIN (EAN) | 4032248056286              |                          |
| Qty.       | 1 pc(s).                   |                          |

## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Fuse holder



The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

## General ordering data

|            |                            |                                                                    |
|------------|----------------------------|--------------------------------------------------------------------|
| Type       | SIHA 3/G20/LD 10-36V       | Version                                                            |
| Order No.  | <a href="#">7921570000</a> | Accessories, Fuse holder, Rated cross-section: Plug-in connection, |
| GTIN (EAN) | 4032248322503              | Wemid, dark beige, Operating instructions/catalogue                |
| Qty.       | 25 pc(s).                  |                                                                    |
| Type       | SIHA 3/G20/LD 140-250V     | Version                                                            |
| Order No.  | <a href="#">7921600000</a> | Accessories, Fuse holder, Rated cross-section: Plug-in connection, |
| GTIN (EAN) | 4032248322633              | Wemid, dark beige, Operating instructions/catalogue                |
| Qty.       | 25 pc(s).                  |                                                                    |
| Type       | SIHA 3/G20                 | Version                                                            |
| Order No.  | <a href="#">7921560000</a> | Accessories, Fuse holder, Rated cross-section: Plug-in connection, |
| GTIN (EAN) | 4032248264643              | Wemid, dark beige, Operating instructions/catalogue                |
| Qty.       | 25 pc(s).                  |                                                                    |

## Blank



WS markers are the perfect match for the W-series connectors. Thanks to their system compatibility, the WS tags can also be used with the I-series and the Z-series. The large marking surfaces do not only permit long character strings but also multi-line text. WS markers are ideal for labels with long, customised character strings. Thanks to the proven MultiCard format, printing with PrintJet CONNECT oder/or Plotter is possible.

- Can be fitted in strips or individually
- Markers in proven MultiCard format

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |                                                                    |
|------------|----------------------------|--------------------------------------------------------------------|
| Type       | WS 10/5 M MC NE WS         | Version                                                            |
| Order No.  | <a href="#">1792000000</a> | WS, Terminal marker, 10 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4032248223862              | Allen-Bradley, white                                               |
| Qty.       | 720 pc(s).                 |                                                                    |

## WMF 2.5 DI BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.


- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |                                                           |
|------------|----------------------------|-----------------------------------------------------------|
| Type       | DEK 5/5 MC NE WS           | Version                                                   |
| Order No.  | <a href="#">1609801044</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397111              | Weidmueller, white                                        |
| Qty.       | 1,000 pc(s).               |                                                           |

## Component plugs

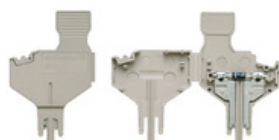

The component plug is used to integrate an electrical component in a disconnect terminal block. After soldering the electronic component, the plug can be integrated into the disconnection area of our disconnect terminal blocks and thus changes the disconnect terminal block into a modular terminal block with integrated electronic component.

## General ordering data

|            |                            |                                   |
|------------|----------------------------|-----------------------------------|
| Type       | BEST/DRBR                  | Version                           |
| Order No.  | <a href="#">1878570000</a> | Accessories, Component plug, 22 A |
| GTIN (EAN) | 4032248471508              |                                   |
| Qty.       | 50 pc(s).                  |                                   |

|            |                            |                                  |
|------------|----------------------------|----------------------------------|
| Type       | BEST/D                     | Version                          |
| Order No.  | <a href="#">1878560000</a> | Accessories, Component plug, 1 A |
| GTIN (EAN) | 4032248471492              |                                  |
| Qty.       | 50 pc(s).                  |                                  |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1270070000](#)