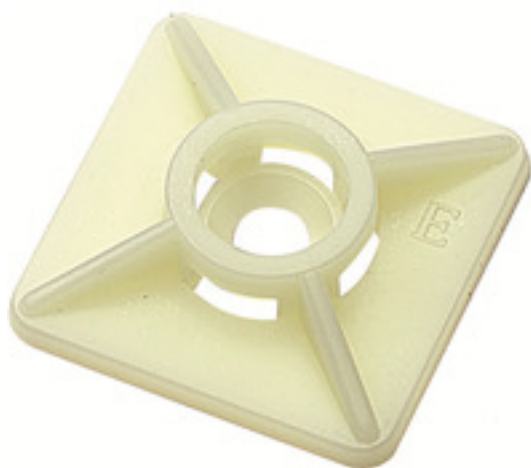


CBH 27/27 NC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Fastening of cables or bundles with ties into electrical switchgears and cabinets.

General ordering data

Version	Cable ties, 27 x 27 mm, Plastic, 80 N
Order No.	1289400000
Type	CBH 27/27 NC
GTIN (EAN)	4008190160067
Qty.	100 pc(s).

CBH 27/27 NC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	2 mm	Depth (inches)	0.079 inch
Height	27 mm	Height (inches)	1.063 inch
Width	27 mm	Width (inches)	1.063 inch
Net weight	1.7 g		

Temperatures

Operating temperature range	-40...75 °C
-----------------------------	-------------

Installation materials

For re-opening	No	Halogen	No
Material	Plastic	Max. cable tie width	4.8 mm
Operating temperature range, max.	75 °C	Operating temperature range, min.	-40 °C
Tensile strength	80 N	Tensile strength (Pound-force)	18 lbf
UL 94 flammability rating	V-2	UV-resistant	Yes
Version	Self-adhesive		

Classifications

ETIM 6.0	EC000449	ETIM 7.0	EC000449
ETIM 8.0	EC000449	ECLASS 9.0	23-15-90-07
ECLASS 9.1	27-40-07-90	ECLASS 10.0	27-40-07-90
ECLASS 11.0	23-15-25-09	ECLASS 12.0	23-15-25-09

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format

CBH 27/27 NC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Drawings

Dimensioned drawing

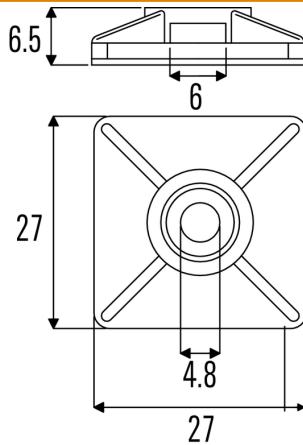

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1289400000](#)