

SAIE-7/8S-3-0.2U-PG11**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

Various build-in connectors are required for the connections on the device side of the sensor/actuator cabling. These are available in the versions M12, M8 and M5.

General ordering data

Version	Built-in plugs, 7/8", PG 11, Number of poles: 3, 0.2 m
Order No.	1292330000
Type	SAIE-7/8S-3-0.2U-PG11
GTIN (EAN)	4050118088335
Qty.	1 pc(s).

SAIE-7/8S-3-0.2U-PG11**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	38 g
------------	------

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

Technical data customisable plug-in connectors

Cable glands	PG 11	Coding	none
Contact surface	Gold-plated	Housing main material	Zinc diecast, nickel-plated
Number of poles	3	Plugging cycles	≥ 100
Protection degree	IP67, when screwed in	Rated current	10 A
Rated current	8 A (4- and 5-pole), 10 A (3-pole)	Rated voltage	300 V
Temperature range of housing	-25...+85 °C	Type of connection	Pin

General data

Cable glands	PG 11	
Cable length	0.2 m	
Coding	none	
Conductor O.D.	-	
Connection thread	7/8"	
Contact material	CuZn	
Contact surface	Gold-plated	
Core cross-section	0.75 mm²	
Housing main material	Zinc diecast, nickel-plated	
Material	PUR/ PUR	
Mounting thread	PG 11	
Mounting torque	min.	6 Nm
	max.	6.25 Nm
Mounting torque range	6 ... 6.25 Nm	
Number of poles	3	
Plugging cycles	≥ 100	
Protection degree	IP67, when screwed in	
Rated current	10 A	
Rated current	8 A (4- and 5-pole), 10 A (3-pole)	
Rated voltage	300 V	
Strand / cable length	0.2 m	
Temperature range of housing	-25...+85 °C	
Tightening torque	1.5 Nm	
Type of connection	Pin	

Classifications

ETIM 6.0	EC002635	ETIM 7.0	EC003570
ETIM 8.0	EC003570	ECLASS 9.0	27-44-01-03
ECLASS 9.1	27-44-01-03	ECLASS 10.0	27-44-01-03
ECLASS 11.0	27-44-01-03	ECLASS 12.0	27-44-01-03

SAIE-7/8S-3-0.2U-PG11

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E307231

Downloads

Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN FL FIELDWIRING EN

SAIE-7/8S-3-0.2U-PG11

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

 

D-32758 Detmold

Germany


www.weidmueller.com

Drawings

Wiring diagram

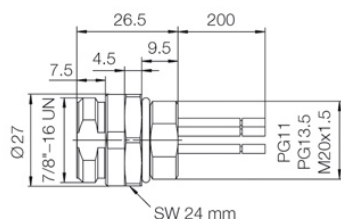

Pole scheme

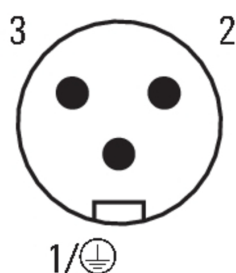

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1292330000](#)