

H0,5/14 OR SP**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

- supplied loose in poly-bag
- in multi-pack bag (5 x 100 pcs.)
- Linked of wire-end ferrule strips (50 pcs.)
- Linked wire-end ferrules on reel (5,000 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
Order No.	1476230000
Type	H0,5/14 OR SP
GTIN (EAN)	4050118283174
Qty.	100 pc(s).

H0,5/14 OR SP**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	0.018 g
------------	---------

Technical data

Description of article	Wire end ferrule with plastic collar, orange	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Collar diameter (D2)	2.6 mm	Colour code	Weidmüller
Conductor cross-section	0.5 mm ²	Contact surface diameter (D1)	1 mm
Contact surface length (L2)	8 mm	L1 in mm	14 mm
Metal sleeve thickness (S1)	0.15 mm	Plastic collar thickness (S2)	0.2 mm
Stripping length	10 mm	Wire connection cross section AWG, max.	AWG 20

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E499744

Downloads

Engineering Data	EPLAN
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format


H0,5/14 OR SP

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

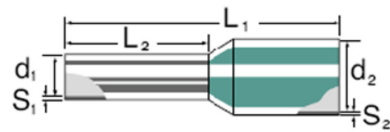

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1476230000](#)