

KQI-M2/-0,5**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Insulated cable connector in PVC or PC/PA**

- Conventional designs
- Not soldered
- With conical entry funnel, except for joint connector

General ordering data

Version	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² - 0.5 mm ²
Order No.	1492090000
Type	KQI-M2/-0,5
GTIN (EAN)	4050118301892
Qty.	100 pc(s).

KQI-M2/-0,5**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	0.29 g
------------	--------

Connectors

Conductor cross-section	0.5 mm ²	Conductor cross-section, max.	0.5 mm ²
Conductor cross-section, min.	0.1 mm ²	Connection length (l)	14 mm
Hole	M 2	Identification colour	yellow
Inside diameter of collar (d4)	2.3 mm	Inside diameter of flange (d2)	2.2 mm
Inside diameter of shaft (d1)	1 mm	Insulation	Available
Material/plastic	PA	Outside diameter of shaft (d3)	5 mm

Classifications

ETIM 6.0	EC001059	ETIM 7.0	EC001059
ETIM 8.0	EC001059	ECLASS 9.0	27-40-02-12
ECLASS 9.1	27-40-02-12	ECLASS 10.0	27-40-02-12
ECLASS 11.0	27-40-02-12	ECLASS 12.0	27-40-02-12

Approvals

ROHS	Conform
------	---------

Downloads


Engineering Data	EPLAN
Catalogues	Catalogues in PDF-format
Brochures	

KQI-M2/-0,5

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

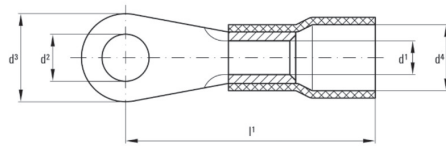

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1492090000](#)