

HSS-HF 1.6-3.2 EL Y30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

Version	Conductor and cable markers, 1.6 - 3.2 mm, yellow
Order No.	1513150000
Type	HSS-HF 1.6-3.2 EL Y30M
GTIN (EAN)	4050118320916
Qty.	1 pc(s).
compatible printer	2599430000 2599440000 1140490000

HSS-HF 1.6-3.2 EL Y30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	0.7 mm	Depth (inches)	0.028 inch
Width	5.6 mm	Width (inches)	0.22 inch
Length	30,000 mm	Length (inches)	1,181.1 inch
Net weight	238 g		

Temperatures

Operating temperature range	-55...105 °C
-----------------------------	--------------

General data

Colour	yellow	Halogen	No
Length	30,000 mm	Material	Polyolefine
Number per roll	1	Operating temperature range	-55...105 °C
Operating temperature range, max.	105 °C	Operating temperature range, min.	-55 °C
Printed characters	without	Type of printing	neutral
Width	5.6 mm		

Conductor and cable markers

Conductor O.D.	1.6 - 3.2 mm	Conductor O.D., max.	3.2 mm
Conductor O.D., min.	1.6 mm	Conductor cross-section, max.	1.5 mm ²
Conductor cross-section, min.	0.5 mm ²	Cross-section for connected wire	0.5 - 1.5 mm ²
Halogen	No	Rate of shrinkage	2:1
Recommended shrinking temperature	90 °C		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ECLASS 9.0	27-40-04-01
ECLASS 9.1	27-40-04-01	ECLASS 10.0	27-40-04-01
ECLASS 11.0	27-28-11-02		

Important note

Product information	External roll holder 1302920000 necessary
---------------------	---

Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	NFX 70-100-1 2006 + NF X 70-100-2 2006 BS EN 45545-2 2013+A1 2015 BS EN ISO 4589-2 1999
Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format

HSS-HF 1.6-3.2 EL Y30M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Drawings



HSS-HF 1.6-3.2 EL Y30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

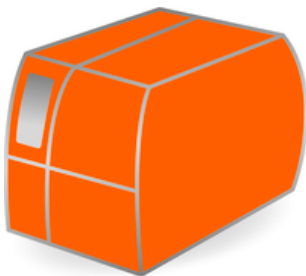
Germany

www.weidmueller.com**Accessories****THM MULTIMARK**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP EXT.RH
Order No.	1302920000
GTIN (EAN)	4050118102307
Qty.	1 pc(s).
Type	THM MMP ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).
Type	THM MMP ROLLER 25
Order No.	1357430000
GTIN (EAN)	4050118160253
Qty.	1 pc(s).

THM MULTIMARK PLUS

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MM PLUS ROLLER 110
Order No.	2672590000
GTIN (EAN)	4050118708097
Qty.	1 pc(s).

HSS-HF 1.6-3.2 EL Y30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON HSS HF EL 40/300	Version
Order No.	1426210000	Ink ribbon
GTIN (EAN)	4050118228823	
Qty.	1 pc(s).	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1513150000](#)