

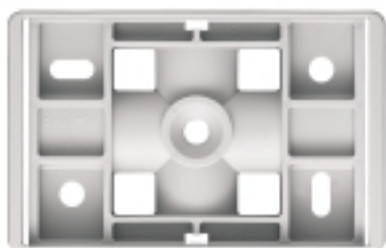
CC-H 85/54 GR**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.comwww.weidmueller.com**General ordering data**

Version	ClipCard, Accessories, 90 x 58 mm, grey
Order No.	1631640002
Type	CC-H 85/54 GR
GTIN (EAN)	4008190465261
Qty.	20 pc(s).

CC-H 85/54 GR

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technical data

Dimensions and weights

Depth	13 mm	Depth (inches)	0.512 inch
Height	90 mm	Height (inches)	3.543 inch
Width	58 mm	Width (inches)	2.283 inch
Net weight	20.9 g		

Temperatures

Operating temperature range	-40...100 °C
-----------------------------	--------------

General data

Colour	grey	Halogen	No
Material	Polyamide 66	Material colour according to resistance code	8
Number of markers per combination	1 MultiCard = Accessories	Operating temperature range	-40...100 °C
Operating temperature range, max.	100 °C	Operating temperature range, min.	-40 °C
Recommended industries	Machinery	UL 94 flammability rating	V-2
Width	58 mm		

Device markers

Halogen	No
---------	----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1631640002](#)