

**LM WO 18/34 WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration



Self-adhesive polyester labels which are suitable for A4 office laser printer.

**General ordering data**

|            |                                                                     |
|------------|---------------------------------------------------------------------|
| Version    | LaserMark, Conductor and cable markers, 5 - 7 mm, 18 x 34 mm, white |
| Order No.  | <a href="#">1695711044</a>                                          |
| Type       | LM WO 18/34 WS                                                      |
| GTIN (EAN) | 4008190924652                                                       |
| Qty.       | 10 pc(s).                                                           |

## LM WO 18/34 WS

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |          |                 |            |
|------------|----------|-----------------|------------|
| Depth      | 0.025 mm | Depth (inches)  | 0.001 inch |
| Height     | 18 mm    | Height (inches) | 0.709 inch |
| Width      | 34 mm    | Width (inches)  | 1.339 inch |
| Net weight | 10.2 g   |                 |            |

## Temperatures

|                             |              |
|-----------------------------|--------------|
| Operating temperature range | -40...150 °C |
|-----------------------------|--------------|

## General data

|                                              |              |                                   |                                                |
|----------------------------------------------|--------------|-----------------------------------|------------------------------------------------|
| Adhesive                                     | Acrylate     | Colour                            | white                                          |
| Halogen                                      | No           | Material                          | Polyester film                                 |
| Material colour according to resistance code | 9            | Number of markers per combination | 1 Label sheet = 88 Conductor and cable markers |
| Number per sheet                             | 88           | Operating temperature range       | -40...150 °C                                   |
| Operating temperature range, max.            | 150 °C       | Operating temperature range, min. | -40 °C                                         |
| Size of labelling field                      | 18 x 12.7 mm | Type of printing                  | neutral                                        |
| UL 94 flammability rating                    | V-0          | Version                           | Self-adhesive                                  |
| Width                                        | 34 mm        |                                   |                                                |

## Conductor and cable markers

|                               |                   |                                  |                        |
|-------------------------------|-------------------|----------------------------------|------------------------|
| Conductor O.D.                | 5 - 7 mm          | Conductor O.D., max.             | 7 mm                   |
| Conductor O.D., min.          | 5 mm              | Conductor cross-section, max.    | 16 mm <sup>2</sup>     |
| Conductor cross-section, min. | 6 mm <sup>2</sup> | Cross-section for connected wire | 6 - 16 mm <sup>2</sup> |
| Halogen                       | No                | Text field height                | 13 mm                  |
| Text field width              | 17.8 mm           |                                  |                        |

## Classifications


|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001530    | ETIM 7.0    | EC001530    |
| ETIM 8.0    | EC001530    | ECLASS 9.0  | 27-40-04-01 |
| ECLASS 9.1  | 27-40-04-01 | ECLASS 10.0 | 27-40-04-01 |
| ECLASS 11.0 | 27-28-11-02 |             |             |

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Downloads

|                  |                                          |
|------------------|------------------------------------------|
| Engineering Data | <a href="#">CAD data – STEP</a>          |
| Engineering Data | <a href="#">EPLAN, WSCAD, Zuken E3.S</a> |
| Catalogues       | <a href="#">Catalogues in PDF-format</a> |

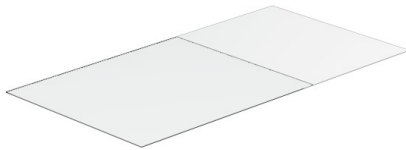

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1695711044](#)