

**SKMU M63 MS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

**General ordering data**

|            |                                                                    |
|------------|--------------------------------------------------------------------|
| Version    | SKMU MS (brass locknut), Locknut, M 63, 6 mm, Brass, nickel-plated |
| Order No.  | <a href="#">1737050000</a>                                         |
| Type       | SKMU M63 MS                                                        |
| GTIN (EAN) | 4008190956523                                                      |
| Qty.       | 25 pc(s).                                                          |

## SKMU M63 MS

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |        |
|------------|--------|
| Net weight | 10.2 g |
|------------|--------|

## Environmental Product Compliance

|            |                |      |                                      |
|------------|----------------|------|--------------------------------------|
| REACH SVHC | Lead 7439-92-1 | SCIP | f350dea6-3de1-42c5-a935-c4eb3e9d5e3c |
|------------|----------------|------|--------------------------------------|

## General information

|                 |                      |                  |          |
|-----------------|----------------------|------------------|----------|
| AF size 1       | 70 mm                | Cable glands     | M 63     |
| External thread | M 63                 | Halogen          | No       |
| Internal thread | M 63                 | Length of thread | 6 mm     |
| Material        | Brass, nickel-plated | O.D.             | 80.85 mm |
| Pitch of thread | 1.5 mm               | Thickness        | 6 mm     |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC000940    | ETIM 7.0    | EC000940    |
| ETIM 8.0    | EC000940    | ECLASS 9.0  | 27-14-44-24 |
| ECLASS 9.1  | 27-14-44-24 | ECLASS 10.0 | 27-14-44-24 |
| ECLASS 11.0 | 27-14-44-24 | ECLASS 12.0 | 27-14-08-05 |

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Downloads

|                  |                                          |
|------------------|------------------------------------------|
| Engineering Data | <a href="#">CAD data – STEP</a>          |
| Engineering Data | <a href="#">EPLAN, WSCAD</a>             |
| Catalogues       | <a href="#">Catalogues in PDF-format</a> |
| Brochures        |                                          |

### SKMU M63 MS

**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

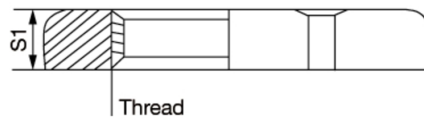

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1737050000](#)