

**THM WO 25/76 GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

THM WriteOn cable markers on reels are used for labelling conductors and cables with an outside diameter of up to 36 mm. The transparent adhesive strip fixes and protects the printing on the marker surface.

- Protection of the marking against dirt and abrasion by wrapping it with the transparent adhesive strip
- Simple and quick printing with the high-quality thermal transfer printers

**General ordering data**

|            |                                                                     |
|------------|---------------------------------------------------------------------|
| Version    | THM, Conductor and cable markers, 4.8 - 19.4 mm, 25 x 76 mm, yellow |
| Order No.  | <a href="#">1774340000</a>                                          |
| Type       | THM WO 25/76 GE                                                     |
| GTIN (EAN) | 4032248148523                                                       |
| Qty.       | 1 pc(s).                                                            |

## THM WO 25/76 GE

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |          |                 |            |
|------------|----------|-----------------|------------|
| Depth      | 0.025 mm | Depth (inches)  | 0.001 inch |
| Height     | 25 mm    | Height (inches) | 0.984 inch |
| Width      | 76 mm    | Width (inches)  | 2.992 inch |
| Net weight | 604 g    |                 |            |

## Temperatures

|                             |              |
|-----------------------------|--------------|
| Operating temperature range | -40...150 °C |
|-----------------------------|--------------|

## General data

|                                              |                       |                                   |                                            |
|----------------------------------------------|-----------------------|-----------------------------------|--------------------------------------------|
| Adhesive                                     | Polyacrylate adhesive | Colour                            | yellow                                     |
| Halogen                                      | No                    | Material                          | Polyester film                             |
| Material colour according to resistance code | 4                     | Number of markers per combination | 1 Label reel = Conductor and cable markers |
| Number per roll                              | 1,800                 | Operating temperature range       | -40...150 °C                               |
| Operating temperature range, max.            | 150 °C                | Operating temperature range, min. | -40 °C                                     |
| Size of labelling field                      | 15 x 25 mm            | Type of printing                  | neutral                                    |
| UL 94 flammability rating                    | V-0                   | Version                           | Self-adhesive                              |
| Width                                        | 76 mm                 |                                   |                                            |

## Conductor and cable markers

|                               |                      |                                  |                            |
|-------------------------------|----------------------|----------------------------------|----------------------------|
| Conductor O.D.                | 4.8 - 19.4 mm        | Conductor O.D., max.             | 19.4 mm                    |
| Conductor O.D., min.          | 4.8 mm               | Conductor cross-section, max.    | 150 mm <sup>2</sup>        |
| Conductor cross-section, min. | 0.75 mm <sup>2</sup> | Cross-section for connected wire | 0.75 - 150 mm <sup>2</sup> |
| Halogen                       | No                   | Text field height                | 15 mm                      |
| Text field width              | 25 mm                |                                  |                            |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001530    | ETIM 7.0    | EC001530    |
| ETIM 8.0    | EC001530    | ECLASS 9.0  | 27-40-04-01 |
| ECLASS 9.1  | 27-40-04-01 | ECLASS 10.0 | 27-40-04-01 |
| ECLASS 11.0 | 27-28-11-02 | ECLASS 12.0 | 27-28-11-02 |

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Downloads

|                  |                                          |
|------------------|------------------------------------------|
| Engineering Data | <a href="#">CAD data – STEP</a>          |
| Engineering Data | <a href="#">EPLAN, WSCAD, Zuken E3.S</a> |
| Catalogues       | <a href="#">Catalogues in PDF-format</a> |

### THM WO 25/76 GE

**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

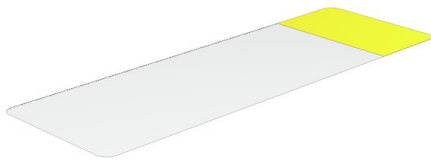

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1774340000](#)