

**SKMU EMV M12****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

**General ordering data**

Version	SKMU MS EMV (brass locknut - EMC), Locknut, M 12, 3.6 mm, Brass, nickel-plated
Order No.	<a href="#">1777610000</a>
Type	SKMU EMV M12
GTIN (EAN)	4032248157884
Qty.	100 pc(s).

Creation date January 27, 2022 11:13:40 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

## SKMU EMV M12

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Net weight	1.41 g
------------	--------

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

## General information

AF size 1	15 mm	Cable glands	metric
External thread	M 12	Halogen	No
Internal thread	M 12 x 1.5	Length of thread	3.6 mm
Material	Brass, nickel-plated	O.D.	16.17 mm
Pitch of thread	1.5 mm	Thickness	1 mm

## Classifications

ETIM 6.0	EC000940	ETIM 7.0	EC000940
ETIM 8.0	EC000940	ECLASS 9.0	27-14-44-24
ECLASS 9.1	27-14-44-24	ECLASS 10.0	27-14-44-24
ECLASS 11.0	27-14-44-24		

## Approvals

ROHS	Conform
------	---------

## Downloads

Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">EPLAN, WSCAD</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	


**Data sheet**

**SKMU EMV M12**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

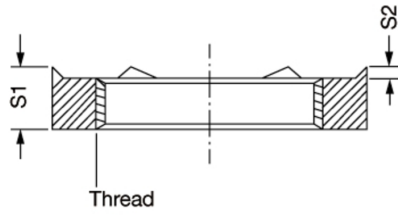

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1777610000](#)