

**HDC 40D TSBU 1M25G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Version	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
Order No.	<a href="#">1787010000</a>
Type	HDC 40D TSBU 1M25G
GTIN (EAN)	4032248204250
Qty.	1 pc(s).

**HDC 40D TSB 1M25G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Depth	93.3 mm	Depth (inches)	3.673 inch
Height	76 mm	Height (inches)	2.992 inch
Width	59 mm	Width (inches)	2.323 inch
Net weight	262 g		

**Temperatures**

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1	
Chemical resistance	Substance	Acetone
	Chemical resistance	Conditionally resistant
	Substance	Drilling oil
	Chemical resistance	Resistant
	Substance	Diesel
	Chemical resistance	Resistant
	Substance	Ethyl alcohol
	Chemical resistance	Resistant
	Substance	Transmission oil
	Chemical resistance	Resistant
	Substance	Hydraulic oil
	Chemical resistance	Resistant
	Substance	Coolant
	Chemical resistance	Resistant
	Substance	Petroleum benzine
	Chemical resistance	Resistant
	Substance	Sweat
	Chemical resistance	Resistant
	Substance	Premium gasoline
	Chemical resistance	Conditionally resistant
	Substance	Water
	Chemical resistance	Resistant
	Substance	UV
	Chemical resistance	Unstable
Substance	Ozone	
Chemical resistance	Unstable	

**Dimensions**

Cable entry	w. threading	Height of housing B	76 mm
Total length housing	93.3 mm	Width housing C	43 mm

**General data**

EMC housings	No	Housing main material	diecast aluminium
Material of locking element	Stainless steel, rust-proof	Protection degree	IP65 (in plugged condition)
Surface finish	Powder coating		

## HDC 40D TSBU 1M25G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Version

BG	6	Cable entry	w. threading
Clamp version	Side-locking clamp	Colour (RAL)	RAL 7035
Design	high	Design of housing	Cable entry from side, Plug housing
Design of locking system	Side-locking clamp on lower side	Internal thread	M 25
Number of cable entry on top	0	Number of cable entry sideways	1
Size	6	Size of cable entries	M 25
Suitable for ModuPlug®	Yes	Top part/bottom part/lid	upper part
Type	Plug		

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ECLASS 9.0	27-44-02-02
ECLASS 9.1	27-44-02-02	ECLASS 10.0	27-44-02-02
ECLASS 11.0	27-44-02-02		

## Approvals

Approvals



ROHS	Conform
UL File Number Search	E92202

## Downloads


Approval/Certificate/Document of Conformity	<a href="#">Manufacturer's declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">EPLAN, WSCAD</a>
Technical Documentation	<a href="#">1787010000_HDC_40D_TSBU_1M25G_STP_Blatt_1.pdf</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">FL FIELDWIRING EN</a>

## HDC 40D TSBU 1M25G

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

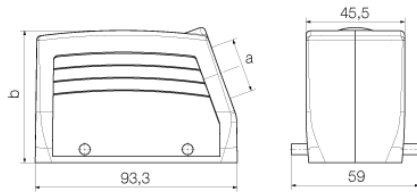

## HDC 40D TSBU 1M25G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Cover



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 16B DMDQ 2QB	Version
Order No.	<a href="#">1665270000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4008190421977	
Qty.	1 pc(s).	

## Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 16B ABU	Version
Order No.	<a href="#">1208600000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Side-locking clamp not replaceable, Standard
GTIN (EAN)	4008190881351	
Qty.	1 pc(s).	

## HDC 40D TSBU 1M25G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	HDC 16B ABU N	Version
Order No.	<a href="#">2488590000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Side-locking clamp replaceable, Standard
GTIN (EAN)	4050118541526	
Qty.	1 pc(s).	

## Coupling hood



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 40D KBU 1PG21G	Version
Order No.	<a href="#">1657310000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190410360	
Qty.	1 pc(s).	
Type	HDC 40D KBU 1M32G	Version
Order No.	<a href="#">1787190000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204533	
Qty.	1 pc(s).	
Type	HDC 40D KBU 1M25G N	Version
Order No.	<a href="#">2559890000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4050118676440	
Qty.	1 pc(s).	
Type	HDC 40D KBU 2M32G N	Version
Order No.	<a href="#">2545510000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4050118558333	
Qty.	1 pc(s).	
Type	HDC 40D KBU 1M25G	Version
Order No.	<a href="#">1787200000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248204540	
Qty.	1 pc(s).	
Type	HDC 40D KBU 1M32G N	Version
Order No.	<a href="#">2559900000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4050118673265	
Qty.	1 pc(s).	
Type	HDC 16B KBU 1PG21G	Version
Order No.	<a href="#">1657270000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190410322	
Qty.	1 pc(s).	

Creation date January 28, 2022 1:14:39 AM CET

## HDC 40D TSB 1M25G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmuller.com

## Accessories

Type	HDC 40D KBU 1PG29G	Version
Order No.	<a href="#">1967670000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4032248670178	
Qty.	1 pc(s).	

## Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 40D SBU 2M32G	Version
Order No.	<a href="#">1787110000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204458	
Qty.	1 pc(s).	
Type	HDC 16B SBU 1M25G	Version
Order No.	<a href="#">1899980000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248520718	
Qty.	1 pc(s).	
Type	HDC 16B SBU 1M25G N	Version
Order No.	<a href="#">2560740000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4050118673234	
Qty.	1 pc(s).	
Type	HDC 40D SBU 2M25G	Version
Order No.	<a href="#">1787120000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248204465	
Qty.	1 pc(s).	
Type	HDC 16B SBU 2M25G	Version
Order No.	<a href="#">1788240000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205776	
Qty.	1 pc(s).	
Type	HDC 16B SBU 2PG21G	Version
Order No.	<a href="#">1656730000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190409746	
Qty.	1 pc(s).	
Type	HDC 16B SBU 2M25G N	Version
Order No.	<a href="#">2560930000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4050118673531	
Qty.	1 pc(s).	

Creation date January 28, 2022 1:14:39 AM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

## HDC 40D TSB 1M25G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	HDC 16B SBU 1PG21G N	Version
Order No.	<a href="#">2560940000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4050118676716	
Qty.	1 pc(s).	
Type	HDC 40D SBU 1PG29G N	Version
Order No.	<a href="#">2560770000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4050118893595	
Qty.	1 pc(s).	
Type	HDC 16B SBU 1PG21G	Version
Order No.	<a href="#">1656720000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190409739	
Qty.	1 pc(s).	
Type	HDC 40D SBU 1M25G	Version
Order No.	<a href="#">1902970000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248592951	
Qty.	1 pc(s).	
Type	HDC 40D SBU 2M25G N	Version
Order No.	<a href="#">2561020000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4050118676914	
Qty.	1 pc(s).	
Type	HDC 40D SBU 1M32G N	Version
Order No.	<a href="#">2561030000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4050118676464	
Qty.	1 pc(s).	
Type	HDC 40D SBU 2PG21G	Version
Order No.	<a href="#">1656810000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190409821	
Qty.	1 pc(s).	
Type	HDC 40D SBU 1M32G	Version
Order No.	<a href="#">1902990000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248592968	
Qty.	1 pc(s).	
Type	HDC 16B SBU 2PG21G N	Version
Order No.	<a href="#">2560950000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4050118676921	
Qty.	1 pc(s).	
Type	HDC 40D SBU 1PG29G	Version
Order No.	<a href="#">1656830000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190409845	
Qty.	1 pc(s).	
Type	HDC 40D SBU 2PG29G	Version
Order No.	<a href="#">1656840000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190409852	
Qty.	1 pc(s).	
Type	HDC 40D SBU 2M32G N	Version
Order No.	<a href="#">2561040000</a>	HDC enclosures, Size: 6, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4050118676457	
Qty.	1 pc(s).	



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1787010000](#)