

IE-PS-LCD-MM**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030


32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

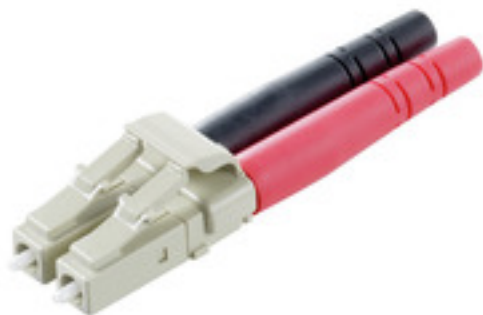

FO LC duplex plug-in connectors according to IEC
61754-20 for wire outer diameters 2.6 to 3 mm

General ordering data

Version	FO connector, Plug LC duplex, multimode, IP20
Order No.	1962970000
Type	IE-PS-LCD-MM
GTIN (EAN)	4032248645152
Qty.	1 pc(s).

IE-PS-LCD-MM

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 4.22 g

Temperatures

Operating temperature -40 °C...70 °C

Humidity

0...93 % rel. humidity

Environmental Product Compliance

REACH SVHC

SCIP

67cf1078-
beca-4687-860b-
dc475a6ec24a

Lead 7439-92-1

General data

Bending protection sleeve material	TPE	Cable pull-out force, min.	100 N
Colour	Miscellaneous	Connection 1	LC Duplex
Connection 2	gluing, crimping, polishing	Crimp barrel material	Copper, nickel-plated
Description of article	Plug LC duplex, multimode	Dust protection cap material	TPE
Ferrule material	Zirconia	Fibre type	GOF, Multimode
Housing main material	PC UL 94 V0	Housing material, insert	Zinc diecast
Humidity	0...93 % rel. humidity	Insertion loss	≤ 0.4 dB
Plugging cycles	1000	Pressure spring material	Stainless steel, rust-proof
Protection degree	IP20	Return loss (attenuation)	≥ 30 dB
Sheath diameter, max.	3 mm	Sheath diameter, min.	2.8 mm
Single conductor diameter, max	1.4 mm	Single conductor diameter, min	0.6 mm

General standards

Connector standard IEC 61754-20

Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ECLASS 9.0	19-17-01-22
ECLASS 9.1	19-17-01-22	ECLASS 10.0	19-17-01-22
ECLASS 11.0	19-17-01-22	ECLASS 12.0	19-17-01-22

Approvals

Approvals



ROHS

Conform

IE-PS-LCD-MM

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

Technical data

info@weidmueller.com

www.weidmueller.com

Downloads

Approval/Certificate/Document of
Conformity

[GOST Approval](#)

Engineering Data

[WSCAD](#)

User Documentation

[MAN IE GUIDE DE](#)

[MAN IE GUIDE EN](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)

[PI PROFINET CABLING EN](#)

[PI PROFINET CABLING EN](#)

IE-PS-LCD-MM

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0


Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Drawings

Dimensioned drawing

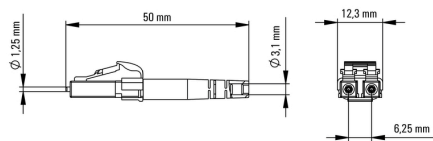

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1962970000](#)