

IE-BH-V05M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

HDC plug-in connector according to IEC 61076-3-106
ver.5 in metal, empty housing

General ordering data

Version	Empty enclosure, Flange-mounted housing, Variant 5 to IEC 61076-3-106, IP67
Order No.	1963530000
Type	IE-BH-V05M
GTIN (EAN)	4032248645626
Qty.	10 pc(s).

IE-BH-V05M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22.4 mm	Depth (inches)	0.882 inch
Height	40 mm	Height (inches)	1.575 inch
Width	28 mm	Width (inches)	1.102 inch
Net weight	33.6 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1, Potassium perfluorobutane sulfonate 29420-49-3
------------	--

General data

Colour	Miscellaneous	Housing main material	diecast aluminium
Plugging cycles	750	Protection degree	IP67
Type of mounting	2 screws		

General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 5
-------------------------	---------	--------------------	------------------------

Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ECLASS 9.0	27-18-27-02
ECLASS 9.1	27-18-27-02	ECLASS 10.0	27-18-27-02
ECLASS 11.0	27-18-27-02		

Approvals

Approvals



UL File Number Search	E316369
-----------------------	---------

Downloads

Approval/Certificate/Document of Conformity	GOST Approval DUXR.E316369
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN FL FIELDWIRING EN PI PROFINET CABLING EN

Creation date January 29, 2022 12:27:53 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.


IE-BH-V05M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

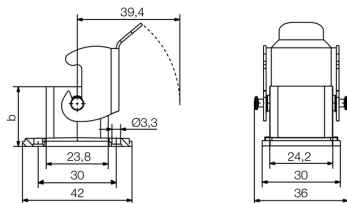

IE-BH-V05M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Dust caps



For protecting your devices against dust and dirt.

Dust caps

General ordering data

Type	IE-BP-V05M	Version
Order No.	1968930000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248692125	
Qty.	10 pc(s).	

RJ45



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-BI-RJ45-FJ-P	Version
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-C	Version
Order No.	1962840000	RJ45 insert socket, Bulkhead inserts coupler
GTIN (EAN)	4032248645046	
Qty.	1 pc(s).	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1963530000](#)