

FBCON SS CG 4WAY**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

For standard industrial applications (non-hazardous areas), PROFIBUS PA junction boxes and limiters are available as 1-way, 2-way, 4-way, and 8-way distributors. FBCon limiters are designed to protect connected field devices from over voltages and short circuits. As voltage-limiting protective elements, suppressor diodes are used. Due to the integrated current limitation, the segment is also protected against short circuit on a spur line. EMC cable glands, protection class IP66 and a wide operating temperature range safely protect your connections in harsh environments.

Functionality

- EMC cable glands for trunk and spurs
- M12 connector for spurs
- External earthing stud
- Pressure equalizing element
- Protection class IP66
- Aluminium and stainless-steel versions
- Profibus PA / Foundation Fieldbus compatible

Note: The use of FBCon products with aluminum enclosures and / or M12 connectors is not recommended in strongly saline environments.

General ordering data

Version	Standard distributor, 4-way distributor, IP66
Order No.	8703450000
Type	FBCON SS CG 4WAY
GTIN (EAN)	4032248398355
Qty.	1 pc(s).

FBCON SS CG 4WAY

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	36 mm	Height (inches)	1.417 inch
Width	80 mm	Width (inches)	3.15 inch
Length	125 mm	Length (inches)	4.921 inch
Net weight	866 g		

Temperatures

Storage temperature	-40 °C...80 °C	Ambient temperature	-40 °C...80 °C
Operating temperature	-40 °C...80 °C		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

Technical properties

Protection degree	IP66
-------------------	------

Technical data

Bus system	Profibus-PA, Foundation Fieldbus	Cable entry	Stainless steel cable gland
Conductor O.D.	-	Connection type PE	Spur line with cable gland
Housing main material	Stainless steel, rust-proof	Type of distribution	4-way distributor
Type of mounting	surface-mounted	Colour	Miscellaneous
Housing main material	Stainless steel, rust-proof	Protection degree	IP66
Type of mounting	surface-mounted		

Classifications

ETIM 6.0	EC001604	ETIM 7.0	EC001604
ETIM 8.0	EC001604	ECLASS 9.0	27-24-26-08
ECLASS 9.1	27-24-26-08	ECLASS 10.0	27-24-26-08
ECLASS 11.0	27-24-26-08		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	Certification EAC Certification UL
Software	Software unit – WI-Segment-Calculator
User Documentation	assembly instruction german / english Application-Guide-Planning and installing Fieldbus networks-using-FBCon_english_deutsch FBCon Segment Calculator_english
Catalogues	Catalogues in PDF-format
Brochures	

FBCON SS CG 4WAY

Weidmüller Interface GmbH & Co. KG


Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Drawings

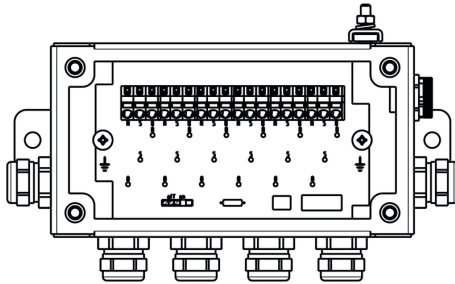

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[8703450000](#)