

SCHUKO TS35**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- Simple installation in electrical cabinet
- TS35 module can be mounted on rail
- VDE mark of conformity
- Two-pole with earthing contact

General ordering data

Version	Electrical-cabinet socket outlet TS 35
Order No.	8734580000
Type	SCHUKO TS35
GTIN (EAN)	4032248407835
Qty.	10 pc(s).

SCHUKO TS35

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	45 mm	Height (inches)	1.772 inch
Width	76 mm	Width (inches)	2.992 inch
Length	60 mm	Length (inches)	2.362 inch
Net weight	95 g		

Temperatures

Storage temperature	-20 °C...40 °C	Operating temperature	-20 °C...40 °C
---------------------	----------------	-----------------------	----------------

Input

Rated current	16 A
---------------	------

General data

Colour	beige	Design	Installation housing
Rail	TS 35		

Insulation coordination

Pollution severity	2	Surge voltage category	II
--------------------	---	------------------------	----

Insulation coordination acc. to EN 50178

Pollution severity	2	Surge voltage category	II
--------------------	---	------------------------	----

Classifications

ETIM 6.0	EC000125	ETIM 7.0	EC000125
ETIM 8.0	EC000125	ECLASS 9.0	27-14-40-42
ECLASS 9.1	27-14-40-42	ECLASS 10.0	27-14-40-42
ECLASS 11.0	27-14-40-42		

Approvals

Approvals



ROHS

Conform

Downloads

Approval/Certificate/Document of
Conformity[Declaration of Conformity](#)

Catalogues

[Catalogues in PDF-format](#)

SCHUKO TS35**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Crosshead screwdriver, Pozidrive**

VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

General ordering data

Type	SDIK PZ1 SL	Version
Order No.	1274730000	Screwdriver, Mounting tool
GTIN (EAN)	4050118073225	
Qty.	1 pc(s).	

W-Series

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

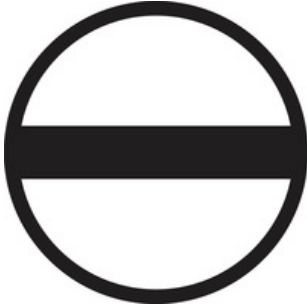
Type	WEW 35/1 V0 GF SW	Version
Order No.	1478990000	W-Series, End bracket
GTIN (EAN)	4050118286892	
Qty.	50 pc(s).	
Type	WEW 35/2 V0 GF SW	Version
Order No.	1479000000	W-Series, End bracket
GTIN (EAN)	4050118286779	
Qty.	100 pc(s).	

SCHUKO TS35**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Slotted screwdriver**

VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

General ordering data

Type	SDIS SL 0.6X3.5X100	Version
Order No.	1274660000	Screwdriver, Mounting tool
GTIN (EAN)	4050118072631	
Qty.	1 pc(s).	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[8734580000](#)