

IE-FM6D2UE0001MSD0SD0X**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Assembled IE cables, FO breakout cable, multimode, SC duplex - SC duplex, black, Core diameter 62.5 µm

General ordering data

Version	Dragline cable, SC duplex IP 20, SC duplex IP 20, 62.5 µm, PUR, 1 m
Order No.	8876440010
Type	IE-FM6D2UE0001MSD0SD0X
GTIN (EAN)	4032248609918
Qty.	1 pc(s).

IE-FM6D2UE0001MSD0SD0X

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Length	1 m	Length (inches)	39.37 inch
Net weight	72 g		

Temperatures

Storage temperature	-40 °C...80 °C	Operating temperature	-40 °C...80 °C
Installation temperature	-20 °C...60 °C		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

Standards

Connector standard	IEC 61754-4
--------------------	-------------

Fibre-optic

Attenuation	2.7 dB/km at 850 nm, ≤ 0.5 dB/km at 1300 nm	Bandwidth	200 MHz*km at 850 nm, 500 MHz*km at 1300 nm
Fibre type	GOF, Multimode, OM1	Insertion loss	≤ 0.4 dB
Return loss (attenuation)	≥ 30 dB		

Cable structure

Cable layout	Break-out dragline	Core diameter	62.5 µm
Material sheath	PUR	Primary coating	245 µm
Sheath diameter	6 mm	Sheathing colour	black

Mechanical and material properties of cable

Bending cycles	100,000	Min. bending radius, once only	25 mm
Min. bending radius, repetitive	77 mm		

Plug, left

Connector left	SC duplex IP 20
----------------	-----------------

Plug, right

Connector right	SC duplex IP 20
-----------------	-----------------

plug

Connector left	SC duplex IP 20	Connector right	SC duplex IP 20
----------------	-----------------	-----------------	-----------------

Classifications

ETIM 6.0	EC002607	ETIM 7.0	EC002607
ETIM 8.0	EC002607	ECLASS 9.0	27-06-10-03
ECLASS 9.1	27-06-10-03	ECLASS 10.0	27-06-10-03
ECLASS 11.0	27-06-10-03		

IE-FM6D2UE0001MSD0SD0X

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	WSCAD
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-FM6D2UE0001MSD0SD0X

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Detailed drawing

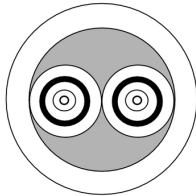

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[8876440010](#)