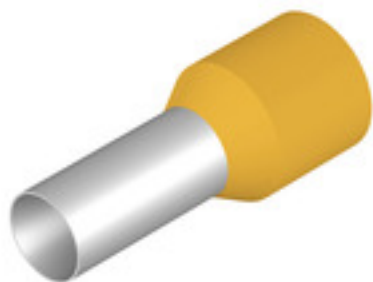


H25,0/30D 16 GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 18 mm, 16 mm, yellow
Order No.	9019280000
Type	H25,0/30D 16 GE
GTIN (EAN)	4008190038380
Qty.	50 pc(s).
Packaging	loose

H25,0/30D 16 GE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	1.188 g
------------	---------

Technical data

Description of article	Wire end ferrule with plastic collar, yellow	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Collar diameter (D2)	11.2 mm	Colour code	DIN
Conductor cross-section	25 mm ²	Contact surface diameter (D1)	7.3 mm
Contact surface length (L2)	16 mm	L1 in mm	30 mm
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 028 A
Plastic collar thickness (S2)	0.4 mm	Stripping length	18 mm
Wire connection cross section AWG, max.	AWG 3		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E499744

Downloads


Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

H25,0/30D 16 GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

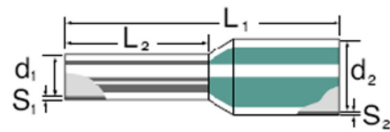www.weidmueller.com**Drawings****Drawing**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9019280000](#)