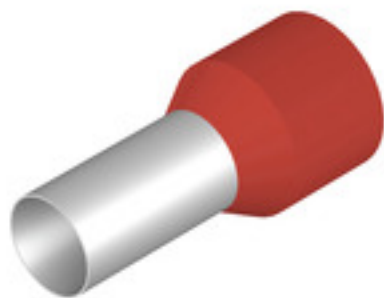


H35,0/30D 16 R**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Standard, 19 mm, 16 mm, red
Order No.	9019310000
Type	H35,0/30D 16 R
GTIN (EAN)	4008190102234
Qty.	50 pc(s).
Packaging	loose

H35,0/30D 16 R**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	1.36 g
------------	--------

Technical data

Description of article	Wire end ferrule with plastic collar, red	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	12.7 mm	Colour code	DIN
Conductor cross-section	35 mm ²	Contact surface diameter (D1)	8.3 mm
Contact surface length (L2)	16 mm	L1 in mm	30 mm
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 031 A
Plastic collar thickness (S2)	0.4 mm	Stripping length	19 mm
Wire connection cross section AWG, max.	AWG 2		

Classifications

ETIM 6.0	EC0000005	ETIM 7.0	EC0000005
ETIM 8.0	EC0000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	


H35,0/30D 16 R

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

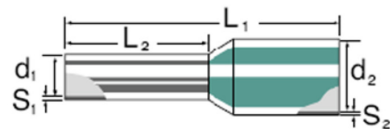

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9019310000](#)