

H4,0/26T OR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- supplied loose in polybag
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 20 mm, 18 mm, orange
Order No.	9021120000
Type	H4,0/26T OR
GTIN (EAN)	4008190092825
Qty.	100 pc(s).
Packaging	loose

Creation date January 30, 2022 12:02:27 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

H4,0/26T OR

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	0.42 g
------------	--------

Technical data

Description of article	Wire end ferrule with plastic collar, orange	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Collar diameter (D2)	4.8 mm	Colour code	Telemecanique
Conductor cross-section	4 mm ²	Contact surface diameter (D1)	2.8 mm
Contact surface length (L2)	18 mm	L1 in mm	26 mm
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 023 A
Plastic collar thickness (S2)	0.3 mm	Stripping length	20 mm
Wire connection cross section AWG, max.	AWG 12		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	


H4,0/26T OR

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

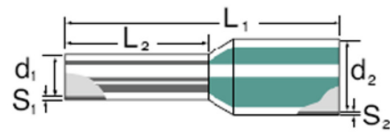

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9021120000](#)