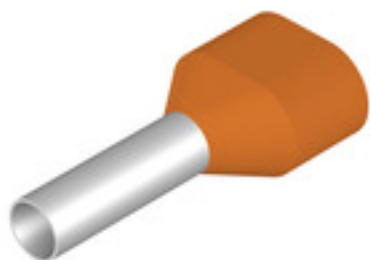


H4,0/22T ZH OR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- supplied loose in poly-bag
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, orange
Order No.	9037670000
Type	H4,0/22T ZH OR
GTIN (EAN)	4008 190493431
Qty.	100 pc(s).
Packaging	loose

H4,0/22T ZH OR

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	0.48 g
------------	--------

Technical data

Description of article	Twin wire end ferrule, orange	Version	Twin wire-end ferrule
------------------------	-------------------------------	---------	-----------------------

Wire-end ferrules

Collar height (A)	9 mm	Collar width (B)	5.2 mm
Colour code	Telemecanique	Conductor cross-section	4 mm ²
Contact surface diameter (D1)	3.5 mm	Contact surface length (L2)	12 mm
L1 in mm	22 mm	Metal sleeve thickness (S1)	0.2 mm
Plastic collar thickness (S2)	0.5 mm	Stripping length	15 mm
Wire connection cross section AWG, max.	AWG 12		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E499744

Downloads


Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

H4,0/22T ZH OR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

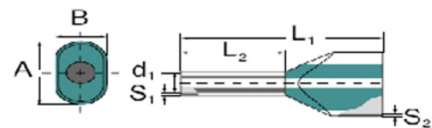www.weidmueller.com**Drawings****Drawing**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9037670000](#)