

CTI 6 G**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Crimping tools for insulated connectors**

cable lugs, terminal pins, parallel and serial connectors,
plug-in connectors

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- With stop for exact positioning of the contacts.
- Tested to DIN EN 60352 part 2

General ordering data

Version	Pressing tool, Tool for insulated cable connectors, 0.5mm ² , 6mm ² , Oval crimping, Parallel crimp
Order No.	9202850000
Type	CTI 6 G
GTIN (EAN)	4032248517855
Qty.	1 pc(s).

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Width	250 mm	Width (inches)	9.842 inch
Weight	747 g	Net weight	689.78 g

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

Technical data

Description of article	Crimping tool for insulated connectors, 0.5-6 mm ²	Version	Mechanical, without interchangeable inserts
------------------------	---	---------	---

Description of contact

Conductor cross-section, max. AWG	AWG 10	Conductor cross-section, min. AWG	AWG 21
Crimping range, max.	6 mm ²	Crimping range, min.	0.5 mm ²
Type of contact	Insulated connector		

tool data crimping

Crimping profile 1, max.	1.5 mm ²	Crimping profile 1, min.	0.5 mm ²
Crimping profile 2, max.	2.5 mm ²	Crimping profile 2, min.	1.1 mm ²
Crimping profile 3, max.	6 mm ²	Crimping profile 3, min.	2.6 mm ²
Crimping type/profile	Oval crimping, Parallel crimp		

Classifications

ETIM 6.0	EC000168	ETIM 7.0	EC000168
ETIM 8.0	EC000168	ECLASS 9.0	21-04-38-11
ECLASS 9.1	21-04-38-11	ECLASS 10.0	21-04-38-11
ECLASS 11.0	21-04-38-11		

Important note

Product information	Not suitable for solid conductors
---------------------	-----------------------------------

Approvals

Approvals



Downloads


User Documentation	Manual
Catalogues	Catalogues in PDF-format
Brochures	

CTI 6 G

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

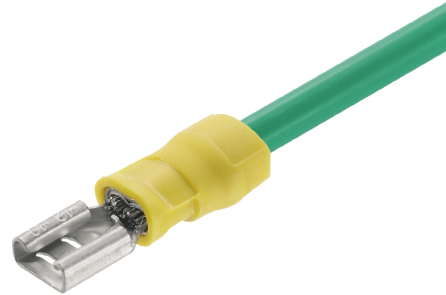

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Round-plug sleeves


Fully-insulated round-plug sleeves made from PVC with copper sleeve

- Commercially available designs
- Not soldered
- With conical entry funnel

General ordering data

Type	VRSHV/0,5-1,0	Version
Order No.	1491980000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0,5 mm ² - 1
GTIN (EAN)	4050118301939	mm ²
Qty.	100 pc(s).	
Type	LID 1,5F4 RF	Version
Order No.	9200700000	cable lug, terminal end, Insulated cable connector, 0,5 mm ² - 1,5
GTIN (EAN)	4032248410545	mm ² , red
Qty.	100 pc(s).	
Type	LID 6,0F5 RF	Version
Order No.	9200720000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	4032248410569	mm ² , yellow
Qty.	100 pc(s).	
Type	VRSHVI/1,5-2,5	Version
Order No.	1491990000	cable lug, terminal end, Insulated cable connector, 2,5 mm ² , 1,5 mm ² -
GTIN (EAN)	4050118301878	2,5 mm ²
Qty.	100 pc(s).	
Type	LID 2,5F5 RF	Version
Order No.	9200710000	cable lug, terminal end, Insulated cable connector, 1,5 mm ² - 2,5
GTIN (EAN)	4032248410552	mm ² , blue
Qty.	100 pc(s).	
Type	VRSHVI/4,0-6,0	Version
Order No.	1492010000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301960	mm ²
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Hook-type cable lugs

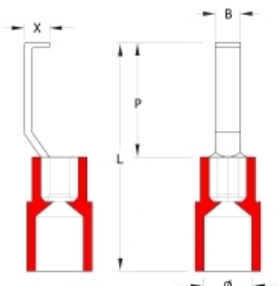

The use of insulated connectors guarantees users a permanent and consistent quality for their electrical connections.

In addition, they bring advantages during installation.

General ordering data

Type	HBT 6,0 - 4,6 GE	Version
Order No.	1216230000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6 mm ² , yellow
GTIN (EAN)	4050118000337	
Qty.	100 pc(s).	
Type	HOOKBLA 1,0-2,5 SW	Version
Order No.	9036300000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1 mm ² - 2.5 mm ² , 16.75 mm
GTIN (EAN)	4032248175932	
Qty.	100 pc(s).	
Type	HBT 1,5 - 3,0 RT	Version
Order No.	1312440000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5 mm ² , red
GTIN (EAN)	4050118115055	
Qty.	100 pc(s).	
Type	HBT 2,5 - 3,0 BL	Version
Order No.	1312450000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5 mm ² , blue
GTIN (EAN)	4050118115130	
Qty.	100 pc(s).	
Type	HOOKBLA 0,25-1,5 SW	Version
Order No.	9036290000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.25 mm ² - 1.5 mm ² , 16.75 mm
GTIN (EAN)	4032248175925	
Qty.	100 pc(s).	
Type	HBT 2,5 - 4,6 BL	Version
Order No.	1233330000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5 mm ² , blue
GTIN (EAN)	4050118016901	
Qty.	100 pc(s).	
Type	HBT 6,0 - 3,0 GE	Version
Order No.	1312470000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6 mm ² , yellow
GTIN (EAN)	4050118114980	
Qty.	100 pc(s).	
Type	HBT 1,5 - 4,6 RT	Version
Order No.	1233340000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5 mm ² , red
GTIN (EAN)	4050118210972	
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Round plug

**Insulated circular plug made from PVC with copper sleeve**

- Commercially available designs
- Not soldered
- With conical entry funnel

General ordering data

Type	LID 6M5 R	Version
Order No.	9200690000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6 mm ² , yellow
GTIN (EAN)	40322484 10538	
Qty.	100 pc(s).	
Type	VRSTI/0,5-1,0	Version
Order No.	1492040000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1 mm ²
GTIN (EAN)	4050118301779	
Qty.	100 pc(s).	
Type	LID 2,5M5 R	Version
Order No.	9200680000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5 mm ² , blue
GTIN (EAN)	40322484 10521	
Qty.	100 pc(s).	
Type	VRSTI/4,0-6,0	Version
Order No.	1492060000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6 mm ²
GTIN (EAN)	4050118301885	
Qty.	100 pc(s).	
Type	VRSTI/1,5-2,5	Version
Order No.	1492050000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² - 2.5 mm ²
GTIN (EAN)	4050118301861	
Qty.	100 pc(s).	
Type	LID 1,5M4 R	Version
Order No.	9200670000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5 mm ² , red
GTIN (EAN)	40322484 10514	
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cable-lug sleeves, fully insulated



Fully-insulated tab-connector sleeves made from PVC with copper sleeve

- Commercially available designs
- Not soldered
- With conical entry funnel

General ordering data

Type	VFSKHV/0,5-1,0/485	Version
Order No.	1491880000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0,5 mm ² - 1
GTIN (EAN)	4050118301748	mm ²
Qty.	100 pc(s).	
Type	LIF 2,5F638 RF	Version
Order No.	9200650000	cable lug, terminal end, Insulated cable connector, 1,5 mm ² - 2,5
GTIN (EAN)	4032248410491	mm ² , blue
Qty.	100 pc(s).	
Type	VFSKHV/0,5-1,0/488	Version
Order No.	1491890000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0,5 mm ² - 1
GTIN (EAN)	4050118301786	mm ²
Qty.	100 pc(s).	
Type	LIF 1,5F638 RF	Version
Order No.	9200640000	cable lug, terminal end, Insulated cable connector, 0,5 mm ² - 1,5
GTIN (EAN)	4032248410484	mm ² , red
Qty.	100 pc(s).	
Type	VFSKHV/1,5-2,5/485	Version
Order No.	1491920000	cable lug, terminal end, Insulated cable connector, 2,5 mm ² , 1,5 mm ² -
GTIN (EAN)	4050118301694	2,5 mm ²
Qty.	100 pc(s).	
Type	VFSKHV/0,5-1,0/638	Version
Order No.	1491910000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0,5 mm ² - 1
GTIN (EAN)	4050118301847	mm ²
Qty.	100 pc(s).	
Type	VFSKHV/4,0-6,0/638	Version
Order No.	1491950000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301946	mm ²
Qty.	100 pc(s).	
Type	VFSKHV/0,5-1,0/288	Version
Order No.	1491870000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0,5 mm ² - 1
GTIN (EAN)	4050118301908	mm ²
Qty.	100 pc(s).	
Type	LIF 6F638 RF	Version
Order No.	9200660000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	4032248410507	mm ² , yellow
Qty.	100 pc(s).	
Type	VFSKHV/1,5-2,5/488	Version
Order No.	1491930000	cable lug, terminal end, Insulated cable connector, 2,5 mm ² , 1,5 mm ² -
GTIN (EAN)	4050118301762	2,5 mm ²
Qty.	100 pc(s).	

Creation date January 30, 2022 4:06:26 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	VFSKHV/0,5-1,0/285	Version
Order No.	1491860000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301915	mm ²
Qty.	100 pc(s).	
Type	VFSKHV/1,5-2,5/638	Version
Order No.	1491940000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301922	2.5 mm ²
Qty.	100 pc(s).	

Ring cable lugs



Insulated ring-cable connector made from PVC

- Commercially available designs
- Not soldered
- With conical entry funnel

General ordering data

Type	LIR 2,5M3 V	Version
Order No.	9200150000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248409778	2.5 mm ²
Qty.	100 pc(s).	
Type	LIR 1,5M4 V	Version
Order No.	9200090000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248409853	1.5 mm ²
Qty.	100 pc(s).	
Type	LIR 6M10 V	Version
Order No.	9200270000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4032248410095	mm ²
Qty.	100 pc(s).	
Type	LIR 1,5M6 V	Version
Order No.	9200110000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248409730	1.5 mm ²
Qty.	100 pc(s).	
Type	LIR 2,5M5 V	Version
Order No.	9200180000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248409808	2.5 mm ²
Qty.	100 pc(s).	
Type	LIR 1,5M3,5 V	Version
Order No.	9200080000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248409846	1.5 mm ²
Qty.	100 pc(s).	
Type	LIR 2,5M3,5 V	Version
Order No.	9200160000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248409785	2.5 mm ²
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	LIR 1,5M8 V	Version
Order No.	9200120000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248409747	1.5 mm ²
Qty.	100 pc(s).	
Type	LIR 6M8 V	Version
Order No.	9200260000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4032248410088	mm ²
Qty.	100 pc(s).	
Type	LIR 2,5M6 V	Version
Order No.	9200190000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248410019	2.5 mm ²
Qty.	100 pc(s).	
Type	LIR 6M4 V	Version
Order No.	9200230000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4032248410057	mm ²
Qty.	100 pc(s).	
Type	LIR 1,5M5 V	Version
Order No.	9200100000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248409860	1.5 mm ²
Qty.	100 pc(s).	
Type	LIR 2,5M10 V	Version
Order No.	9200210000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248410033	2.5 mm ²
Qty.	100 pc(s).	
Type	LIR 2,5M4 V	Version
Order No.	9200170000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248409792	2.5 mm ²
Qty.	100 pc(s).	
Type	LIR 6M5 V	Version
Order No.	9200240000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4032248410064	mm ²
Qty.	100 pc(s).	
Type	LIR 1,5M10 V	Version
Order No.	2792000000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4064675073192	1.5 mm ²
Qty.	1 pc(s).	
Type	LIR 1,5M3 V	Version
Order No.	9200070000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248409839	1.5 mm ²
Qty.	100 pc(s).	
Type	LIR 6M6 V	Version
Order No.	9200250000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4032248410071	mm ²
Qty.	100 pc(s).	
Type	LIR 2,5M8 V	Version
Order No.	9200200000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248410026	2.5 mm ²
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

 
D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Parallel connectors



Insulated cable connector in PVC or PC/PA

- Conventional designs
- Not soldered
- With conical entry funnel, except for joint connector

General ordering data

Type	VPLI/0,5-1,0	Version
Order No.	1491460000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301366	mm ²
Qty.	100 pc(s).	
Type	VPLI/0,1-0,5	Version
Order No.	1491450000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² -
GTIN (EAN)	4050118301595	0.5 mm ²
Qty.	100 pc(s).	
Type	VPLI/4,0-6,0	Version
Order No.	1491480000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301359	mm ²
Qty.	100 pc(s).	
Type	VPLI/1,5-2,5	Version
Order No.	1491470000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301571	2.5 mm ²
Qty.	100 pc(s).	

Pin cable lugs



Insulated pin-cable connector made from PVC or PC/PA

- Conventional designs
- Not soldered
- With conical entry funnel

General ordering data

Type	LIP 1,5R12 V	Version
Order No.	9200460000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5
GTIN (EAN)	4032248410309	mm ² , red
Qty.	100 pc(s).	
Type	KSI/1,5-2,5	Version
Order No.	1491390000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301458	2.5 mm ²
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com

Accessories

Type	KSI/4,0-6,0	Version
Order No.	1491420000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6 mm ²
GTIN (EAN)	4050118300994	
Qty.	100 pc(s).	
Type	LIP 6R14 V	Version
Order No.	9200480000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6 mm ² , yellow
GTIN (EAN)	4032248410323	
Qty.	100 pc(s).	
Type	KSI/1,5-2,5	Version
Order No.	1491410000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² - 2.5 mm ²
GTIN (EAN)	4050118301632	
Qty.	100 pc(s).	
Type	KSI/0,1-0,5	Version
Order No.	1491370000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² - 0.5 mm ²
GTIN (EAN)	4050118301625	
Qty.	100 pc(s).	
Type	KSI/0,5-1,0	Version
Order No.	1491380000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1 mm ²
GTIN (EAN)	4050118301441	
Qty.	100 pc(s).	
Type	LIP 2,5R12 V	Version
Order No.	9200470000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5 mm ² , blue
GTIN (EAN)	4032248410316	
Qty.	100 pc(s).	

Plug-in distributor

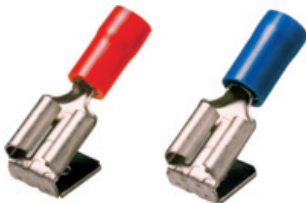

Insulated cable connector in PVC or PC/PA

- Conventional designs
- Not soldered
- With conical entry funnel, except for joint connector

General ordering data

Type	VSTVI/1,5-2,5	Version
Order No.	1491780000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² - 2.5 mm ²
GTIN (EAN)	4050118301373	
Qty.	100 pc(s).	
Type	VSTVI/0,5-1,0	Version
Order No.	1491770000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1 mm ²
GTIN (EAN)	4050118301465	
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cable-lug sleeves


Insulated tab-connector sleeves made from PVC with copper sleeve

- Commercially available designs
- Not soldered
- With conical entry funnel

General ordering data

Type	VFSKHI/0,5-1,0/488	Version
Order No.	1491670000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301502	mm ²
Qty.	100 pc(s).	
Type	VFSKHI/4,0-6,0/95 12	Version
Order No.	1491760000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301588	mm ²
Qty.	100 pc(s).	
Type	VFSKHI/0,1-0,5/285	Version
Order No.	1491620000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² -
GTIN (EAN)	4050118301526	0.5 mm ²
Qty.	100 pc(s).	
Type	VFSKHI/0,5-1,0/638	Version
Order No.	1491680000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301618	mm ²
Qty.	100 pc(s).	
Type	LIF 2,5F488 R	Version
Order No.	9200550000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248410392	2.5 mm ²
Qty.	100 pc(s).	
Type	LIF 1,5F488 R	Version
Order No.	9200530000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248410378	1.5 mm ²
Qty.	100 pc(s).	
Type	VFSKHI/1,5-2,5/485	Version
Order No.	1491690000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301717	2.5 mm ²
Qty.	100 pc(s).	
Type	LIF 1,5F288 R	Version
Order No.	9200520000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248410361	1.5 mm ²
Qty.	100 pc(s).	
Type	LIF 2,5F638 R	Version
Order No.	9200560000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4032248410408	2.5 mm ²
Qty.	100 pc(s).	
Type	VFSKHI/0,1-0,5/288	Version
Order No.	1491630000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² -
GTIN (EAN)	4050118301489	0.5 mm ²
Qty.	100 pc(s).	

Creation date January 30, 2022 4:06:26 PM CET

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	VFSKHI/0,5-1,0/288	Version
Order No.	1491650000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301519	mm ²
Qty.	100 pc(s).	
Type	VFSKHI/0,5-1,0/285	Version
Order No.	1491640000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301557	mm ²
Qty.	100 pc(s).	
Type	LIF 6F638 R	Version
Order No.	9200570000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4032248410415	mm ²
Qty.	100 pc(s).	
Type	VFSKHI/1,5-2,5/638	Version
Order No.	1491720000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301564	2.5 mm ²
Qty.	100 pc(s).	
Type	VFSKHI/1,5-2,5/285	Version
Order No.	1491730000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301700	2.5 mm ²
Qty.	100 pc(s).	
Type	VFSKHI/1,5-2,5/288	Version
Order No.	1491740000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301472	2.5 mm ²
Qty.	100 pc(s).	
Type	LIF 1,5F638 R	Version
Order No.	9200540000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4032248410385	1.5 mm ²
Qty.	100 pc(s).	
Type	VFSKHI/0,5-1,0/485	Version
Order No.	1491660000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301410	mm ²
Qty.	100 pc(s).	
Type	VFSKHI/1,5-2,5/488	Version
Order No.	1491710000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301663	2.5 mm ²
Qty.	100 pc(s).	
Type	VFSKHI/4,0-6,0/638	Version
Order No.	1491750000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301816	mm ²
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Joint connector

**Fully-insulated joint connector made from PVC or PC/PA**

- Conventional designs
- Not soldered

General ordering data

Type	VSTI/4,0-6,0	Version
Order No.	1491570000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6 mm ²
GTIN (EAN)	4050118301809	
Qty.	100 pc(s).	
Type	VSTI/0,1-0,5	Version
Order No.	1491540000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² - 0.5 mm ²
GTIN (EAN)	4050118301649	
Qty.	100 pc(s).	
Type	LIB 6B26 VF	Version
Order No.	9200510000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6 mm ² , yellow
GTIN (EAN)	4032248410354	
Qty.	100 pc(s).	
Type	LIB 1,5B25 VF	Version
Order No.	9200490000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5 mm ² , red
GTIN (EAN)	4032248410330	
Qty.	100 pc(s).	
Type	LIB 2,5B25 VF	Version
Order No.	9200500000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5 mm ² , blue
GTIN (EAN)	4032248410347	
Qty.	100 pc(s).	
Type	VSTI/1,5-2,5	Version
Order No.	1491560000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² - 2.5 mm ²
GTIN (EAN)	4050118301656	
Qty.	100 pc(s).	
Type	VSTI/0,5-1,0	Version
Order No.	1491550000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1 mm ²
GTIN (EAN)	4050118301731	
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cable-lug connector

**Insulated tab connector made from PVC with copper sleeve**

- Commercially available designs
- Not soldered
- With conical entry funnel

General ordering data

Type	FSKI/1,5-2,5/638	Version
Order No.	1491830000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301830	2.5 mm ²
Qty.	100 pc(s).	
Type	FSKI/0,5-1,0/288	Version
Order No.	1491790000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4050118301540	1 mm ²
Qty.	100 pc(s).	
Type	FSKI/0,5-1,0/488	Version
Order No.	1491810000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4050118301380	1 mm ²
Qty.	100 pc(s).	
Type	FSKI/1,5-2,5/488	Version
Order No.	1491850000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301687	2.5 mm ²
Qty.	100 pc(s).	
Type	LIF 1,5M638 R	Version
Order No.	9200580000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5
GTIN (EAN)	4032248410422	mm ² , red
Qty.	100 pc(s).	
Type	FSKI/4,0-6,0/638	Version
Order No.	1491840000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301823	mm ²
Qty.	100 pc(s).	
Type	LIF 6M638 R	Version
Order No.	9200600000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	4032248410446	mm ² , yellow
Qty.	100 pc(s).	
Type	FSKI/0,5-1,0/638	Version
Order No.	1491820000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.5 mm ² -
GTIN (EAN)	4050118301670	1 mm ²
Qty.	100 pc(s).	
Type	LIF 2,5M638 R	Version
Order No.	9200590000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5
GTIN (EAN)	4032248410439	mm ² , blue
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cable-lug sleeves with bifurcation


**Insulated tab-connector sleeves with branch,
made from PVC with copper sleeve**

- Commercially available designs
- Not soldered
- With conical entry funnel

General ordering data

Type	LIF 1,5T638 R	Version
Order No.	9200610000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5
GTIN (EAN)	40322484 10453	mm ² , red
Qty.	100 pc(s).	
Type	LIF 6T638 R	Version
Order No.	9200630000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	40322484 10477	mm ² , yellow
Qty.	100 pc(s).	
Type	LIF 2,5T638 R	Version
Order No.	9200620000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5
GTIN (EAN)	40322484 10460	mm ² , blue
Qty.	100 pc(s).	

Crimp cable lugs


Insulated cable connector in PVC or PC/PA

- Conventional designs
- Not soldered
- With conical entry funnel, except for joint connector

General ordering data

Type	KQI-M2/-0,5	Version
Order No.	1492090000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² -
GTIN (EAN)	4050118301892	0.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M12/-6	Version
Order No.	1492420000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118302189	mm ²
Qty.	100 pc(s).	
Type	KQI-M2,5/-1	Version
Order No.	1492150000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302028	mm ²
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KQI-M3/-0,5	Version
Order No.	1492100000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² -
GTIN (EAN)	4050118302011	0.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M10/-2,5	Version
Order No.	1492340000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302295	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M3,5/-1	Version
Order No.	1492180000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302080	mm ²
Qty.	100 pc(s).	
Type	KQI-M5/S/2,5	Version
Order No.	1492300000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302332	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M10/-6	Version
Order No.	1492410000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118302363	mm ²
Qty.	100 pc(s).	
Type	KQI-M4/S/-1	Version
Order No.	1492190000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302165	mm ²
Qty.	100 pc(s).	
Type	KQI-M5/-6	Version
Order No.	1492380000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118302219	mm ²
Qty.	100 pc(s).	
Type	KQI-M4/-6	Version
Order No.	1492370000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118302264	mm ²
Qty.	100 pc(s).	
Type	KQI-M12/-2,5	Version
Order No.	1492350000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302059	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M3,5/-2,5	Version
Order No.	1492270000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302134	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M5/-1	Version
Order No.	1492220000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302110	mm ²
Qty.	100 pc(s).	
Type	KQI-M8/-2,5	Version
Order No.	1492330000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302325	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M6/-1	Version
Order No.	1492230000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302400	mm ²
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KQI-M5/-2,5	Version
Order No.	1492310000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302271	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M8/-6	Version
Order No.	1492400000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118302257	mm ²
Qty.	100 pc(s).	
Type	KQI-M3/-1	Version
Order No.	1492170000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302035	mm ²
Qty.	100 pc(s).	
Type	KQI-M6/-6	Version
Order No.	1492390000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118302509	mm ²
Qty.	100 pc(s).	
Type	KQI-M5/-0,5	Version
Order No.	1492120000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² -
GTIN (EAN)	4050118302042	0.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M4/-2,5	Version
Order No.	1492290000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302172	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M8/-1	Version
Order No.	1492240000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302066	mm ²
Qty.	100 pc(s).	
Type	KQI-M3/-2,5	Version
Order No.	1492250000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302073	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M4/-0,5	Version
Order No.	1492110000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² , 0.1 mm ² -
GTIN (EAN)	4050118302103	0.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M6/-2,5	Version
Order No.	1492320000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302417	2.5 mm ²
Qty.	100 pc(s).	
Type	KQI-M10/-1	Version
Order No.	1492130000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302158	mm ²
Qty.	100 pc(s).	
Type	KQI-M4/-1	Version
Order No.	1492200000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302301	mm ²
Qty.	100 pc(s).	
Type	KQI-M4/S/-2,5	Version
Order No.	1492280000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302141	2.5 mm ²
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KQI-M2/-1	Version
Order No.	1492140000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302127	mm ²
Qty.	100 pc(s).	
Type	KQI-M5/S/-1	Version
Order No.	1492210000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302004	mm ²
Qty.	100 pc(s).	

Forked cable lugs



Insulated forked-cable connector made from PVC or PC/PA

- Conventional designs
- Not soldered
- With conical entry funnel

General ordering data

Type	LIS 6M10 V	Version
Order No.	9200450000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	4032248410293	mm ² , yellow
Qty.	50 pc(s).	
Type	KQIG-M3/-1	Version
Order No.	1492520000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302431	mm ²
Qty.	100 pc(s).	
Type	LIS 2,5M3,5 V	Version
Order No.	9200360000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5
GTIN (EAN)	4032248410187	mm ² , blue
Qty.	100 pc(s).	
Type	LIS 2,5M5 V	Version
Order No.	9200380000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5
GTIN (EAN)	4032248410224	mm ² , blue
Qty.	100 pc(s).	
Type	LIS 1,5M6 V	Version
Order No.	9200330000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5
GTIN (EAN)	4032248410156	mm ² , red
Qty.	100 pc(s).	
Type	KQIG-M6/-6	Version
Order No.	1491290000	cable lug, terminal end, Insulated cable connector, 4 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301328	mm ²
Qty.	100 pc(s).	
Type	LIS 2,5M6 V	Version
Order No.	9200390000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5
GTIN (EAN)	4032248410231	mm ² , blue
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	LIS 1,5M4 V	Version
Order No.	9200310000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5
GTIN (EAN)	4032248410132	mm ² , red
Qty.	100 pc(s).	
Type	KQIG-M4/-6	Version
Order No.	1491270000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301342	mm ²
Qty.	100 pc(s).	
Type	KQIG-M3/-2,5	Version
Order No.	1492600000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302202	2.5 mm ²
Qty.	100 pc(s).	
Type	KQIG-M4/-2,5	Version
Order No.	1492630000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302424	2.5 mm ²
Qty.	100 pc(s).	
Type	KQIG-M4/S/-2,5	Version
Order No.	1492620000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302387	2.5 mm ²
Qty.	100 pc(s).	
Type	LIS 6M8 V	Version
Order No.	9200440000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	4032248410286	mm ² , yellow
Qty.	50 pc(s).	
Type	KQIG-M6/-1	Version
Order No.	1492590000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302318	mm ²
Qty.	100 pc(s).	
Type	KQIG-M6/-2,5	Version
Order No.	1491260000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301182	2.5 mm ²
Qty.	100 pc(s).	
Type	LIS 1,5M3 V	Version
Order No.	9200290000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5
GTIN (EAN)	4032248410118	mm ² , red
Qty.	100 pc(s).	
Type	LIS 1,5M5 V	Version
Order No.	9200320000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5
GTIN (EAN)	4032248410149	mm ² , red
Qty.	100 pc(s).	
Type	LIS 6M5 V	Version
Order No.	9200420000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	4032248410262	mm ² , yellow
Qty.	100 pc(s).	
Type	KQIG-M3,5/-2,5	Version
Order No.	1492610000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302097	2.5 mm ²
Qty.	100 pc(s).	
Type	LIS 1,5M3,5 V	Version
Order No.	9200300000	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5
GTIN (EAN)	4032248410125	mm ² , red
Qty.	100 pc(s).	

CTI 6 G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KQIG-M3,5/-1	Version
Order No.	1492530000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302370	mm ²
Qty.	100 pc(s).	
Type	KQIG-M5/-6	Version
Order No.	1491280000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301311	mm ²
Qty.	100 pc(s).	
Type	LIS 2,5M3 V	Version
Order No.	9200350000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5
GTIN (EAN)	4032248410170	mm ² , blue
Qty.	100 pc(s).	
Type	LIS 2,5M4 V	Version
Order No.	9200370000	cable lug, terminal end, Insulated cable connector, 1.5 mm ² - 2.5
GTIN (EAN)	4032248410194	mm ² , blue
Qty.	100 pc(s).	
Type	KQIG-M5/-1	Version
Order No.	1492580000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301793	mm ²
Qty.	100 pc(s).	
Type	KQIG-M10/-6	Version
Order No.	1491320000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301199	mm ²
Qty.	100 pc(s).	
Type	KQIG-M8/-6	Version
Order No.	1491310000	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6
GTIN (EAN)	4050118301298	mm ²
Qty.	100 pc(s).	
Type	LIS 6M4 V	Version
Order No.	9200410000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	4032248410255	mm ² , yellow
Qty.	100 pc(s).	
Type	KQIG-M4/-1	Version
Order No.	1492550000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302240	mm ²
Qty.	100 pc(s).	
Type	LIS 6M6 V	Version
Order No.	9200430000	cable lug, terminal end, Insulated cable connector, 4 mm ² - 6
GTIN (EAN)	4032248410279	mm ² , yellow
Qty.	100 pc(s).	
Type	KQIG-M4/S/-1	Version
Order No.	1492540000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118302523	mm ²
Qty.	100 pc(s).	
Type	KQIG-M5/-2,5	Version
Order No.	1492640000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118302448	2.5 mm ²
Qty.	100 pc(s).	

CTI 6 G**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Round-plug sleeves, fully insulated****Insulated cable connector in PVC or PC/PA**

- Conventional designs
- Not soldered
- With conical entry funnel, except for joint connector

General ordering data

Type	VRSHVI/1,5-2,5	Version
Order No.	1492030000	cable lug, terminal end, Insulated cable connector, 2.5 mm ² , 1.5 mm ² -
GTIN (EAN)	4050118301854	2.5 mm ²
Qty.	100 pc(s).	
Type	VRSHVI/0,5-1,0	Version
Order No.	1492020000	cable lug, terminal end, Insulated cable connector, 1 mm ² , 0.5 mm ² - 1
GTIN (EAN)	4050118301984	mm ²
Qty.	100 pc(s).	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9202850000](#)