

General ordering data

Part designation

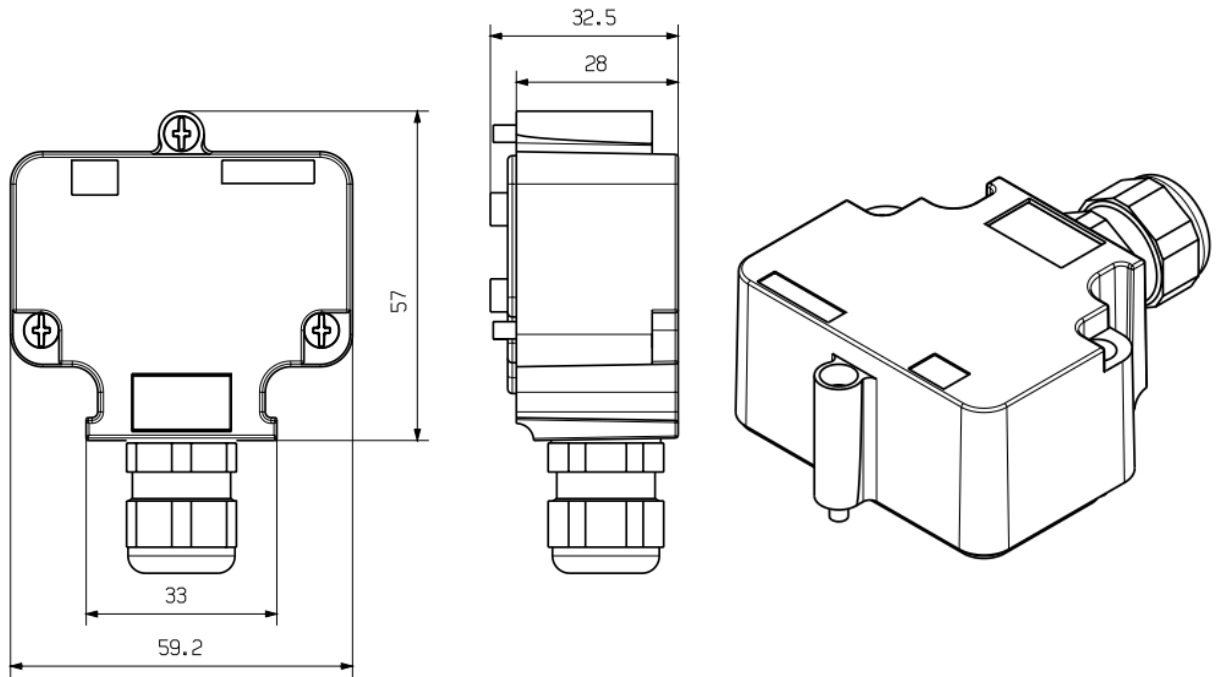
Order No.

Version

• SAI-4/6/8 MH-MM BL 3.5

• 1724754000

• Metal hood version, plastic gland, screw connection

**Technical data**

Ambient temperature

Material housing

Ingress protection class

Nominal voltage

Total current

Current per signal

Max. Current-carrying capacity per slot

Conductor O.D., min-max.

Sheathing stripping length

Cable gland

Clamping range, min.-max.

• -20°C ... 80°C

• Zinc diecast

• IP67/ 68

• 10 ... 30 V

• 10 A

• 2 A

• 4 A

• 6mm-12mm

• 100mm

• M20

• 0,08mm²-1.5mm²

General ordering data

Part designation
Order No.
Version

- SAI-4/6/8-MHF 5P PUR XM
- 179146XXXX
- Hood version, fixed cable, Xm

Number	Wire cross sesction in mm²	Color
1	0,34	white
2	0,34	green
3	0,34	yellow
4	0,34	grey
5	0,34	pink
6	0,34	red
7	0,34	black
8	0,34	violett
9	0,34	Grey/pink
10	0,34	Red/blue
11	0,34	White/green
12	0,34	Brown/green
13	0,34	White/yellow
14	0,34	Yellow/brown
15	0,34	White/grey
16	0,34	Grey/brown
17	1	brown
18	1	blue
19	1	red
20	1	black
21	1	Green/yellow

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1724754000](#)