


**CRIMP TYPE CABLE CONNECTORS FOR FLEXIBLE CABLE****Straight Plug, Non-Captive Contact**


| Part Number         | Cable Numbers  |
|---------------------|----------------|
| 050 - 622 - 9188890 | RG174/U, 316/U |
| 050 - 622 - 9875890 | RD316          |

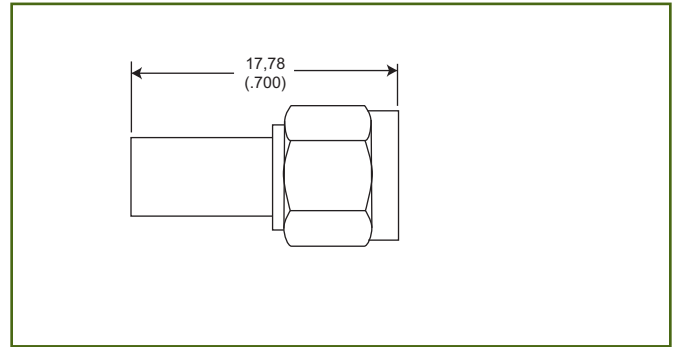

Assembly Instructions AI-102 (Page 43)

**Straight Plug, Captive Contact**


| Part Number         | Cable Numbers  |
|---------------------|----------------|
| A50 - 624- 9188890  | RG174/U, 316/U |
| A50 - 624 - 9875890 | RD316          |

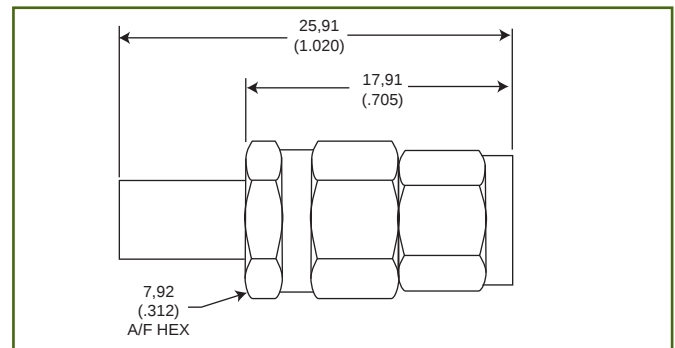

Assembly Instructions AI-703 (Page 51)

**Right Angle Plug, Captive Contact**


| Part Number         | Cable Numbers  |
|---------------------|----------------|
| 050 - 628- 9188890  | RG174/U, 316/U |
| 050 - 628 - 9875890 | RD316          |

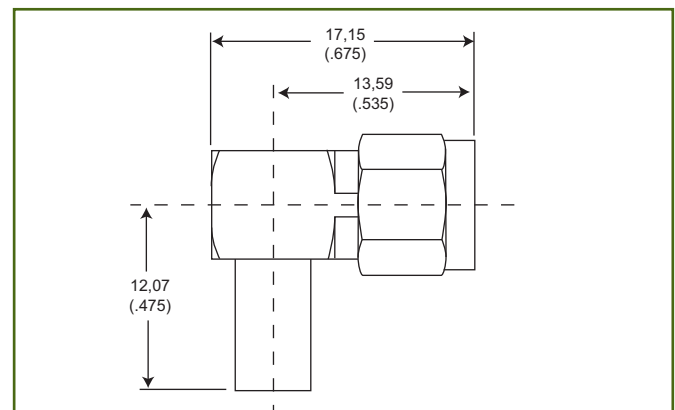

Assembly Instructions AI-90 (Page 41)

**Bulkhead Jack, Captive Contact**

| Part Number        | Cable Numbers  |
|--------------------|----------------|
| 050 - 627- 9188890 | RG174/U, 316/U |
| 050 - 627- 9875890 | RD316          |

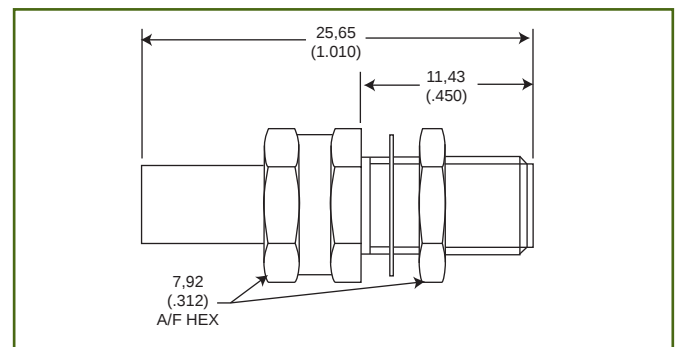

Mounting Plan W (Page 40)

Assembly Instructions AI-227 (Page 46)

The surface finish on these products is passivated stainless steel. For gold plated versions change last three digits of the the part number from 890 to 310.



Dimensions shown in mm (inch)  
Specifications and dimensions subject to change

[www.ittcannon.com](http://www.ittcannon.com)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ITT Cannon:](#)

[A50-624-9188310](#)