


AD8015-7 SERIES




External Dimensions

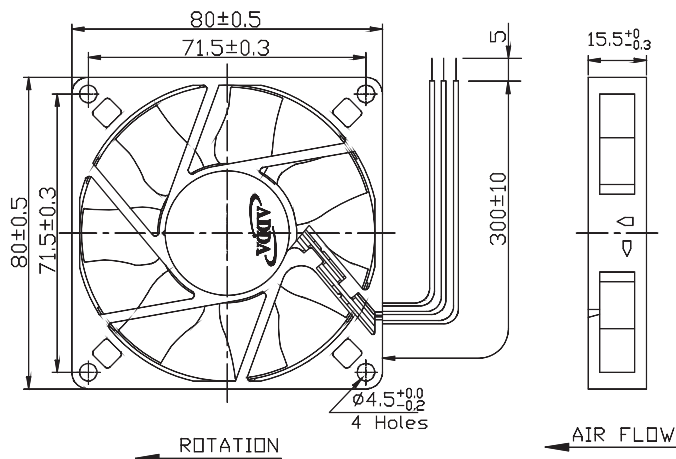

Frame:Plastic(UL:94V-0)
Impeller:Plastic(UL:94V-0)
Lead wire:UL1007AWG24

Specifications(Nominal)


*Noise is measured at the distance of one (1) meter from the axis of intake.

Bearing type: ◎=Ball ※=Sleeve ●=Hypro bearing

Frame size (mm)	Model No.	Bearing System Type	Rated Voltage (VDC)	Current (A)	Power (W)	Rated Speed (rpm)	Maximum AirFlow (CMM)	Maximum AirFlow (CFM)	Maximum Pressure (InAq)	Maximum Pressure (mmAq)	*Noise Level (dB/A)	Weight (g)
80x80x15	AD0805MB-D73(N75)	◎ ●	5	0.13	0.65	2440	0.574	20.299	0.073	1.854	27.5	62.0
	AD0805HB-D73(N75)	◎ ●	5	0.22	1.10	3200	0.778	27.494	0.129	3.276	35.4	
	AD0812LB-D73(N75)	◎ ●	12	0.03	0.36	2000	0.489	17.287	0.054	1.371	21.6	
	AD0812MB-D73(N75)	◎ ●	12	0.05	0.60	2440	0.574	20.299	0.073	1.854	27.5	
	AD0812HB-D73(N75)	◎ ●	12	0.09	1.08	3200	0.778	27.494	0.129	3.276	35.4	
	AD0812UB-D73(N75)	◎ ●	12	0.13	1.56	3800	0.922	32.589	0.186	4.724	40.7	
	AD0824MB-D73(NEUM)	◎ ●	24	0.03	0.72	2440	0.574	20.299	0.073	1.854	27.5	
	AD0824HB-D73(NEUM)	◎ ●	24	0.06	1.44	3200	0.778	27.494	0.129	3.276	35.4	
	AD0824UB-D73(NEUM)	◎ ●	24	0.08	1.92	3800	0.922	32.589	0.186	4.724	40.7	
	AD0824XB-D73(NEUM)	◎ ●	24	0.10	2.40	4300	1.042	36.845	0.226	5.740	43.3	

Specifications subject to change without notice.

The specification for bearing type is for reference only , for more bearing types information, please contact with your ADDA sales representative, thanks!!
(網頁上呈現產品軸承資訊均以2Ball為主，若需其他產品資訊請聯絡您在ADDA的業務代表，謝謝!!)

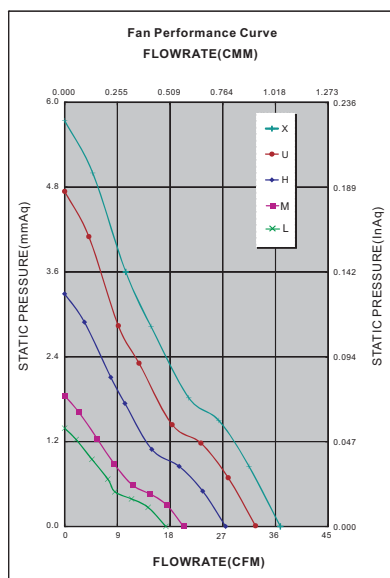

*Motor protective circuit and third lead wire functions

0	1	2	3	4	6	7	8	9	A	B
	✓	✓	✓							

*Safety approvals

✓	✓		✓	✓

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ADDA:](#)

[AD0812HB-D71-5"-LF](#) [AD0824MB-D71-LF](#) [AD0805HB-D71-LF](#) [AD0812UB-D71\(N75\)](#) [AD0812HB-D71\(N75\)](#)
[AD0805MB-D71\(N75\)](#) [AD0812LB-D71\(N75\)](#) [AD0812MB-D71\(N75\)](#) [AD0805HB-D71\(N75\)](#)