




# AD8015-7 SERIES

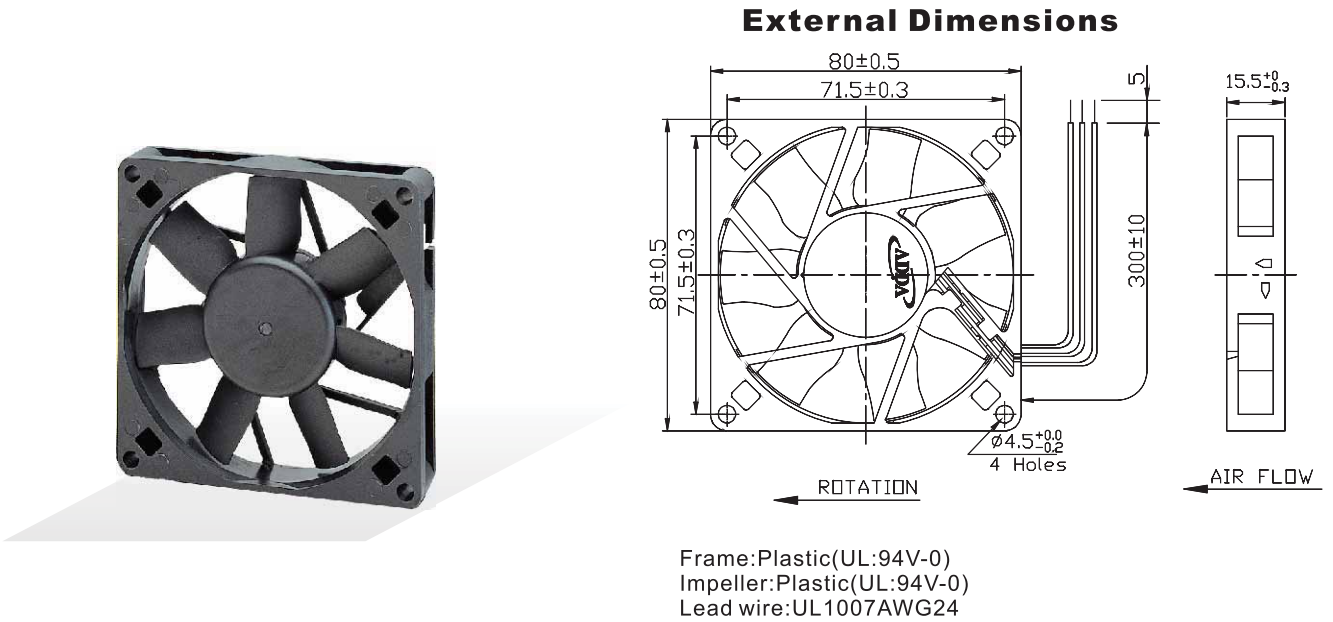

Specifications(Nominal)

\*Noise is measured at the distance of one (1) meter from the axis of intake.


Bearing type: ◎=Ball※=Sleeve●=Hypro bearing

| Frame size (mm) | Model No.       | Bearing System Type | Rated Voltage (VDC) | Current (A) | Power (W) | Rated Speed (rpm) | Maximum AirFlow (CMM) | (CFM)  | Maximum Pressure (InAq) | (mmAq) | *Noise Level (dB/A) | Weight (g) |
|-----------------|-----------------|---------------------|---------------------|-------------|-----------|-------------------|-----------------------|--------|-------------------------|--------|---------------------|------------|
| 80x80x15        | AD0805MB-D73(N) | ◎※●                 | 5                   | 0.13        | 0.65      | 2440              | 0.617                 | 21.805 | 0.078                   | 1.981  | 24.9                | 62.0       |
|                 | AD0805HB-D73(N) | ◎※●                 | 5                   | 0.22        | 1.10      | 3200              | 0.841                 | 29.722 | 0.122                   | 3.098  | 34.4                |            |
|                 | AD0812LB-D73(N) | ◎※●                 | 12                  | 0.04        | 0.48      | 2000              | 0.518                 | 18.335 | 0.052                   | 1.320  | 18.8                |            |
|                 | AD0812MB-D73(N) | ◎※●                 | 12                  | 0.05        | 0.60      | 2440              | 0.617                 | 21.805 | 0.078                   | 1.981  | 24.9                |            |
|                 | AD0812HB-D73(N) | ◎※●                 | 12                  | 0.11        | 1.32      | 3200              | 0.841                 | 29.722 | 0.122                   | 3.098  | 34.4                |            |
|                 | AD0812UB-D73(N) | ◎※●                 | 12                  | 0.16        | 1.92      | 3800              | 0.971                 | 34.338 | 0.173                   | 4.394  | 38.1                |            |
|                 | AD0824MB-D73(N) | ◎※●                 | 24                  | 0.05        | 1.20      | 2440              | 0.617                 | 21.805 | 0.078                   | 1.981  | 24.9                |            |
|                 | AD0824HB-D73(N) | ◎※●                 | 24                  | 0.08        | 1.92      | 3200              | 0.841                 | 29.722 | 0.122                   | 3.098  | 34.4                |            |

Specifications subject to change without notice.

The specification for bearing type is for reference only , for more bearing types information, please contact with your ADDA sales representative, thanks!!

(網頁上呈現產品軸承資訊均以2Ball為主，若需其他產品資訊請聯絡您在ADDA的業務代表，謝謝!!)

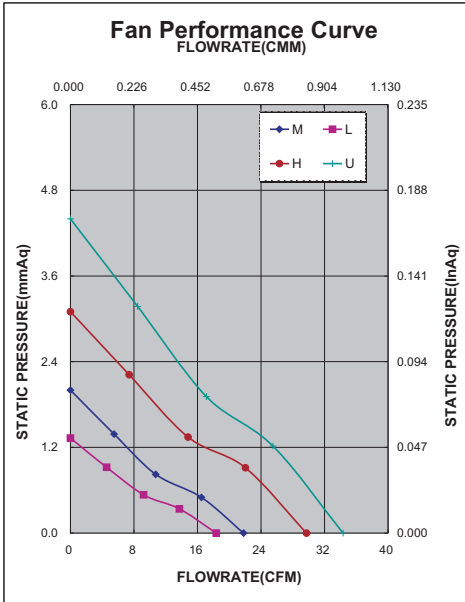

\*Motor protective circuit and third lead wire functions

|   |   |   |   |   |   |   |   |   |   |   |
|---|---|---|---|---|---|---|---|---|---|---|
| 0 | 1 | 2 | 3 | 4 | 6 | 7 | 8 | 9 | A | B |
|   | ✓ | ✓ | ✓ |   |   |   |   |   |   |   |

\*Safety approvals

|   |   |  |   |   |
|---|---|--|---|---|
|   |   |  |   |   |
| ✓ | ✓ |  | ✓ | ✓ |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ADDA:](#)

[AD0812HB-D71-5"-LF](#) [AD0812UB-D71\(N75\)](#) [AD0812HB-D71\(N75\)](#) [AD0805MB-D71\(N75\)](#) [AD0812LB-D71\(N75\)](#)  
[AD0812MB-D71\(N75\)](#)