


AD8025 SERIES

External Dimensions

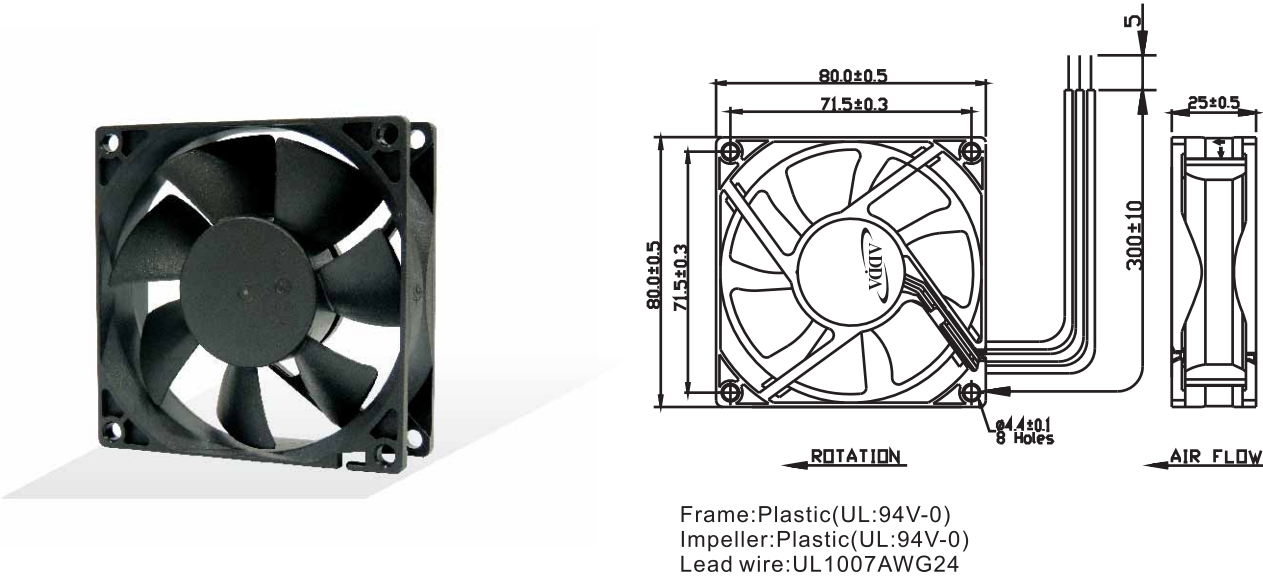


Specifications(Nominal)

*:Noise is measured at the distance of one (1) meter from the axis of intake.

Bearing type: ◎=Ball※=Sleeve●=Hypro bearing												
Frame size (mm)	Model No.	Bearing System Type	Rated Voltage (VDC)	Current (A)	Power (W)	Rated Speed (rpm)	Maximum AirFlow (CMM) (CFM)		Maximum Pressure (InAq) (mmAq)		*Noise Level (dB/A)	Weight (g)
80x80x25	AD0812DB-A73GL(LN)	◎ ※ ●	12	0.04	0.48	1600	0.611	21.607	0.046	1.168	14.0	86.0
	AD0812LB-A73GL(LN)	◎ ※ ●	12	0.06	0.72	2000	0.758	26.801	0.078	1.981	21.6	
	AD0812MB-A73GL(LN)	◎ ※ ●	12	0.09	1.08	2500	0.945	33.400	0.117	2.971	28.3	
	AD0812HB-A73GL(LN)	◎ ※ ●	12	0.16	1.92	3000	1.139	40.259	0.154	3.911	33.4	
	AD0812UB-A73GL(LN)	◎ ※ ●	12	0.30	3.60	3900	1.485	52.494	0.265	6.731	40.8	
	AD0812XB-A73GL(LN)	◎ ※ ●	12	0.33	3.96	4200	1.606	56.768	0.303	7.696	43.4	
	AD0824MB-A73GL(LN)	◎ ※ ●	24	0.06	1.44	2500	0.945	33.400	0.117	2.971	28.3	
	AD0824HB-A73GL(LN)	◎ ※ ●	24	0.09	2.16	3000	1.139	40.259	0.154	3.911	33.4	
	AD0824UB-A73GL(LN)	◎ ※ ●	24	0.15	3.60	3900	1.485	52.494	0.265	6.731	40.8	
Specifications subject to change without notice.												

The specification for bearing type is for reference only , for more bearing types information, please contact with your ADDA sales representative, thanks!!
(網頁上呈現產品軸承資訊均以2Ball為主，若需其他產品資訊請聯絡您在ADDA的業務代表，謝謝！！)

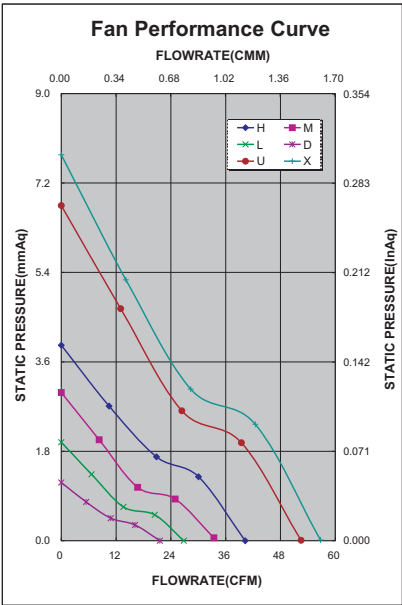

*Motor protective circuit and third lead wire functions

0	1	2	3	4	6	7	8	9	A	B
	✓	✓	✓							

*Safety approvals

✓	✓	✓	✓	✓

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ADDA:](#)

[AD0812HB-A76GL-LF](#) [AD0812DX-A70GL-LF](#) [AD0824HB-A73GL\(LN\)](#) [AD0824LB-A73GL\(LN\)](#) [AD0824MB-A73GL\(LN\)](#) [AD0812MB-A73GL\(LN\)](#)