


AD9225(T) SERIES



External Dimensions

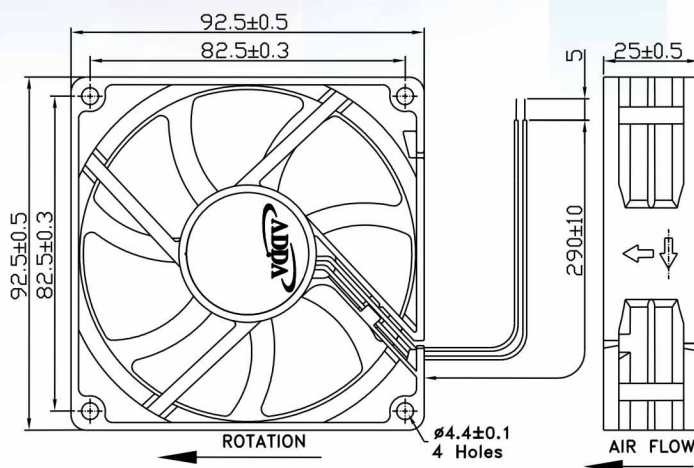

Frame:Plastic(UL:94V-0)
Impeller:Plastic(UL:94V-0)
Bearing:Hypro bearing
Lead wire:UL1007AWG24
VOLTAGE AVAILABLE:24V


Specifications(Nominal)

*:Noise is measured at the distance of one (1) meter from the axis of intake.

Bearing type: ◎=Ball※=Sleeve○=1B1S●=Hypro bearing

Frame size (mm)	Model No.	Bearing System Type	Rated Voltage (VDC)	Rated Current (A)	Actual Current (A)	Rated Power (W)	Actual Power (W)	Rated Speed (rpm)	Maximum AirFlow (CMM)	Maximum AirFlow (CFM)	Maximum Pressure (InAq)	Maximum Pressure (mmAq)	*Noise Level (dB/A)	Weight (g)
92x92x25	AD0912DB-A70GL(T) ◎ ※ ●		12	0.09	0.07	1.08	0.84	1600	0.794	28.00	0.002	0.06	22.0	101.0
	AD0912LB-A70GL(T) ◎ ※ ●		12	0.13	0.10	1.56	1.20	2000	1.022	36.00	0.063	1.60	25.0	
	AD0912MB-A70GL(T) ◎ ※ ●		12	0.17	0.15	2.04	1.80	2400	1.235	43.50	0.092	2.33	31.3	
	AD0912HB-A70GL(T) ◎ ※ ●		12	0.25	0.26	3.00	3.12	2900	1.491	52.50	0.133	3.37	35.0	
	AD0912UB-A70GL(T) ◎ ※ ●		12	0.30	0.28	3.60	3.36	3300	1.619	57.00	0.160	4.06	39.4	
	AD0924LB-A70GL(T) ◎ ※ ●		24	0.08	0.05	1.92	1.20	2000	1.022	36.00	0.063	1.60	26.5	
	AD0924MB-A70GL(T) ◎ ※ ●		24	0.12	0.09	2.88	2.16	2400	1.235	43.50	0.092	2.33	31.0	
	AD0924HB-A70GL(T) ◎ ※ ●		24	0.15	0.14	3.60	3.36	2900	1.491	52.50	0.133	3.37	35.0	

Specifications subject to change without notice.

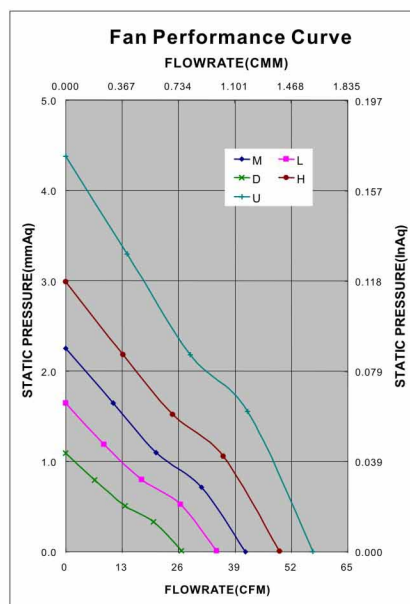

*Motor protective circuit and third lead wire functions

0	1	2	3	4	6	7	8	9	A	B
✓					✓					

*Safety approvals

UL	cUL	SA	DAIWA	CE
✓	✓		✓	✓

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ADDA:](#)

[AD0912UB-A70GLLF](#) [AD0924LB-A70GL\(HT\)](#) [AD0912LB-A70GL\(HT\)](#) [AD0924UB-A70GL\(HT\)](#) [AD0924HB-A70GL\(HT\)](#) [AD0924MB-A70GL\(HT\)](#) [AD0912MB-A70GL\(HT\)](#) [AD0912HB-A70GL\(HT\)](#) [AD0912UB-A70GL\(HT\)](#)